


1-206062-2 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

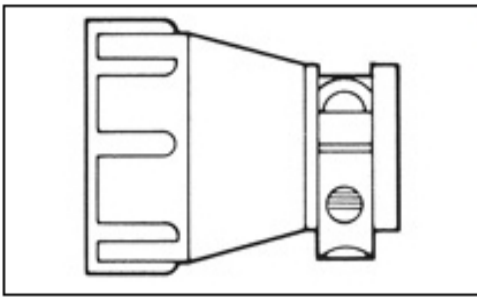

1-206062-2

TE Part Number: 1-206062-2

Active

Add to Part List

View 3D PDF

CPC Accessories

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Cable Clamp
- Shell Size = 11
- Body Style = Straight
- Cable Diameter (Max.) = 8.36 mm
- Thermoplastic Cable Clamp Material

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [CABLE CLAMP KIT, STANDARD, SHELL SIZE 11, CPC](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: [\(CAD Format & Compression Information\)](#)

- [2D Drawing](#) (DXF, Version T)
- [3D Model](#) (IGES, Version T)
- [3D Model](#) (STEP, Version T)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Product Usage](#)
- [Product Usage](#)
- [Product Usage](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Cable Clamp
- [Shell Size](#) = 11
- [Body Style](#) = Straight
- Thread Size = 5/8-24
- Screw Size = 5-20 Self-Tapping
- Comment = Clamping areas adjustable by inverting or changing inserts.; Cable clamp inserts are not sold separately.; Replacement screws are available in the following sizes: 9.52mm [3/8 in.] -P/N 19024-1, 12.7mm [1/2 in.] -P/N 19024-2, 15.88]mm [5/8 in.] -P/N 19024-3, 25.4mm [1 in.] -P/N 19024-4, 19.05mm [3/4 in.]-P/N 19024-5.; Components for all cable clamps are packaged unassembled. This includes the cable clamp, two screws, and the clamping inserts.; Cable clamps can be threaded directly onto plugs or receptacles, or onto back-shell extenders.

Termination Related Features:

- Screw Finish = Stainless Steel (Non Magnatic)

Body Related Features:

- [Cable Diameter \(Max.\)](#) (mm [in]) = 8.36 [0.329]
- [Cable Clamp Material](#) = Thermoplastic
- [Cover](#) = Without
- Cable Clamp Color = Black
- Cable Clamp Flammability Rating = UL94V-1

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Individual

Other:

- Brand = AMP