


Product Details for 603817 -4

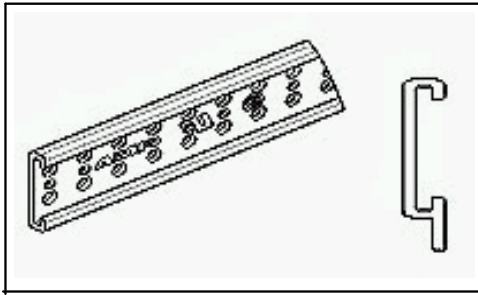

603817 -4

[Active](#)

Accessories (Terminal Block)

[RoHS Compliant \(Statement of Compliance\)](#)

Product Highlights:

- ? Accessory Type = Mounting Channel
- ? Number of Circuits = 1 thru 80
- ? FLEXI-BLOCK Dual Barrier Block Series
- ? Used With FLEXI -BLOCK #6 Series
- ? Block or Strip Style = Barrier Strips

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [TRACK WITH MARKER TAB, F -B6](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Accessory Type](#) = Mounting Channel
- ? [Number of Circuits](#) = 1 thru 80
- ? [Block or Strip Style](#) = Barrier Strips
- ? [Mounting Channel Type](#) = Pre -Punched Plastic
- ? Comment = For marker identification. Accommodates 80 positions, 2 end stops.; When cutting track to required length, use number of positions plus two positions for end stops.

Body Related Features:

- ? [Block Series](#) = FLEXI -BLOCK Dual Barrier
- ? [Used With](#) = FLEXI -BLOCK #6 Series
- ? Mounting Channel Length (ft) = 3
- ? Mounting Track Material = Noryl
- ? Mounting Track Color = White
- ? Track Shape = Flanged
- ? Mounting Track Length (mm [in]) = 914.40 [36.000]

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- ? Brand = AMP