


1-322249-9 Product Details

Have a Question?

Chat with a Product Information Specialist

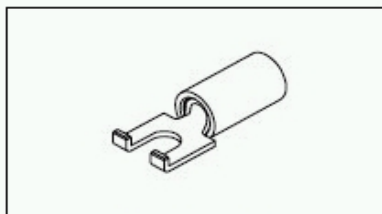

1-322249-9

TE Internal Number: 1-322249-9

Active

[View 3D PDF](#)

Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Terminal Shape = Spade Tongue, Flanged
- Receptacle Style = Straight
- Body Style = PLASTI-GRIP
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [TERMINAL, SPADE, FLANGED, PLASTI-GRIP, WIRE SIZE: 22...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [PLASTI-GRIP Terminals and Splices](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version L)
- [3D Model](#) (IGES, Version L)
- [3D Model](#) (STEP, Version L)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Product Photo](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Terminal Shape](#) = Spade Tongue, Flanged
- [Receptacle Style](#) = Straight
- [Body Style](#) = PLASTI-GRIP
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 2.67-3.56 [.105-.140]
- [Stud Diameter \(mm \[in\]\)](#) = 4.34 [0.171]
- Stud Size = 8 [M4]
- [Shape](#) = SPADE-025
- [Heavy Duty](#) = No
- [Material](#) = Copper
- [Finish](#) = Tin
- Tongue Material Thickness (mm [in]) = 0.79 [0.031]
- Color = Red
- Insulation Material = Vinyl

Electrical Characteristics:

- Voltage (VAC) = 600

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.30-1.40² [22-16]
- Wire Range (CMA) = 509 - 3,260

Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Tape Mounted
- Packaging Quantity = 5,000/Reel

Other:

- Brand = AMP

BOOKMARK

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat with Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:



Visit Us On:

