


8-321026-1 Product Details

Have a Question?

Chat with a Product Information Specialist

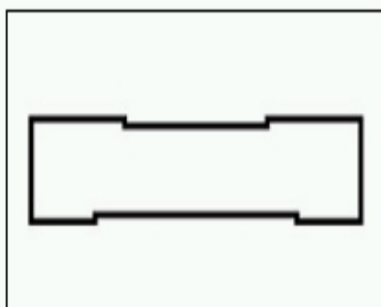

8-321026-1

Splices - Closed Barrel

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Splice
- Not Sealed
- Splice Type = Butt
- Butt Splice Type = Standard
- Body Style = PLASTI-GRIP

[View all Features](#)

TE Internal Number: 8-321026-1

Active

[View 3D PDF](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [WIRE BUTT SPLICE, PLASTI-GRIP, WIRE SIZE: 26-22](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [PLASTI-GRIP Terminals and Splices](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files: [\(CAD Format & Compression Information\)](#)

- [2D Drawing](#) (DXF, Version F2)
- [3D Model](#) (IGES, Version F2)
- [3D Model](#) (STEP, Version F2)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Splice
- [Sealed](#) = No
- [Splice Type](#) = Butt
- [Body Style](#) = PLASTI-GRIP
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 2.03 [.080] Max.
- [Material](#) = Copper
- [Finish](#) = Tin
- [Color](#) = Yellow
- [Comment](#) = 26-22 splices are 26-24 range in accordance with MIL-T-7928.

Body Related Features:

- [Butt Splice Type](#) = Standard
- [Wire Range \(mm \[AWG\]\)](#) = 0.12-0.40² [26-22]
- [Wire Range \(CMA\)](#) = 202 - 810
- [Insulation Sleeve Material](#) = Vinyl

Industry Standards:

- [Government/Industry Qualification](#) = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Loose Piece
- [Packaging Quantity](#) = 100/Box

Other:

- [Brand](#) = AMP

BOOKMARK

Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:



Visit Us On:

