
 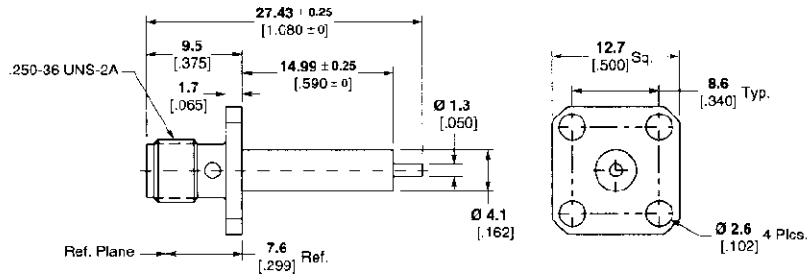




SMA Connectors (Continued)
Panel Mount, Straight Terminal

4 Hole Flange Mount Jack Receptacle





| Body Material & Finish | Contact Captivation | RF Leakage db min. | Temperature Range | M/A-COM Model No. | Part No. |
|------------------------|---------------------|--------------------|-------------------|-------------------|-----------|
| Stainless, Passivated | None | -(100-fGHz) | -65 to 165° C | 2052-1200-02 | 1052518-1 |
| Stainless, Passivated | Epoxy | -(60-fGHz) | -65 to 125° C | 2052-1201-02 | 1052523-1 |
| Stainless, Gold | Epoxy | -(60-fGHz) | -65 to 125° C | 2052-1201-00 | 1052522-1 |

 2 Hole Flange Mount Plug Receptacle

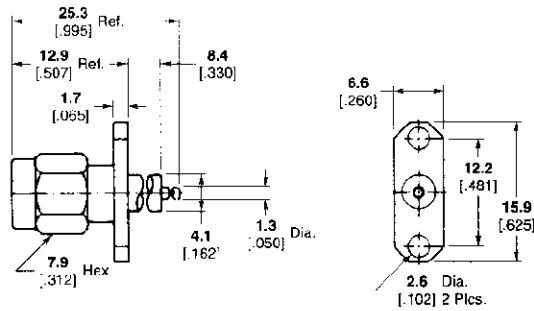

| Body Material & Finish | Contact Captivation | RF Leakage db min. | Temperature Range | M/A-COM Model No. | Part No. |
|------------------------|---------------------|--------------------|-------------------|-------------------|-----------|
| Stainless, Passivated | Epoxy | -(60-fGHz) | -65 to 125° C | 2051-1352-02 | 1052349-1 |

2 Hole Flange Mount Jack Receptacle

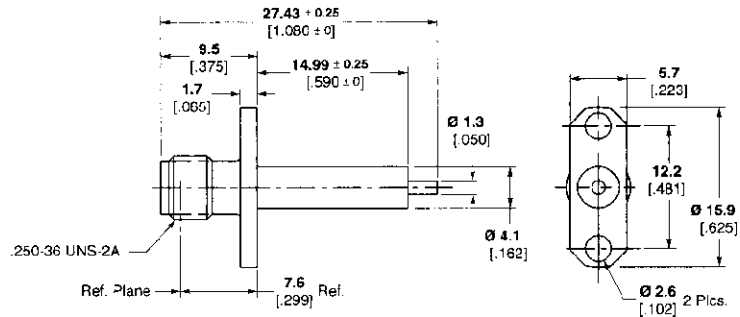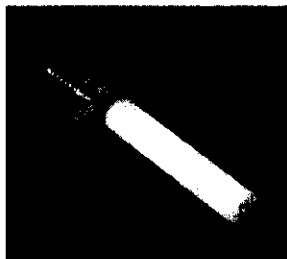

| Body Material & Finish | Contact Captivation | RF Leakage db min. | Temperature Range | M/A-COM Model No. | Part No. |
|------------------------|---------------------|--------------------|-------------------|-------------------|-----------|
| Stainless, Passivated | None | -(100-fGHz) | -65 to 165° C | 2052-1351-02 | 1052548-1 |
| Stainless, Passivated | Epoxy | -(60-fGHz) | -65 to 125° C | 2052-1352-02 | 1052552-1 |