


**SSMT Surface Mount Interconnect System** (Continued)

**Right Angle Jack to Jack  
Cable Assembly  
(180° Offset)**

Assembly Length (A)	M/A-COM Model No.	Part No.
100 [4.0]	9960-3100-24	1082845-1
200 [8.0]	9960-3200-24	1082846-1
305 [12.0]	9960-3305-24	1082847-1

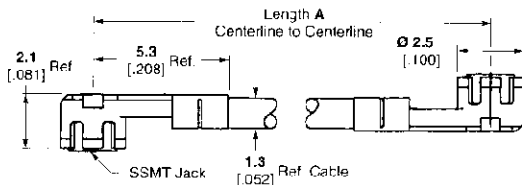


**Notes:**

- Consult AMP for non-standard cable lengths.  
Cable length tolerance:  
Length A Tolerances:  

Length A	Tolerance
50 To 100 [3.94]	± 3 [± .12]
101 To 500 [3.98 to 19.69]	± 5 [± .20]
Over 500 [19.69]	± 10 [± .39]
- SSMT Jack is not mateable with OSMT High Retention Plug receptacle (1055690-1).
- To avoid damaging the cable, minimize time at temperature while soldering and/or applying heat to unterminated end of cable.

**Right Angle Jack Cable  
Pigtail**

Assembly Length (A)	M/A-COM Model No.	Part No.
100 [4.0]	9960-2100-24	1064535-1
200 [8.0]	9960-2200-24	1064538-1
305 [12.0]	9960-2305-24	1064540-1
510 [20.0]	9960-2510-24	1064542-1

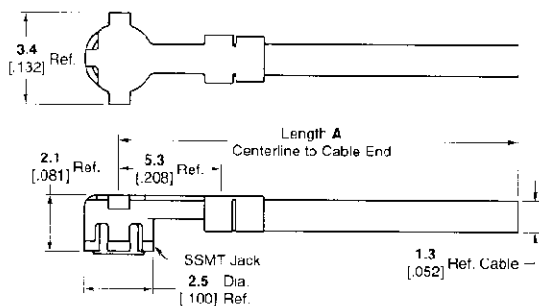

**Notes:**

- Consult AMP for non-standard cable lengths.  
Cable length tolerance:  
Length A Tolerances:  

Length A	Tolerance
50 To 100 [3.94]	± 3 [± .12]
101 To 500 [3.98 to 19.69]	± 5 [± .20]
Over 500 [19.69]	± 10 [± .39]
- SSMT Jack is not mateable with OSMT High Retention Plug receptacle (1055690-1).
- To avoid damaging the cable, minimize time at temperature while soldering and/or applying heat to unterminated end of cable.