

J3 Type B Right-Angle Female Connector

Materials and Finish

Glass filled polyester housing, gray,
UL94 V-0 rated.

Phosphor-bronze signal contacts and
shields

Contact area 0.8µm Au
over 1.3µm Ni


ACTION PIN contact 0.5µm Sn/Pb
over 1.3 µm Ni.

Enhanced electrical performance is
attained through the use of pre-
attached upper ground return
shields.

- 95 signal contacts
- Length 37.9mm

- Daughter Card applications

Technical documents see pg 82.

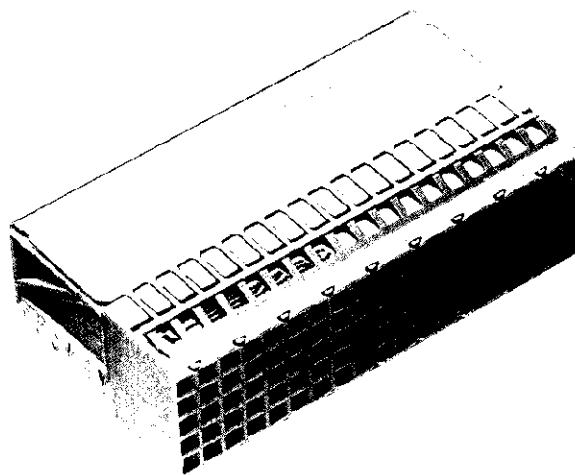

Connector Type	CompactPCI Designation	Number of Signal Contacts	Part Number
B (19)	J3	95	352171-1

