

## P2/P5 Type B Vertical Male Feed-To

### Materials and Finish


Glass filled polyester housing gray,  
UL94 V-0 rated  
Phosphor-bronze signal contacts  
Contact area 0.8µm Au over 1.3µm Ni  
ACTION PIN contact 0.5µm Sn/Pb  
over 1.3 µm Ni

### 5+2 Row Configuration



This configuration accommodates the upper ground return shield feature on the mating female connector by providing contacts in rows z & f in addition to the five rows of signal pins.

- 110 signal contacts
- Length 43.9mm
- Backplane applications



Technical documents see pg 82.

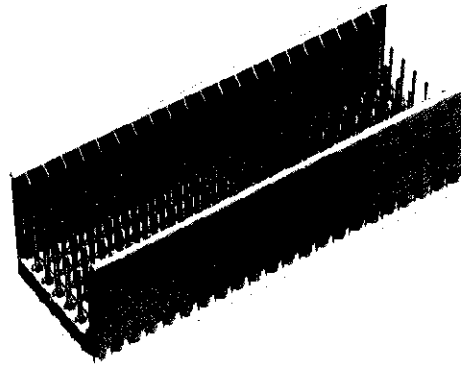

Connector Type	CompactPCI Designation	Number of Signal Contacts	Part Number
B (22)	P2.P5	110	188835-1

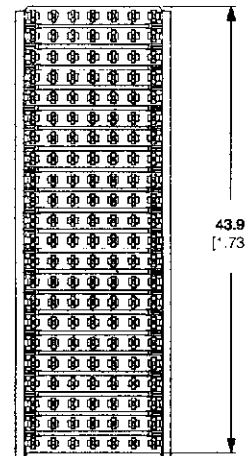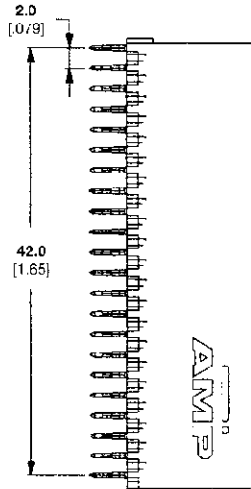

### Contact Layout

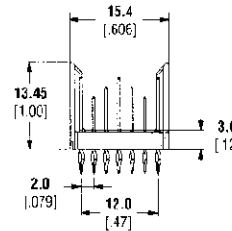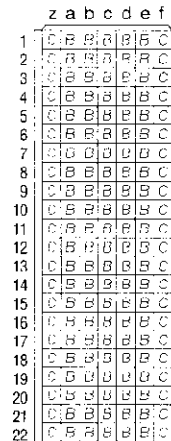

### CONTACT DIMENSIONS

