

**Post Header Assemblies (For MT Type)**


**Standard Type  
(PC Board Application  
Side)**

**Horizontal Mount Type**


**Materials and Finishes:**

Housing—UL94V-0 rated,  
6/6 nylon, see note  
below for color

Post Contact—Tin-lead  
plated brass

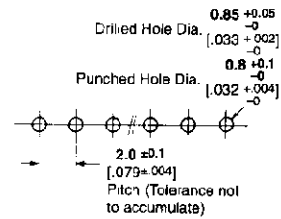

(Acceptable board thickness: 0.8-1.6mm)

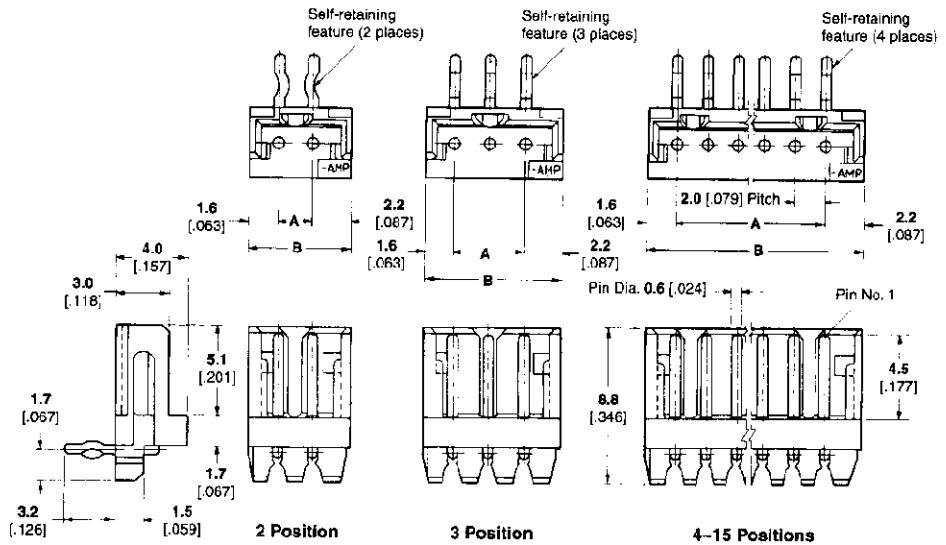


**Vertical Mount Type**


**Materials and Finishes:**

Housing—UL94V-0 rated,  
6/6 nylon, see note  
below for color

Post Contact—Tin-lead  
plated brass

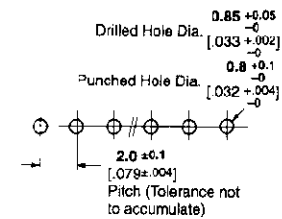

(Acceptable board thickness: 0.8-1.6mm)

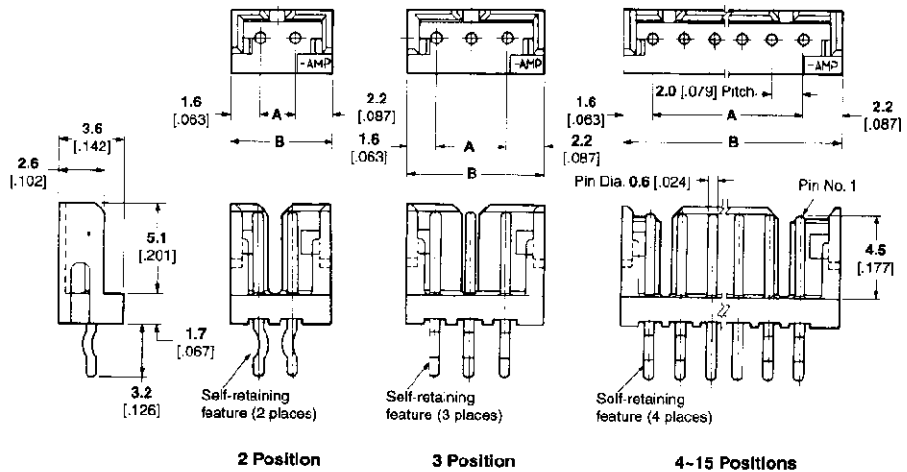

No. of Pos.	Dimensions		Part No. of Post Header Assembly*	
	A	B	Horizontal Mount	Vertical Mount
2	2.0 [.079]	5.8 [.228]	173979-2	173981-2
3	4.0 [.157]	7.8 [.307]	173979-3	173981-3
4	6.0 [.236]	9.8 [.396]	173979-4	173981-4
5	8.0 [.315]	11.8 [.465]	173979-5	173981-5
6	10.0 [.394]	13.8 [.543]	173979-6	173981-6
7	12.0 [.472]	15.8 [.622]	173979-7	173981-7
8	14.0 [.551]	17.8 [.701]	173979-8	173981-8
9	16.0 [.630]	19.8 [.780]	173979-9	173981-9
10	18.0 [.709]	21.8 [.858]	1-173979-0	1-173981-0
11	20.0 [.787]	23.8 [.937]	1-173979-1	1-173981-1
12	22.0 [.866]	25.8 [1.02]	1-173979-2	1-173981-2
13	24.0 [.945]	27.7 [1.09]	1-173979-3	1-173981-3
14	26.0 [1.02]	29.8 [1.17]	1-173979-4	1-173981-4
15	28.0 [1.10]	31.8 [1.25]	1-173979-5	1-173981-5

\*The color of housing is natural. Other colors available include blue, yellow, black, and red.