



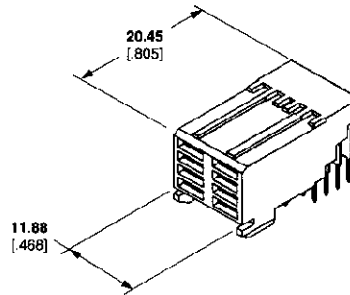

Z-PACK 2mm FutureBus+ Connectors (Continued)
 IEC61076-4-0X(48B)

4 Row — Power Modules, Right Angle Receptacle Assemblies
 (Free-Board Connector), 2mm x 2mm Circuit Grid


Receptacle Assemblies with Solder Leads and Compliant Press-Fit Leads (8 Positions)

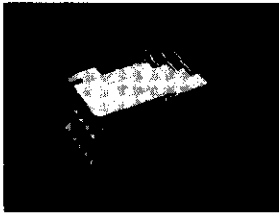

Material and Finish:


Housing — Liquid crystal polymer
Receptacle Contacts — Phosphor bronze, duplex plated gold flash over 0.0008 min. palladium-nickel or mating surface, 0.0038 min. tin-lead on solder lead, with entire contact underplated 0.0013 nickel

Related Product Data
Material Specifications — page 293
Compliant Press-Fit Contact Specifications — page 293
Application Tooling — page 360

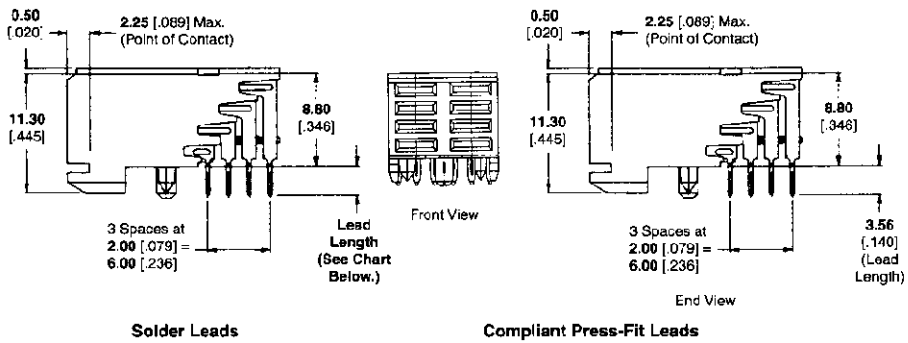

Technical Documents

- Product Specification**
108-1441
- Application Specification**
114-1075
- Instruction Sheets**
408-6927, 408-9910, 408-9979
- Electrical Performance Report**
6547E

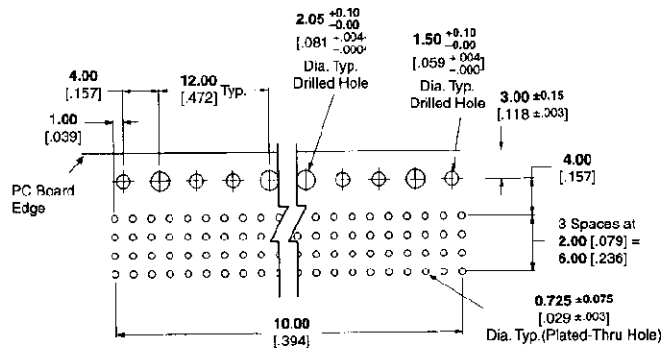

Recommended PC Board Hole Layout
 per IPC-D-300, Type II, Class C
 (Component Side)

Receptacle Assembly

No. of Positions	Part Numbers			Seating Tooling
	with Solder Leads		with Press-Fit Leads	
	2.73 [.107] Lead Length	3.53 [.139] Lead Length		
8	536607-1	536613-1	536614-1	Industry Standard Flat Rock