

# Unshielded Cable Clamps

## Material and Finish:

**Cable Clamp Housing**—

Thermoplastic, black

**Cable Clamp Wedge Set**—

Thermoplastic, black

**4-40 Mounting Screws**—

Steel, zinc plated

## Related Product Data:

**Connectors used with:**

**HDE Metal-Shell**—pages 119 & 120

**HDP Metal-Shell**—pages 95-107


**Other accessory capabilities:**

**Spring Latches (Two Piece)**—  
page 157

## Technical Documents:

**Instruction Sheet**—408-7555

## Universal Cable Clamps for Jacketed Cable

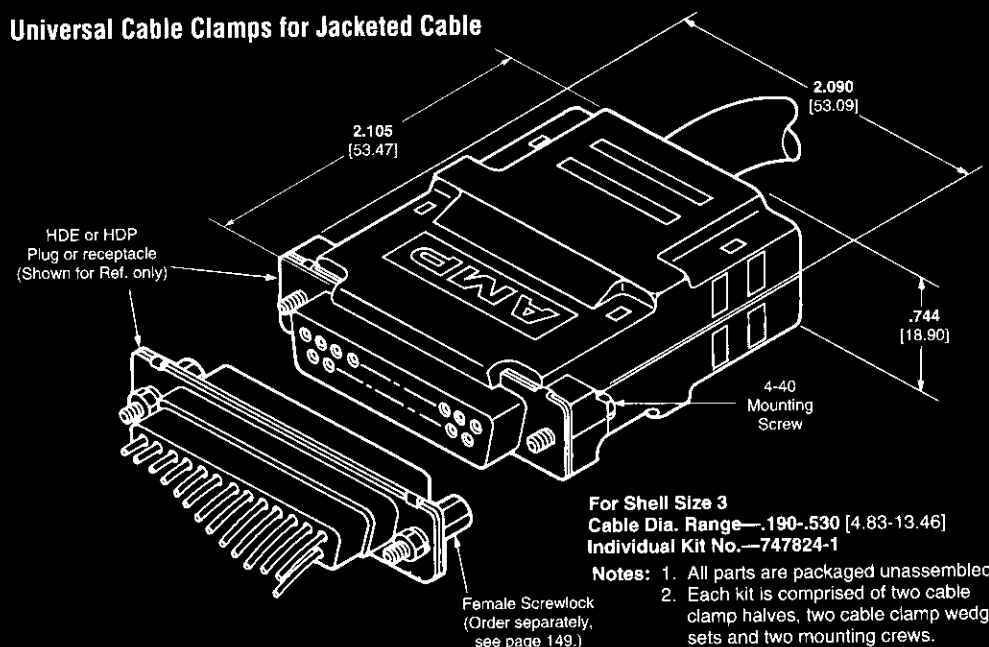

## Material and Finish:

**Cable Clamp Housing**—

Thermoplastic, gray

**4-40 Mounting Screws**—

Steel, zinc plated

**4-40 Housing Screws & Hex Nuts**—

Steel, zinc plated

## Related Product Data:

**Connectors used with:**

**HDE All-Plastic**—pages 117 & 118

**HDE Metal-Shell**—pages 119 & 120

**HDP Metal-Shell**—pages 95-107


**Other accessory capabilities:**

**Spring Latches (Two Piece)**—  
page 157

## Technical Documents:

**Instruction Sheet**—408-7555

## Straight/90° Exit

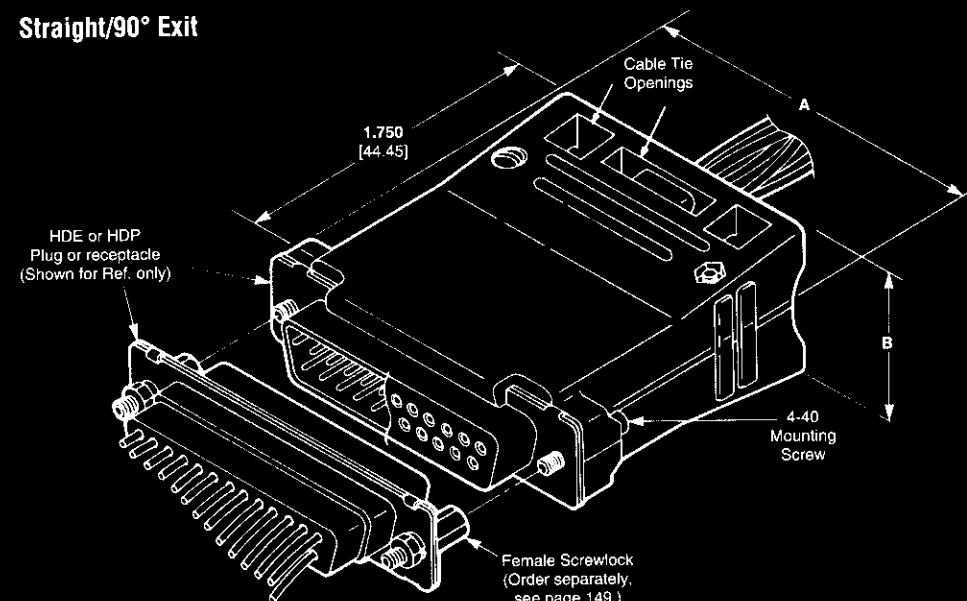

Shell Size	Dimensions		Cable Dia. (Max.)	Cable Clamp Kit No.	
	A	B		Individual	Bulk Packed*
2	1.550	.826	.350	206471-1	—
	39.37	20.98	8.89		
3	2.090	.826	.335	206472-1	—
	53.09	20.98	8.51		
4	2.738	.826	.460	745134-1	745134-2
	69.55	20.98	11.68		
5	2.644	.938	.675	745081-1	745081-2
	67.16	23.83	17.15		
			.775	745082-1	—
			19.69		

\*Each part is individually bulk packed for multiple assembly orders.

**Notes:** 1. All parts are packaged unassembled.

2. Straight or 90° cable exit is achieved by inserting AMP-TY Cable Ties through cable tie openings and clamping the cable to one housing half only.