


BNC Connectors

Plugs

Plating

Body — Nickel
Center Contact — Gold

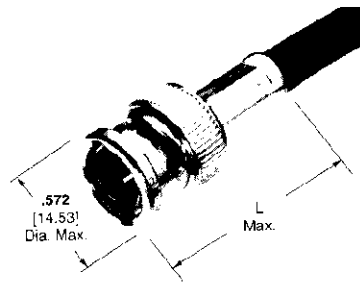


JIS Cable	Termination Type	Dielectric	Impedance	Part No.	Dim. L	Interchangeable Dies for PRO-CRIMPER Hand Tool 354940-1 or PRO-CRIMPER Adapter 678304-1
5C-2V	Hex Crimp	Polymethylpentene	75Ω	1-413589-2	1.160 29.45	58425-3
3C-2V	Hex Crimp	Polymethylpentene	75Ω	1-413589-1	1.160 29.45	58425-1
3C-2W	Hex Crimp	Polymethylpentene	75Ω	1-413589-4	1.160 29.45	58425-1
2.5C-2V	Hex Crimp	Polymethylpentene	75Ω	1-413589-6	1.160 29.46	58425-2
2.5C-2W	Hex Crimp	Polymethylpentene	75Ω	1-413589-5	1.160 29.46	58425-1
1.5C-2V	Hex Crimp	Polymethylpentene	75Ω	1-413589-3	1.160 29.46	58425-2
3D-2V	Hex Crimp	Polyethylene	50Ω	3-221128-1	1.320 33.53	58465-1
1.5D-2V	Hex Crimp	Polyethylene	50Ω	3-221128-2	1.320 33.53	58465-3

Bulkhead Jacks

Plating

Body — Nickel
Center Contact — Gold
Dielectric — Polymethylpentene

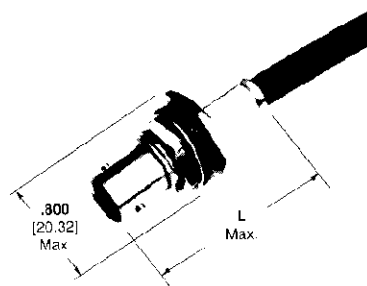

JIS Cable	Termination Type	Impedance	Part No.	Dim. L	Interchangeable Dies for PRO-CRIMPER Hand Tool 354940-1 or PRO-CRIMPER Adapter 678304-1
3C-2V	Hex Crimp	75Ω	1-413590-4*	1.450 36.83	58425-1
3C-2W	Hex Crimp	75Ω	1-413590-1*	1.450 36.83	58425-1
2.5C-2V	Hex Crimp	75Ω	1-413590-3	1.450 36.83	58425-2
2.5C-2W	Hex Crimp	75Ω	1-413590-2	1.450 36.83	58425-1
1.5C-2V	Hex Crimp	75Ω	1-413590-4**	1.450 36.83	58425-2

Note: All parts are packaged in 25 pieces per bag unless otherwise noted.
*Individually packaged.
**Packaged in 100 pieces per bag.

BNC Connectors