
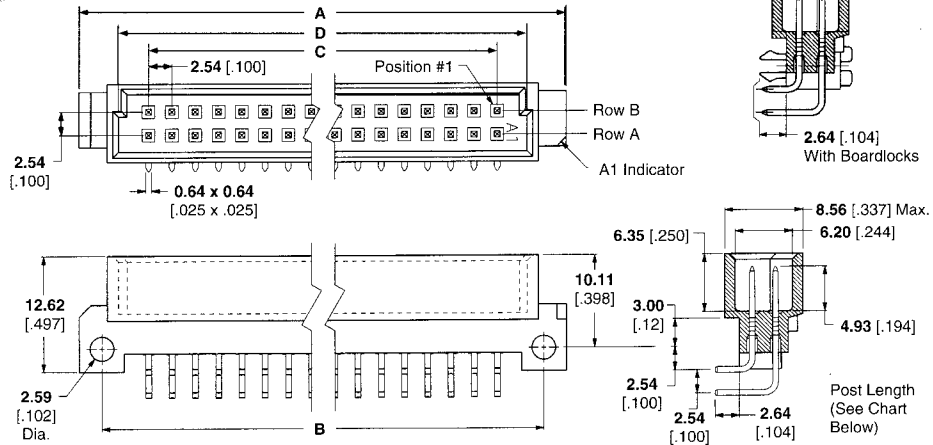


Type B Right Angle Pin Assemblies with Solder Posts

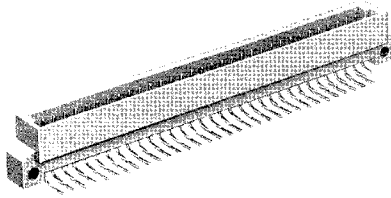

Material

Housing — Glass filled polymer
Contacts — Copper alloy

Related Product Data

- Common Bus Systems Application** — Page 4
- DIN Performance Levels** — Page 6
- Performance Specifications** — Page 7
- Mateable Connectors** — Pages 15, 16, 51
- PC Board Hole Layout** — Page 58
- Accessories** — Pages 68, 69
- Technical Documents** — Page 74:
DIN Specification 41612
IEC Specification 60603-2
Application Specification 114-9014
Instruction Sheet 408-6784

Standard Size

Number of Positions	Rows Loaded	Dimensions				Post Length	DIN Level	Part Number
		A	B	C	D			
64	A,B	93.98	88.90	78.74	85.29	2.64	II	536052-5
		3.700	3.500	3.100	3.358	.104		536385-5 ¹
						3.00	I	1393644-1
						.118		1393644-5 ¹
						3.30	II	536379-5
						.130		

¹ With Boardlocks

Half Size

Number of Positions	Rows Loaded	Dimensions				Post Length	DIN Level	Part Number
		A	B	C	D			
32	A,B	53.34	48.26	38.10	44.65	2.64	II	536053-5
		2.100	1.900	1.500	1.758	.104		536386-5 ¹
						3.00	I	1393644-3
						.118		

¹ With Boardlocks

Third Size

Number of Positions	Rows Loaded	Dimensions				Post Length	DIN Level	Part Number
		A	B	C	D			
20	A,B	38.12	33.02	22.86	33.12	3.00	II	5-1393644-6
		1.501	1.359	.900	1.304	.118		

Note: Select Load and MFBL available upon request, contact Tyco Electronics at the numbers listed below.

Type B Assemblies