

Accessories Miniature PCB Relay RYII

- Accessories for Miniature PCB Relay RYII, pinning 3.2 mm
- Socket with PCB terminals
- No reduction of protection class or creepage/clearance with plastic retainer
- Easy replacement of relays
- Socket can be used as connector for diagnosis function
- Sockets and accessories: RoHS compliant (Directive 2002/95/EC)
- Not suitable for MSR-type



F0125-A


Socket with PCB terminals

RY 78 600 pinning 3.2 mm

Approvals



Technical data	RY 78 600
Rated voltage / max. switching voltage AC	240 / 400 VAC
Rated current	12 A
Limiting continuous current	see derating curve
Dielectric strength coil-contact circuit	5000 V _{rms}
Clearance / creepage coil-contact circuit	≥ 8/8 mm
Material group of insulation parts	IIIa
Insulation to IEC 60664-1	
Type of insulation coil-contact circuit	reinforced
open contact circuit	functional
Rated insulation voltage	250 V
Pollution degree	2
Rated voltage system	230 / 400 V
Overvoltage category	III
RoHS - Directive 2002/95/EC	compliant
Ambient temperature range	-40...+80°C
Terminals	pcb
Insertion cycles	A (10)
Max. Insertion Force total	100 N
Mounting distance	≥ 0, dense packing
Resistance to soldering heat	270°C / 10 s
Weight	3 g
Packaging unit	100 pcs

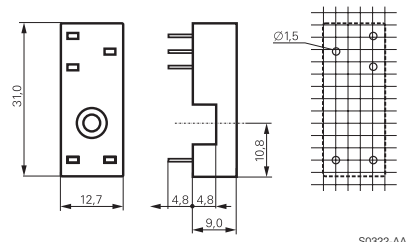


S0322-AA

Socket with PCB terminals

Type	Part Number
RY 78 600 Socket with PCB terminals, pinning 3.2 mm	7-1393161-3

Accessories for RY78600

RY 16 037 Plastic retaining clip	6-1393161-5
---	-------------

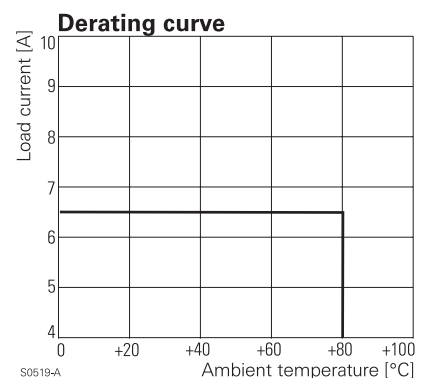

S0519-A