


## 353537 - 1 Product Details

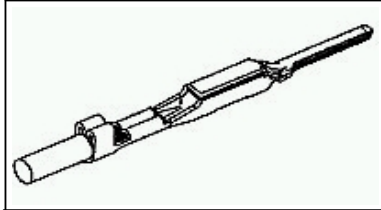

**353537 - 1**

TE Internal Number: 353537 - 1

 [Active](#)

### MULTILOCK Connectors and Contacts

[Always EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

#### Product Highlights:

- ? Contact
- ? Contact Gender = Tab
- ? Applies To Wire
- ? Wire/Cable Type = Discrete Wire
- ? Tab Width = 1.02 mm

[View all Features](#)

[Add to My Part List](#) | 
 [Request Sample](#) | 
 [Find Similar Products](#) | 
 [Buy Product](#)

### Have a Question?

Chat with a Product Information Specialist



#### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

#### Documentation & Additional Information

##### Product Drawings:

- ? [.040 III UNSEALED CONTACT, TAB \(S\)](#) (PDF, English)

##### Catalog Pages/Data Sheets:

- ? None Available

##### Product Specifications:

- ? [.040 III Series Multilock Connector \(MLC\) for Wi... \(1\)](#) (PDF, English)
- ? [.040 III Series Multilock Connector \(MLC\) for Wi... \(2\)](#) (PDF, English)

##### Application Specifications:

- ? [Crimping .040III Unsealed Contact, Tab \(1\)](#) (PDF, Japanese)
- ? [Crimping .040III Unsealed Contact, Tab \(2\)](#) (PDF, Japanese)

##### Instruction Sheets:

- ? None Available

##### CAD Files:

- ? None Available

##### Additional Information:

- ? [Product Line Information](#)

##### Related Products:

- ? [Tooling](#)

[List all Documents](#)

#### Product Features (Please use the Product Drawing for all design activity)

##### Product Type Features:

- ? [Product Type](#) = Contact
- ? Wire/Cable Type = Discrete Wire
- ? [Tab Width \(mm \[in\]\)](#) = 1.02 [0.04]
- ? Proprietary Name = MULTILOCK
- ? Product Series = 040 III

##### Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = AVSS, CAVS 0.30 - 0.50 ?

##### Contact Related Features:

- ? Contact Gender = Tab
- ? [Contact Base Material](#) = Brass
- ? [Contact Plating, Mating Area, Material](#) = Pre -Tin

##### Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

##### Conditions for Usage:

- ? [Applies To](#) = Wire
- ? [Insulation Diameter, Range \(mm \[in\]\)](#) = 1.50 - 1.78 [0.059 - 0.071]

##### Packaging Related Features:

- ? [Packaging Method](#) = Reel

##### Other:

- ? Brand = AMP

#### Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

#### Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

#### Customer Support

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

#### Sign up for our eNewsletter

Enter your email address

#### Follow Us On:

