


170108-4 Product Details

[Share](#) [Print](#) [Email](#)

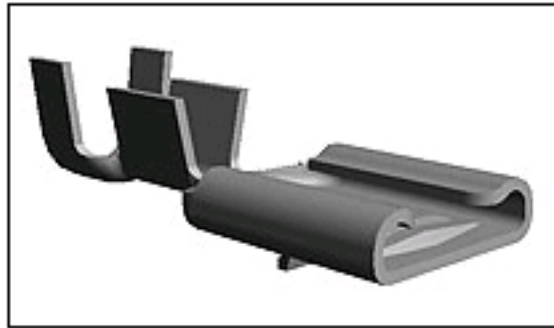

170108-4

TE Internal Number: 170108-4

Active

[View 3D PDF](#)

Multiple Circuit Housings with Tabs & Receptacles

Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

Product Highlights:

- Contact
- Contact Type = Receptacle
- Mating Area Interface Dimensions = 6.35 x 0.81 mm
- Wire Range = 0.80-2.00² [18-14] mm [AWG]
- Insulation Diameter = 3.10-4.10 [.122-.161] mm [in]

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [JAPANESE](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- [AMP DOUBLE ACTION HAND TOOL 720725-1 \(1\)](#) (PDF, Japanese)
- [AMP DOUBLE ACTION HAND TOOL 720725-1 \(2\)](#) (PDF, Japanese)

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version 0)
- [3D Model](#) (IGES, Version 0)
- [3D Model](#) (STEP, Version 0)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Contact
- [Mating Area Interface Dimensions \(mm \[in\]\)](#) = 6.35 x 0.81 [.250 x .032]
- [Insulation Diameter \(mm \[in\]\)](#) = 3.10-4.10 [.122-.161]
- [Receptacle Style](#) = Straight
- [Wire/Cable Type](#) = Regular Wire
- [Finish](#) = Tin
- [Material](#) = Brass
- [Insertion Force](#) = Normal
- [Insulation Support](#) = With
- [Crimp Type](#) = F-Crimp
- FASTON = Yes
- For Housing Type = Multiple

Body Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.80-2.00² [18-14]
- Stock Thickness (mm [in]) = 0.81 [0.032]

Contact Features:

- Contact Type = Receptacle

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Features:

- [Packaging Method](#) = Loose Piece

Other:

- Line = FASTIN-FASTON .250
- Brand = AMP

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference Products](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

