


171111-1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

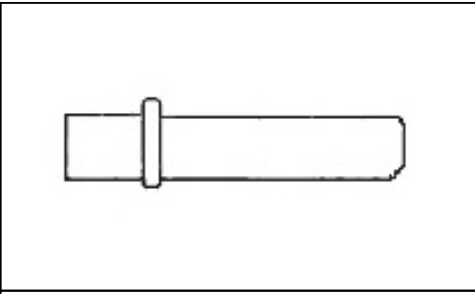

171111-1

✓ [Active](#)

Pins and Receptacles

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Housing
- Number of Positions = 1
- Wire/Cable Type = Regular Wire
- Noryl SE 100J Material
- None Finish

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [1-Position Pin Receptacle Housing For 2.36 Pin Contact](#) (TIF, Japanese)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [No title](#) (PDF, English)
- [PRODUCT SPECIFICATION 2.360 PIN RECEPTACLE FOR MULTI...](#) (PDF, English)
- [JAPANESEE](#) (PDF, English)

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version C)
- [3D Model](#) (IGES, Version C)
- [3D Model](#) (STEP, Version C)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Housing
- Number of Positions = 1
- [Wire/Cable Type](#) = Regular Wire
- Material = Noryl SE 100J
- Finish = None
- Gender = Receptacle
- Color = Gray

Termination Related Features:

- Height (mm [in]) = 7.20 [0.283]

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = AMP