


1734260 -2 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

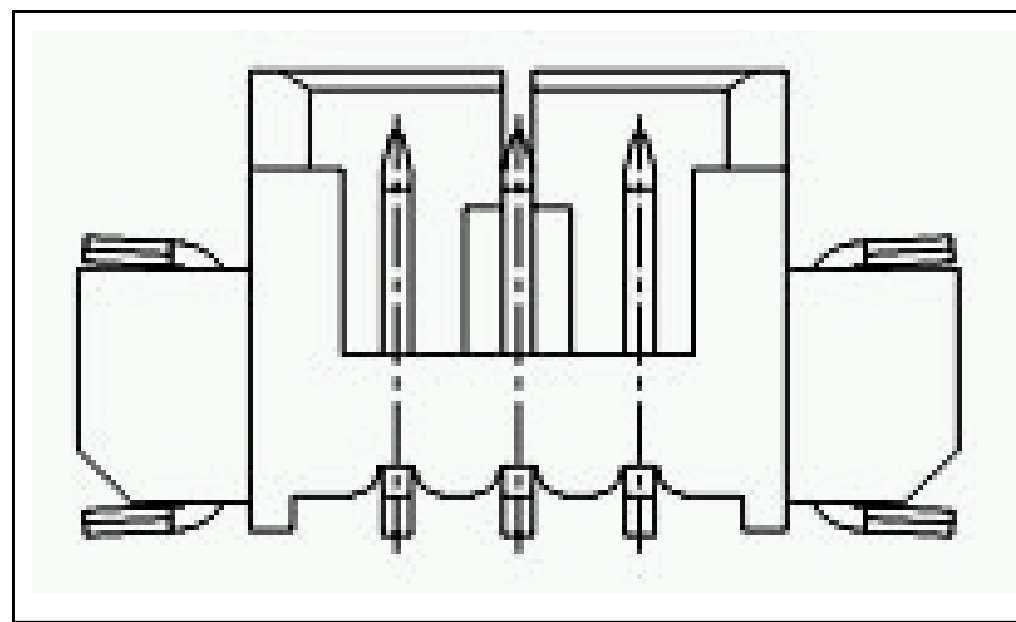

1734260 -2

✓ [Active](#)

High Performance Interconnects (HPI)

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? 1.25 mm Centerline
- ? Header
- ? Number of Positions = 2
- ? Housing Color = Natural
- ? Vertical Mount Angle

[View all Features](#) | [Find Similar Products](#) **NEW!**

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [View Mating Products \(1\)](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [WIRE TO BOARD MALE HEADER, 1.25MM PITCH, SMT STRAIGH...](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)
- ? [Mating Products \(1\)](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Header
- ? [Number of Positions](#) = 2
- ? [Mount Angle](#) = Vertical

Body Related Features:

- ? [Centerline \(mm \[in\]\)](#) = 1.25 [0.049]
- ? [Mount Style](#) = Surface Mount
- ? [Number of Rows](#) = Single
- ? Post Material = Phosphor Bronze
- ? Post Plating = Tin over Nickel

Contact Related Features:

- ? Contact Material = Phosphor Bronze
- ? Contact Finish = Tin over Nickel

Housing Related Features:

- ? [Housing Color](#) = Natural
- ? Housing Flammability Rating = UL 94V -0
- ? Housing Material = Thermoplastic High Temperature

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Reflow solder capable to 245°C, Reflow solder capable to 260°C
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? Packaging Method = 24mm Tape & Reel
- ? Packaging Quantity = 1,000/Reel

Other:

- ? Brand = AMP