


184068-1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

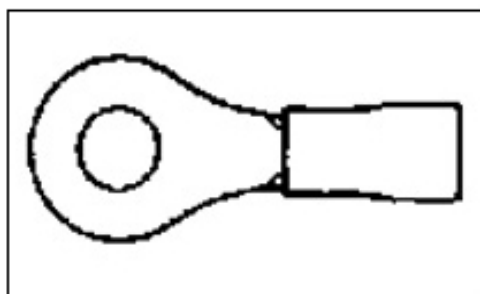

184068-1

TE Part Number: 184068-1

✓ [Active](#)

[Add to Part List](#)

Ring and Spade Tongue Terminals

Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

Product Highlights:

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = SOLISTRAND
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [TERMINAL, RING TONGUE,SOLISTRAND ZTM](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- [Body Style](#) = SOLISTRAND
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = No
- [Insulation Support](#) = Non-Insulation Support
- Stud Size = 10 mm
- [Stud Diameter \(mm \[in\]\)](#) = 10.50 [0.413]
- [Shape](#) = RING-054
- [Heavy Duty](#) = No
- [Material](#) = Copper
- [Finish](#) = Tin

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 34.00-35.00² [2]
- Wire Range (CMA) = 52,600 - 83,700

Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Strip

Other:

- Brand = AMP