


## 280000-6 Product Details

 [Live Product Chat](#)

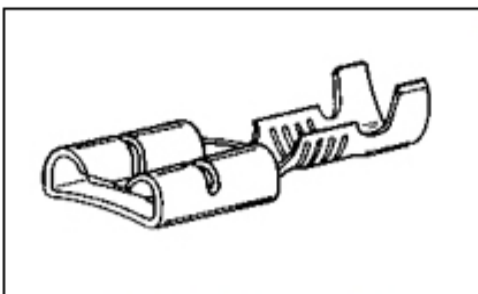

### 280000-6

TE Part Number: 280000-6

 [Active](#)

 [Add to Part List](#)

## FASTON Uninsulated Receptacles & Housings

 [Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

### Product Highlights:

- Receptacle
- Tab Fit = 6.35 x 0.81 mm
- Board Mount = No
- Receptacle Style = Straight
- Insulation Support

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

## Documentation & Additional Information

### Product Drawings:

- None Available

### Catalog Pages/Data Sheets:

- None Available

### Product Specifications:

- None Available

### Application Specifications:

- None Available

### Instruction Sheets:

- None Available

### CAD Files:

- None Available

### Additional Information:

- [Product Line Information](#)

### Related Products:

- [Tooling](#)

## Product Features (Please use the Product Drawing for all design activity)

### Product Type Features:

- [Product Type](#) = Receptacle
- [Tab Fit \(mm \[in\]\)](#) = 6.35 x 0.81 [.250 x .032]
- [Receptacle Style](#) = Straight
- [Insulation Support](#) = Insulation Support
- [Wire/Cable Type](#) = Stranded
- [Insulation Diameter \(mm \[in\]\)](#) = 2.30-3.30 [.091-.129]
- [Insertion Force](#) = Low
- [Material](#) = Brass
- [Finish](#) = Tin
- [Crimp Type](#) = F-Crimp
- CSA Certified = Yes

### Mechanical Attachment:

- [Board Mount](#) = No

### Body Related Features:

- [Weld Tab](#) = Without
- [Wire Range \(mm \[AWG\]\)](#) = 0.30-0.90<sup>2</sup> [22-18]
- UL Rating = Listed

### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

### Packaging Related Features:

- [Packaging Method](#) = Strip

### Other:

- [For Hermetic Header Tab](#) = No
- [Line](#) = FASTON .250
- Brand = AMP