


## 282109-3 Product Details

**Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

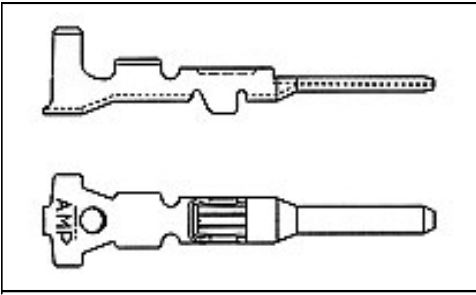

**282109-3**

[Active](#)

### Superseal 1.5 Series

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

#### Product Highlights:

- Contact
- Contact Type = Tab
- Wire Range = 0.75-1.50<sup>2</sup> [18.5-15.5] mm [AWG]
- Wire Insulation Diameter = 1.80 - 3.30 mm
- Strip

[View all Features](#) | [Find Similar Products](#)

#### Quick Links

[Check Pricing & Availability](#)  
[Search for Tooling](#)  
[Product Feature Selector](#)  
[Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [Mini MIC srs. tab etc.](#) (TIF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- [ET\\*\\*AMP Superseal 1,5 SRS Connectors](#) (PDF, English)

#### Application Specifications:

- [APPLICATION SPEC. FOR MINI MIC CONTACTS WITH SINGLE ...](#) (PDF, English)

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Contact
- [Wire Insulation Diameter \(mm \[in\]\)](#) = 1.80 - 3.30 [0.071 - 0.130]
- Product Line = Super Seal

#### Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.75-1.50<sup>2</sup> [18.5-15.5]

#### Contact Related Features:

- Contact Type = Tab
- [Contact Material](#) = Brass
- Contact Mating Area Plating = .8 µm Gold

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- [Packaging Method](#) = Strip
- Packaging Quantity = 4,000

#### Other:

- Brand = AMP