


350560 - 1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

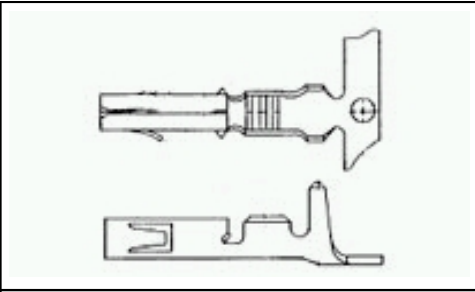

350560 - 1

Active

[View 3D PDF](#)

.200" Centerline, 250 V, 13 A max.

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Contact
- ? Contact Diameter = 2.07 mm
- ? Loose Piece
- ? Contact Type = Socket
- ? Wire Range = 0.20 - 0.80 ² [24 - 18] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [View Housings \(70\)](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [SOCKET, MATE-N-LOK, DUAL LANCE](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? [MATE-N-LOK Dual Lance Pin And Socket Contacts](#) (PDF, English)

Instruction Sheets:

- ? None Available

CAD Files: ([CAD Format & Compression Information](#))

- ? [2D Drawing](#) (DXF, Version H)
- ? [3D Model](#) (IGES, Version H)
- ? [3D Model](#) (STEP, Version H)

[List all Documents](#)

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)
- ? [Housings \(70\)](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? Product Type = Contact
- ? Wire Insulation Diameter (mm [in]) = 2.54 [0.100]
- ? Connector Line = Commercial MATE -N-LOK
- ? Comment = Dual Lance.

Electrical Characteristics:

- ? Voltage (VAC) = 250
- ? Current Rating (Amps.) = 13

Termination Related Features:

- ? Solder Tail Contact Plating = Pre -Tin

Body Related Features:

- ? Contact Diameter (mm [in]) = 2.07 [0.081]
- ? Wire Range (mm [AWG]) = 0.20 - 0.80 ² [24 - 18]

Contact Related Features:

- ? Contact Type = Socket
- ? Contact Material = Brass

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? Packaging Method = Loose Piece

Other:

- ? Brand = AMP