


## 5100161-9 Product Details

Live Product Chat

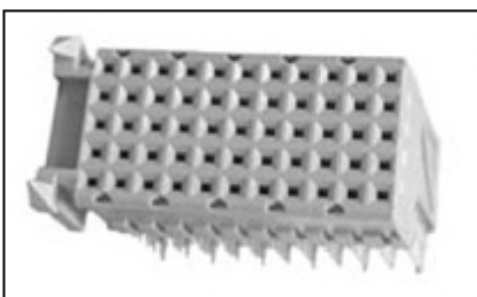

**5100161-9**

TE Part Number: 5100161-9

Active

Add to Part List

### 2mm Hard Metric PCB Mount Connectors (Z-PACK 2mm HM)

Always EU RoHS/ELV Compliant (Statement of Compliance)

#### Product Highlights:

- Connector
- Connector Type = Type C
- Receptacle
- Interface Type = 2mm HM
- Contact Type = ACTION PIN Post, Signal

[View all Features](#) | [Find Similar Products](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [Z-PACK 2mm HM TYPE C 55 POS. FEMALE CONNECTOR](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- [Z-Pack 2 mm HM CONNECTORS](#) (PDF, English)

#### Application Specifications:

- [Z-PACK 2mm HM Interconnection System for Board-to-Bo...](#) (PDF, English)

#### Instruction Sheets:

- None Available

#### CAD Files: (CAD Format & Compression Information)

- [2D Drawing](#) (DXF, Version B)
- [3D Model](#) (IGES, Version B)
- [3D Model](#) (STEP, Version B)

[List all Documents](#)

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Connector
- [Connector Type](#) = Type C
- [Gender](#) = Receptacle
- [Number of Positions](#) = 55
- [PCB Mount Angle](#) = Right Angle
- [Mating Polarization](#) = With
- [Mating Polarization Method](#) = Guide Lugs
- [Shielded](#) = No
- Comment = Connector lubricated with Bellcore approved lubricant.; Connector tested and qualified against Bellcore Quality Level III, Central Office Applications.

#### Mechanical Attachment:

- [Board Mount](#) = Free Board
- [Module Length \(mm \[in\]\)](#) = 25.00 [0.984]
- [Crosstalk Version](#) = Standard
- AMP Standard Option Number = 1

#### Termination Related Features:

- [Interface Type](#) = 2mm HM
- Termination End Plating = Tin over Nickel

#### Body Related Features:

- [Number of Rows](#) = 5
- [Grounding Contact](#) = Without
- Rows Loaded = A, E, B, C, D

#### Contact Related Features:

- Contact Type = ACTION PIN Post, Signal
- [Feedthrough Post Length \(mm \[in\]\)](#) = 3.71 [0.146]
- [CompactPCI](#) = No
- [Contact Mating Area Plating Material](#) = Gold (30) over Nickel (50)
- Contact Style = Short Tail
- Contact Material = Phosphor Bronze

#### Housing Related Features:

- Housing Material = Polyester GF
- Housing Color = Gray
- Housing Flammability Rating = UL 94V-0

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- Packaging Quantity = 22

#### Other:

- Brand = AMP