


## 5-160321-2 Product Details

[Live Product Chat](#)

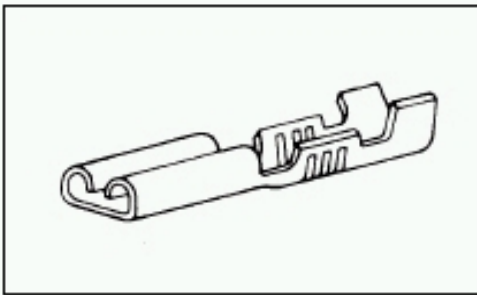

### 5-160321-2

TE Part Number: 5-160321-2

[Active](#)

[Add to Part List](#)

## FASTON Uninsulated Receptacles & Housings

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

### Product Highlights:

- Receptacle
- Tab Fit = 2.79 x 0.79 mm
- Board Mount = No
- Receptacle Style = Straight
- Insulation Support

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

## Documentation & Additional Information

### Product Drawings:

- None Available

### Catalog Pages/Data Sheets:

- None Available

### Product Specifications:

- None Available

### Application Specifications:

- None Available

### Instruction Sheets:

- None Available

### CAD Files:

- None Available

### Additional Information:

- [Product Line Information](#)

### Related Products:

- [Tooling](#)

## Product Features (Please use the Product Drawing for all design activity)

### Product Type Features:

- [Product Type](#) = Receptacle
- [Tab Fit \(mm \[in\]\)](#) = 2.79 x 0.79 [.110 x .031]
- [Receptacle Style](#) = Straight
- [Insulation Support](#) = Insulation Support
- [Wire/Cable Type](#) = Regular Wire
- [Insulation Diameter \(mm \[in\]\)](#) = 1.30-2.00 [.051-.079]
- [Insertion Force](#) = Normal
- [Material](#) = Brass
- [Finish](#) = Tin
- [Crimp Type](#) = F-Crimp
- CSA Certified = Yes
- Comment = Chamfered

### Mechanical Attachment:

- [Board Mount](#) = No

### Body Related Features:

- [Weld Tab](#) = Without
- [Wire Range \(mm \[AWG\]\)](#) = 0.30-0.60<sup>2</sup> [22-20]
- UL Rating = Listed

### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

### Packaging Related Features:

- [Packaging Method](#) = Loose Piece
- Packaging Quantity = 10,000

### Other:

- [For Hermetic Header Tab](#) = No
- [Line](#) = Commercial
- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)