


53440-1 Product Details

[Live Product Chat](#)

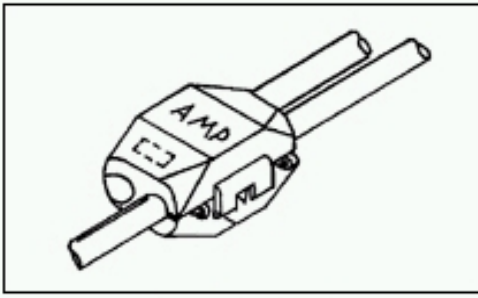

53440-1

TE Part Number: 53440-1

[Active](#)

[Add to Part List](#)

ELECTRO-TAP Cable Connector/Splice

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Cable Connector/Splice
- Wire Range = 0.80-2.00² [18-14] mm [AWG]
- 1 Tap Wires
- Tap Wire Range = .80 - 2.00 mm²

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [ELECTRO-TAP](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- [ELECTRO-TAP Connectors](#) (PDF, English)

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version M)
- [3D Model](#) (IGES, Version M)
- [3D Model](#) (STEP, Version M)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Cable Connector/Splice
- Insulation Diameter (mm [in]) = 4.00 [.157] Max.

Electrical Characteristics:

- Number of Tap Wires = 1

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.80-2.00² [18-14]
- [Tap Wire Range \(mm²\)](#) = 0.80 - 2.00

Contact Related Features:

- Contact Material = Brass
- Contact Mating Area Plating Material = Tin

Housing Related Features:

- Housing Color = Blue
- Housing Material = Nylon

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- Packaging Quantity = 1,000

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)