


## 5353928-1 Product Details

 **Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

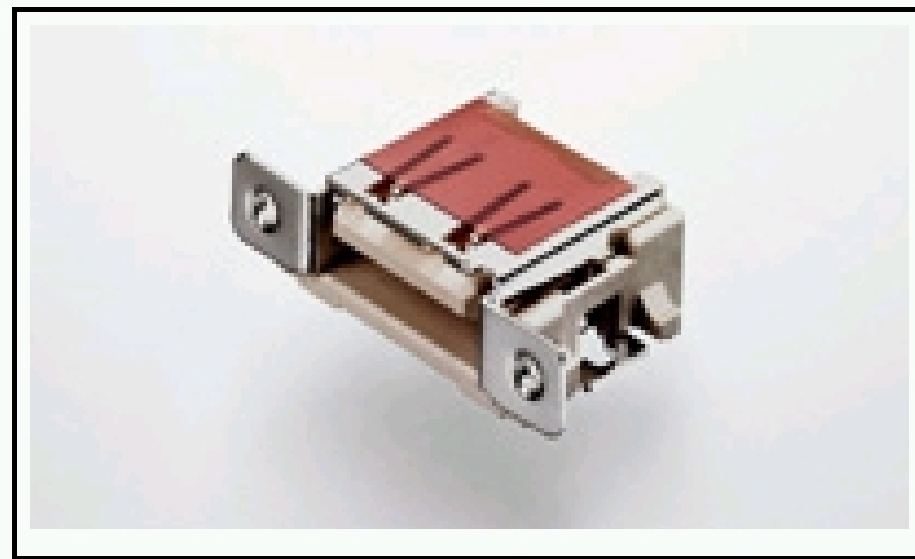

**5353928-1**

TE Part Number: 5353928-1

 **Active**

 [Add to Part List](#)

### Universal Serial Bus (USB) Connectors

 Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

#### Product Highlights:

- Connector
- Size = Standard
- A Series
- Receptacle
- Without Locking Feature

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- [EMBOSS ASSY REVERSE TYPE USB CONN. REC. WITH COVER...](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version 0)
- [3D Model](#) (IGES, Version 0)
- [3D Model](#) (STEP, Version 0)

[List all Documents](#)

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Product Type = Connector
- Size = Standard
- Gender = Receptacle
- Number of Ports = 1
- Orientation = Right Angle
- Number of Positions = 4

#### Mechanical Attachment:

- Mount Location = Bottom

#### Electrical Characteristics:

- Panel Ground Type = M2 Threaded Hole

#### Termination Related Features:

- Termination Method = Solder to PC Board

#### Body Related Features:

- [Series](#) = A
- Locking Feature = Without
- [Panel Ground](#) = With
- PCB Retention Method = SMT Hold Down
- Shell Plating = Bright Tin over Nickel
- Pick and Place Cover = With
- Locating Posts = With

#### Contact Related Features:

- Contact Termination Type = Surface Mount
- [Contact Mating Area Plating Material](#) = Gold Flash over Palladium Nickel
- Contact Mating Area Plating Thickness = 30 Microinches

#### Housing Related Features:

- [Housing Color](#) = White

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Reflow solder capable to 245°C, Reflow solder capable to 260°C
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Conditions for Usage:

- Terminate To = Printed Circuit Board

#### Packaging Related Features:

- Panel Ground Location = Right/Left
- [Packaging Method](#) = Tape & Reel

#### Other:

- Brand = AMP