




Search bar: What can we help you find?

### 557571-3 Product Details

Share | Print | Email

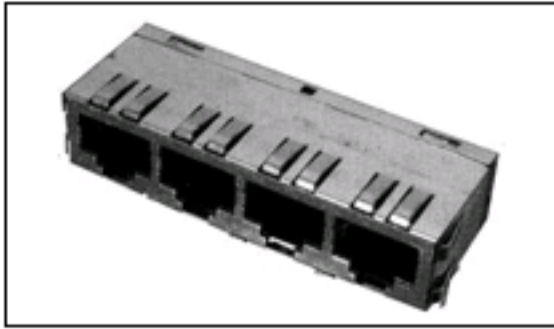

557571-3

#### PCB Mounted Jacks - Single Port, Multi-port and Stacked

Not reviewed for RoHS Compliance

##### Product Highlights:

- Connector
- Preloaded
- Multiple Port Configuration
- 1 x 4 Jack Configuration
- Jack Type = RJ45

[View all Features](#)

##### Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

TE Internal Number: 557571-3



[Add to My Part List](#) | [Request Sample](#) | [Find Similar Products](#) | [Buy Product](#)

Contact Product Information Center

Documentation & Additional Information	
<p><b>Product Drawings:</b></p> <ul style="list-style-type: none"> <li>• None Available</li> </ul> <p><b>Catalog Pages/Data Sheets:</b></p> <ul style="list-style-type: none"> <li>• None Available</li> </ul> <p><b>Product Specifications:</b></p> <ul style="list-style-type: none"> <li>• None Available</li> </ul> <p><b>Application Specifications:</b></p> <ul style="list-style-type: none"> <li>• <a href="#">Modular Jacks</a> (PDF, English)</li> </ul> <p><b>Instruction Sheets:</b></p> <ul style="list-style-type: none"> <li>• None Available</li> </ul> <p><b>CAD Files:</b></p> <ul style="list-style-type: none"> <li>• None Available</li> </ul>	<p><b>Additional Information:</b></p> <ul style="list-style-type: none"> <li>• <a href="#">Product Line Information</a></li> </ul> <p><b>Related Products:</b></p> <ul style="list-style-type: none"> <li>• <a href="#">Tooling</a></li> </ul>

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)	
<p><b>Product Type Features:</b></p> <ul style="list-style-type: none"> <li>• Product Type = Connector</li> <li>• Jack Type = RJ45</li> <li>• PCB Mounting Orientation = Side Entry (Right Angle)</li> <li>• PCB Mount Style = Through Hole</li> <li>• Termination Method to PC Board = Solder</li> <li>• Performance Category = Cat 4</li> <li>• LED = Without</li> <li>• Grounding Options = PCB Ground</li> <li>• Panel Stops = Without</li> <li>• Keyed = No</li> <li>• Profile = Standard</li> <li>• Color = Black</li> <li>• Shield Material = Copper Zinc Alloy</li> </ul> <p><b>Mechanical Attachment:</b></p> <ul style="list-style-type: none"> <li>• Panel Mount Retention = Without</li> </ul> <p><b>Electrical Characteristics:</b></p> <ul style="list-style-type: none"> <li>• Shielded = Yes</li> </ul> <p><b>Termination Features:</b></p> <ul style="list-style-type: none"> <li>• Solder Tail Contact Plating = Tin-Lead over Nickel</li> </ul> <p><b>Dimensions:</b></p> <ul style="list-style-type: none"> <li>• PCB Tail Length (mm [in]) = 3.56 [0.140]</li> </ul> <p><b>Body Features:</b></p> <ul style="list-style-type: none"> <li>• Inverted Jack Face = No</li> <li>• Shield Plating = Bright Tin</li> <li>• Number of Contacts Loaded, RJ45 (8 Positions) = 8</li> <li>• PCB Ground Tab Location (mm [in]) = 4.57 [0.180]</li> </ul>	<p><b>Contact Features:</b></p> <ul style="list-style-type: none"> <li>• Contact Plating, Mating Area, Material = Gold (50)</li> <li>• Contact Base Material = Phosphor Bronze</li> </ul> <p><b>Housing Features:</b></p> <ul style="list-style-type: none"> <li>• Housing Material = PCT GF</li> <li>• UL Flammability Rating = UL 94V-0</li> </ul> <p><b>Configuration Features:</b></p> <ul style="list-style-type: none"> <li>• Preloaded = Yes</li> <li>• Port Configuration = Multiple</li> <li>• Jack Configuration = 1 x 4</li> <li>• Number of Positions = 8</li> <li>• Number of Contacts Loaded = 8</li> <li>• Number of PCB Ground Tabs = 5</li> </ul> <p><b>Industry Standards:</b></p> <ul style="list-style-type: none"> <li>• RoHS/ELV Compliance = Not reviewed for ELV/RoHS compliance</li> <li>• Lead Free Solder Processes = Not reviewed for lead free solder process</li> </ul> <p><b>Packaging Features:</b></p> <ul style="list-style-type: none"> <li>• Packaging Method = Tray</li> <li>• Packaging Quantity = 20</li> </ul> <p><b>Product Availability:</b></p> <ul style="list-style-type: none"> <li>• Region = Asia, North America</li> </ul> <p><b>Other:</b></p> <ul style="list-style-type: none"> <li>• Brand = AMP</li> </ul>

#### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

#### Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

#### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

#### Keep Me Informed

