


5746881 - 2 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

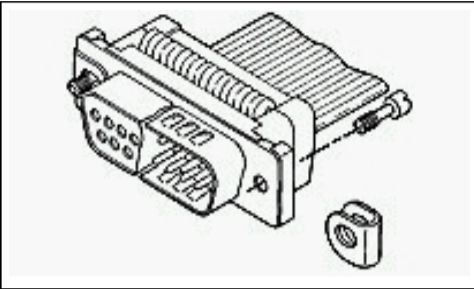

5746881 - 2

✓ [Active](#)

Hardware (AMPLIMITE)

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Male Screw Retainers
- ? Thread Size = 4 -40
- ? Clear Chromate Screw Finish
- ? Bulk

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [SCREW RETAINER KIT, .135 FLANGE, LOW PROFILE, AMPLIM...](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? [Female Screwlock Kits and Male Screw Retainer Kits](#) (PDF, English)

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Male Screw Retainers
- ? [Thread Size](#) = 4 -40
- ? Screw Material = Steel
- ? Retainer Clip Material = Stainless Steel
- ? For Use With = Metal Shell and All Plastic Connectors (HDF)
- ? Comment = Each part is individually bulk packed for multiple kit orders.

Mechanical Attachment:

- ? Screw Plating = Zinc

Termination Related Features:

- ? [Screw Finish](#) = Clear Chromate

Industry Standards:

- ? Government/Industry Qualification = No
- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Packaging Method](#) = Bulk

Other:

- ? Brand = AMP