


626437 -1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

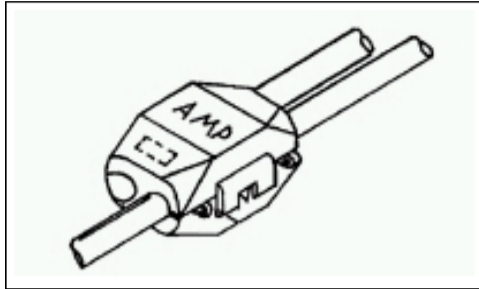

626437 -1

[Active](#)

ELECTRO - TAP Cable Connector/Splice

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Cable Connector/Splice
- ? Wire Range = 1.00 - 2.50² [17-13.5] mm [AWG]
- ? 1 Tap Wires
- ? Tap Wire Range = 1.00 - 2.50 mm²

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [Electro Tap Assy](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? Product Type = Cable Connector/Splice
- ? Insulation Diameter (mm [in]) = 4.00 [.157] Max.

Electrical Characteristics:

- ? Number of Tap Wires = 1

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 1.00 - 2.50² [17-13.5]
- ? [Tap Wire Range \(mm²\)](#) = 1.00 - 2.50

Contact Related Features:

- ? Contact Material = Brass
- ? Contact Mating Area Plating Material = Tin

Housing Related Features:

- ? Housing Color = Blue
- ? Housing Material = Nylon 66

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not reviewed for lead free solder process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- ? Brand = AMP