


## 62811-1 Product Details

 [Live Product Chat](#)

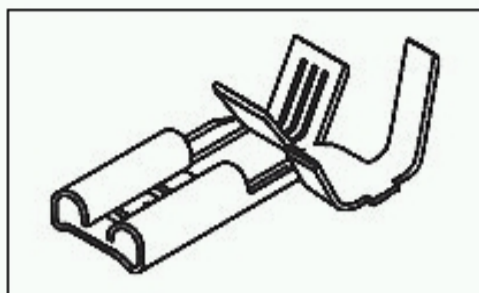

**62811-1**

TE Part Number: 62811-1

 [Active](#)

 [Add to Part List](#)

### FASTON Uninsulated Receptacles & Housings

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Receptacle
- Tab Fit = 6.35 x 0.81 mm
- Board Mount = No
- Receptacle Style = Flag
- Insulation Support

[View all Features](#) | [Find Similar Products](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- [250 series premier flag faston receptacle](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- [FASTON Flag Receptacles With "F"-Crimp Feature](#) (PDF, English)

#### Instruction Sheets:

- None Available

#### CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version H)
- [3D Model](#) (IGES, Version H)
- [3D Model](#) (STEP, Version H)

[List all Documents](#)

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Receptacle
- [Tab Fit \(mm \[in\]\)](#) = 6.35 x 0.81 [.250 x .032]
- [Receptacle Style](#) = Flag
- [Insulation Support](#) = Insulation Support
- [Wire/Cable Type](#) = Stranded
- [Insulation Diameter \(mm \[in\]\)](#) = 2.79-4.06 [.110-.160]
- [Insertion Force](#) = Normal
- [Material](#) = Brass
- [Finish](#) = None
- [Crimp Type](#) = F-Crimp

#### Mechanical Attachment:

- [Board Mount](#) = No

#### Body Related Features:

- [Weld Tab](#) = Without
- [Wire Range \(mm \[AWG\]\)](#) = 0.80-2.00<sup>2</sup> [18-14]
- [Stock Thickness \(mm \[in\]\)](#) = 0.51 [0.020]

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

#### Packaging Related Features:

- [Packaging Method](#) = Strip

#### Other:

- [For Hermetic Header Tab](#) = No
- [Line](#) = Premier
- [Brand](#) = AMP

 [Provide Website Feedback](#) | [Need Help?](#)