


63625 -1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

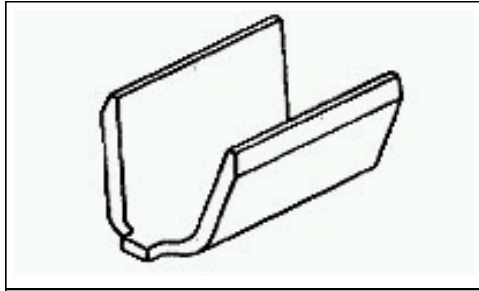

63625 -1

✓ [Active](#)

Splices - Open Barrel

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Splice
- ? Non - Insulation Support
- ? Wire/Cable Type = Regular Wire
- ? Wire Range = 5000 - 16000 CMA
- ? Without Serrations

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [SPLICE](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? [Open Barrel Pigtail and Thru Splices](#) (PDF, English)

Instruction Sheets:

- ? None Available

CAD Files: ([CAD Format & Compression Information](#))

- ? [2D Drawing](#) (DXF, Version C)
- ? [3D Model](#) (IGES, Version C)
- ? [3D Model](#) (STEP, Version C)

[List all Documents](#)

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Splice
- ? [Insulation Support](#) = Non - Insulation Support
- ? [Wire/Cable Type](#) = Regular Wire
- ? [Serrations](#) = Without Serrations
- ? [Splicing Type](#) = Thru
- ? [Strip Type](#) = Side Feed
- ? [Material](#) = Brass
- ? Finish = None

Body Related Features:

- ? [Wire Range \(CMA\)](#) = 5,000 - 16,000
- ? [Stock Thickness \(mm \[in\]\)](#) = 0.64 [0.025]

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? Packaging Method = Strip

Other:

- ? Brand = AMP