


## 796381-1 Product Details

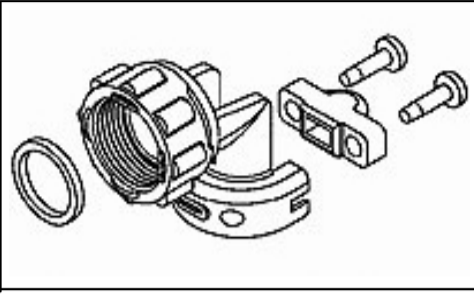

**796381-1**

✓ [Active](#)

### CPC Accessories

[Not EU RoHS or ELV Compliant \(Find RoHS Compliant Alternates\)](#)

#### Product Highlights:

- Cable Clamp
- Shell Size = 17
- Body Style = Right Angle
- Cable Diameter (Max.) = 11.51 mm
- Nylon Cable Clamp Material

[View all Features](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [CABLE CLAMP KIT, UNASSEMBLED, RIGHT ANGLE, SIZE 17, CPC](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- [CIRCULAR CONNECTORS FOR COMMERCIAL SIGNAL AND POWER ...](#) (PDF, English)

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files: [\(CAD Format & Compression Information\)](#)

- [3D Model](#) (STEP, Version A1)
- [3D Model](#) (IGES, Version A1)
- [2D Drawing](#) (DXF, Version A1)

[List all Documents](#)

#### Additional Information:

- [Product Line Information](#)

#### Additional Product Images:

- [Product Usage](#)
- [Product Usage](#)
- [Product Usage](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Cable Clamp
- [Shell Size](#) = 17
- [Body Style](#) = Right Angle
- Screw Size = 5-20 Self-Tapping

#### Body Related Features:

- [Cable Diameter \(Max.\) \(mm \[in\]\)](#) = 11.51 [0.453]
- [Cable Clamp Material](#) = Nylon
- [Cover](#) = Without
- Cable Clamp Color = Black
- Cable Clamp Flammability Rating = UL94V-0

#### Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

#### Packaging Related Features:

- [Packaging Method](#) = Individual

#### Other:

- Brand = AMP