


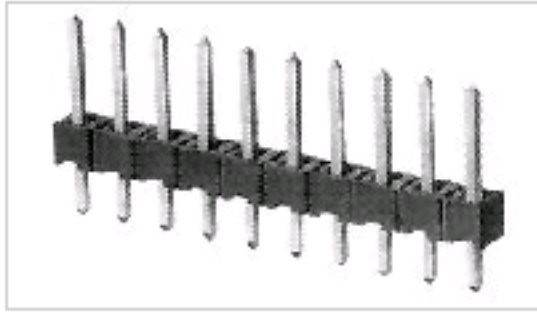

825433-8 Product Details

[Share](#) | [Print](#) | [Email](#)


.100 inch AMPMODU Headers

MOD 2 PINHDR 1X8 P.

825433-8

TE Internal Number: 825433-8

Active

[View 3D PDF](#)

Product Highlights [View All](#)

- Connector
- Header Type = Standard
- 8 Positions
- Mating Post Length = 6.70 mm
- Row-to-Row Spacing = 2.54 mm

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

Documents

Features

Compliance

Please Note:

Use the Product Drawing for all design activity

Product Type Features	
Product Type	Connector
Mount Angle [?]	Vertical
PCB Mount Retention [?]	Without
Board Standoff [?]	Without
Mating Connector Lock [?]	Without
Post Size (mm [in])	0.64 [.025]
Profile	Standard
Mechanical Attachment	
Mounting Ears [?]	Without
Panel Mount Retention [?]	Without
Termination Features	
Termination Post Length (mm [in]) [?]	3.20 [0.1259]
Dimensions	
Mating Post Length (mm [in])	6.70 [0.264]
Body Features	
Header Type	Standard
Row-to-Row Spacing (mm [in])	2.54 [0.100]
Selectively Loaded [?]	No
Mount Type [?]	Printed Circuit Board
Contact Features	
Contact Plating, Mating Area, Material [?]	Gold (30)
Solder Tail Contact Plating	Tin
Contact Shape	Square
Contact Base Material	Phosphor Bronze

Housing Features	
Housing Material	Polyester - GF
Configuration Features	
Number of Positions [?]	8
Number of Rows [?]	1
Surface Mount Compatible [?]	No
Industry Standards	
RoHS/ELV Compliance [?]	RoHS compliant, ELV compliant
Lead Free Solder Processes [?]	Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
RoHS/ELV Compliance History	Always was RoHS compliant
UL Flammability Rating	UL 94V-0
Conditions for Usage	
High Temperature Housing [?]	No
Operation/Application	
High Speed Serial Data Connector [?]	No
Packaging Features	
Packaging Quantity	500
Other	
Brand	AMP

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

