


## 827914-1 Product Details

[Live Product Chat](#)

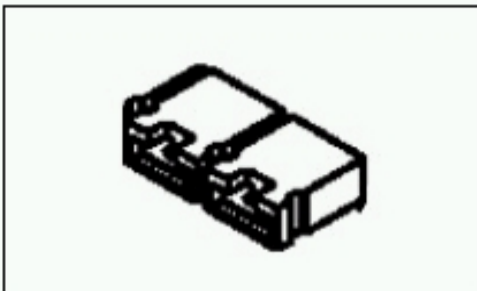

### 827914-1

TE Part Number: 827914-1

[Active](#)

[Add to Part List](#)

### Post Shunts

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Shunt Type = Mod. IV
- Number of Positions = 2
- 2.54 mm Centerline
- Gold (16) over Nickel (50) Contact Mating Area Plating Material
- Shunt Style = Open Top

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- None Available

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- [AMP Novo Shunt Connector](#) (PDF, English)

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Shunt Type = Mod. IV
- [Number of Positions](#) = 2
- [Shunt Style](#) = Open Top
- CSA Certified = Yes
- Comment = Loose piece of 142270-1

#### Termination Related Features:

- Height (mm [in]) = 6.00 [0.236]

#### Body Related Features:

- [Centerline \(mm \[in\]\)](#) = 2.54 [0.100]
- Handle = Without
- UL Rating = Recognized

#### Contact Related Features:

- Contact Mating Area Plating Material = Gold (16) over Nickel (50)
- Contact Material = Beryllium Copper

#### Housing Related Features:

- Housing Color = Green
- Housing Material = Polyester GF
- Housing Flammability Rating = UL 94V-0

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- Packaging Method = Loose Piece

#### Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)