


829261-6 Product Details

[Share](#) [Print](#) [Email](#)

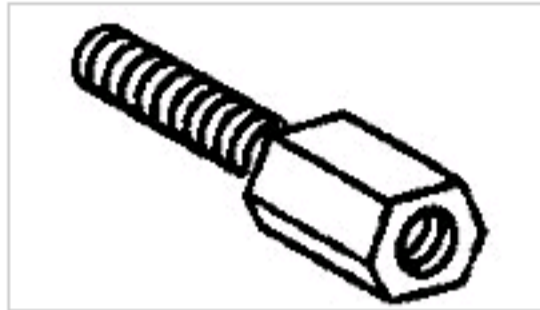

Hardware (AMPLIMITE)

HD FEMALE SCREWLOCK

829261-6

TE Internal Number: 829261-6

Active

[View 3D PDF](#)

Product Highlights [View All](#)

- Accessory Type = Female Screw Locks
- Tin Body Finish
- Thread Size = M3
- Thread Length = 7.90 mm
- Screwlock Style = Screwlock Only

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:
Use the Product Drawing for all design activity

Product Type Features	
Accessory Type	Female Screw Locks
Thread Size	M3
Dimensions	
Thread Length (mm)	7.90 [0.311]
Thread Length (in)	
Body Features	
Body Finish	Tin
Screwlock Style	Screwlock Only
Mating Thread Size	4-40
Body Material	Brass

Industry Standards	
Government/Industry Qualification	No
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant
Packaging Features	
Packaging Method	Individual
Other	
Brand	AMP
Comment	For Rear Panel Mount.

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)