



My Cart



My Part Lists



Sign In/Register



English (Change)

Have a Question?

Chat with a Product  
Information Specialist



What can we help you find?



Products

Industries

Resources

About TE

My Account

Innovation

Support Center

Home > Products > Parallel > Product Feature Selector > Product Details

## 5352068-9 Product Details




Share



Print



Email

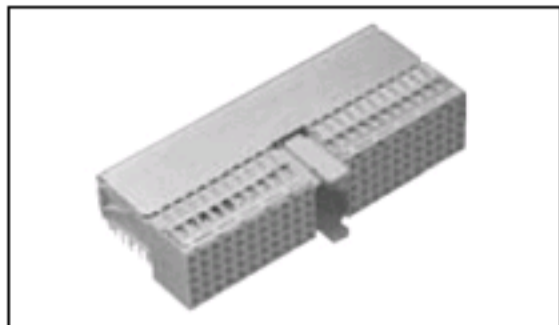

5352068-9

TE Internal Number: 5352068-9



Active



View 3D PDF

### 2mm Hard Metric PCB Mount Connectors (Z-PACK 2mm HM)



Always EU RoHS/ELV Compliant (Statement of Compliance)

#### Product Highlights:

- Connector
- Connector Assembly
- Connector Style = Receptacle
- Type = Type A
- Interface Type = 2mm HM

[View all Features](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

#### Documentation & Additional Information

##### Product Drawings:

- [Z-PACK 2mm HM TYPE A - 25 COLUMNS PRE-SHIELDED RECEP...](#) (PDF, English)

##### Catalog Pages/Data Sheets:

- None Available

##### Product Specifications:

- [Z-Pack 2 mm HM CONNECTORS](#) (PDF, English)

##### Application Specifications:

- [Z-PACK 2mm HM Interconnection System for Board-to-Bo...](#) (PDF, English)

##### Instruction Sheets:

- None Available

##### CAD Files: (CAD Format & Compression Information)

- [2D Drawing](#) (DXF, Version A)
- [3D Model](#) (IGES, Version A)
- [3D Model](#) (STEP, Version A)

[List all Documents](#)

##### Additional Information:

- [Product Line Information](#)

##### Related Products:

- [Tooling](#)

#### Product Features (Please use the Product Drawing for all design activity)

##### Product Type Features:

- Product Type = Connector
- Connector Type = Connector Assembly
- [PCB Mounting Orientation](#) = Right Angle

##### Mechanical Attachment:

- [Board Mount](#) = Free Board
- Shield Type = Ground Return Shielding
- Shield Style = Upper

##### Electrical Characteristics:

- [Shielded](#) = Yes

##### Termination Features:

- [Interface Type](#) = 2mm HM
- Termination End Plating = Tin over Nickel

##### Dimensions:

- [Module Length \(mm \[in\]\)](#) = 50.00 [1.968]

##### Body Features:

- [Type](#) = Type A
- CompactPCI Designation = J1, J4

##### Contact Features:

- Contact Configuration = ACTION PIN Post, Signal
- [Feedthrough Post Length \(mm \[in\]\)](#) = 3.70 [0.145]
- CompactPCI = Yes
- [Contact Plating, Mating Area, Material](#) = Performance-Based
- [Grounding Contact](#) = Without
- Contact Style = Short Tail
- Number of Signal Contacts = 110
- Contact Base Material = Phosphor Bronze

##### Housing Features:

- Connector Style = Receptacle
- [Mating Alignment](#) = With
- [Mating Alignment Type](#) = Multi-Purpose Center
- Housing Color = Gray
- Housing Material = Polyester GF
- UL Flammability Rating = UL 94V-0

##### Configuration Features:

- [Number of Rows](#) = 5
- [Number of Positions](#) = 110
- [Crosstalk Version](#) = Standard
- Rows Loaded = E, C, B, A, D

##### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

##### Other:

- Brand = AMP
- Comment = Connector lubricated with Telcordia GR-1217-Core approved lubricant.; Connector tested and qualified against Telcordia GR-1217-Core Quality Level III Central Office Applications; Female connector with pre-installed shield.

#### Corporate Information

[About TE](#)

[Investors](#)

[News Room](#)

[Supplier Portal](#)

[Careers](#)

[Terms & Conditions](#)

[Privacy Policy](#)

#### Quick Links

[Check Distributor Inventory](#)

[Cross Reference Products](#)

[Find Documents & Drawings](#)

[Product Compliance Support Center](#)

[Site Map](#)

#### Customer Support

[Email or Chat With Us](#)

[Find a Phone Number](#)

[Search Knowledge Base](#)

[Manage Your Account](#)

#### Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

