

COIL: @ +25°C

RESISTANCE 700 OHMS ± 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.5 VDC

MUST RELEASE 1.5 - 8.0 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS AT 30 g's

SHOCK 100 g's 6 ± 1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

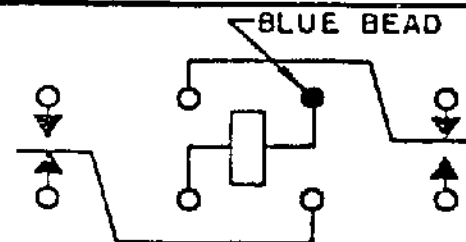

CONTACT RATING: Low Level

2 AMPS, 28 VDC

100,000  
Operations

DR. 4-4-89 JMB ck.

**Communications  
Instruments, Inc.**

CUST.

CUST. NO. 139016/6-105P

TYPE HFW RELAY

HFW 1230K06P