


REV. 0  
DCO 140993

COIL: @ 25°C  
 RESISTANCE 880 OHMS ± 10%  
 NOMINAL VOLTAGE 18.0 VDC  
 MUST OPERATE 10.6 VDC  
 MUST RELEASE 6.0 VDC MAX, 0.91 VDC MIN.

ENVIRONMENT:  
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2 MS MAX  
RELEASE TIME 4 MS MAX  
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

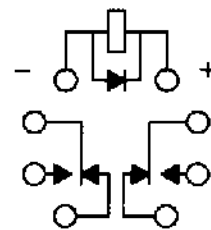

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 3/31/99 CK *[Signature]* 3-31-99



JMACD-18XL

CUST. QPL  
 CUST. NO. M39016/15-080L

TYPE JMAD RELAY