


COIL: 26.5 VDC	
WINDING #1	WINDING #2
1000 OHMS ± 10% @ 25° C	1000 OHMS ± 10% @ 25° C
13.0 VDC MUST OPERATE	13.0 VDC MUST OPERATE
26.5 VDC NOMINAL VOLTAGE	26.5 VDC NOMINAL VOLTAGE

CUSTOMER DATA SHEET

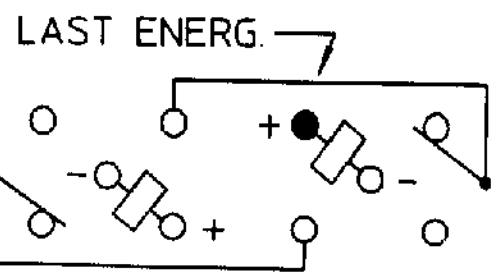

ENVIRONMENT:  
 VIBRATION 10 CPS TO 2500 CPS @ 30 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OTHER SPECIFICATIONS IN ACCORDANCE WITH MIL-R-39016/45  
OPERATE TIME 5 MS MAX  
BOUNCE 2.0 MS MAX

CONTACT RATING: LOW LEVEL TO 2 AMPS  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 9/21/94 | CK. 9/21/94



CUST. COMMERCIAL  
 CUST. NO. REF. M39016/45-021L TYPE "LS" RELAY

LS-9521L