

REV. 0


DCO 141905

COIL: @ 25°C	
RESISTANCE	3200 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.0 VDC
	1.4 VDC
MUST RELEASE	

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 4.0 MS MAX
	RELEASE TIME 2.0 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

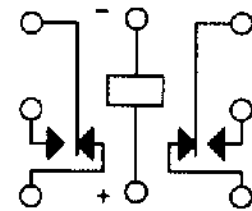

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. PBB 3/31/00 CK/ERY 3/31/00



CUST. C. I. I.
CUST. NO. STD. REV.

'MGS' RELAY

MGSC-26W