

WIRING INSTALLATION

**900-147/900-148/900-149 Fish Tape** **900-147****900-148****900-149**

- Made from flexible spring steel and black finish.
- Equipped with durable plastic container and slide handle.
- Easy to thread through the pipe and pull out the electric cable.

Model No.	Steel tape size	Individual packing
900-147	50 Feet	PE shrink
900-148	100 Feet	PE shrink
900-149	200 Feet	PE shrink

**902-197 Fiberglass Fish Tape**

Fiberglass tape size	Individual packing
150 Feet	PE shrink

**DK-2053A Fiberglass Push/Pull Rod Set (10 Pcs/set)**


- Ideal for running multi-purpose cable in hard-to-reach area such as behind walls, up through crawl spaces, and under floors.
- 10 pcs, 1M/3.28Ft each
- Diameter 5mm±0.2mm (13/64"±0.008")




Hook



Ring

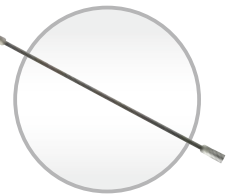

Flexible Extender

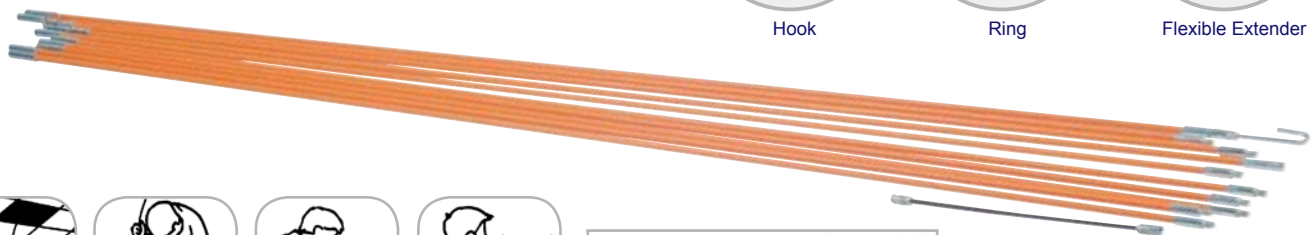

Ceiling ducts



Under floorboards



Trunking



Wall cavities



Description	Individual packing
3.28 feet, 10pcs/set	PVC tube

▶ CP-391 All-in-One Insulated Staple Cable Tacker

Good for CAT5/6, Coax, Romex and Silver Satin cables



STEP 1
Press the staple feeder downward and remove from its channel.



STEP 2
Load a strip of staples into the channel.




STEP 3
Slide in the staple feeder and push it up to its locked position.



Interchangeable staple guide plate

Note: One of the guide plates must be in place to operate properly


CP-391-1

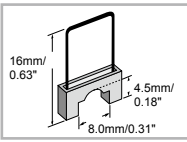

Round Cable
Height: 4mm~6mm (0.16"~0.24")

Flat Wire
Height: 2.5mm~4.0mm (0.10"~0.16")
Width: Below 8.0mm (0.31")

CP-391-2

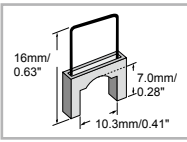

Round Cable
Height: 6mm~8mm (0.24"~0.31")

Flat Wire
Height: 4.5mm~6.3mm (0.18"~0.25")
Width: Below 10.3mm (0.41")



- All in one insulated staple cable tacker works for different kinds of round cables and flat wires.
- Easy way to change different staple guide plates to match different staples (CP-391-1 or CP-391-2)

▶ CP-392 Heavy Duty 3 In 1 Tacker

New



Adjustable punch force to match for different material hardness




Fastens 3 different types of staples: flat crown staples, round crown staples and brad nails




- Easy-squeeze product works overtime as a staple gun, brad nailer, cable tacker and wire tacker
- Fastens 3 different types of staples: flat crown staples, round crown staples and brad nails
- Ideal for upholstery, wood working, ceiling tiles, rack & roofing
- Adjustable punch force to match for different material hardness.
- Less force to squeeze and more driving power
- Non-slip grip and quick jam release
- Made of all carbon steel construction.
- OAL: 4.7"

CP-392-3 Flat Crown Staples

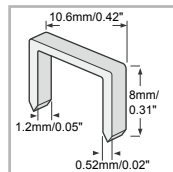


500pcs/box

CP-392-4 Round Crown Staples

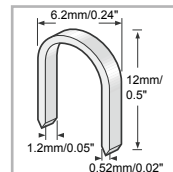

500pcs/box

CP-392-5 Brad Nail

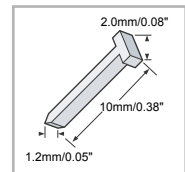

1000pcs/box

Model No.	Material	Replacement staples	Individual packing
CP-391	ABS	CP-391-1 (200pcs/pack) CP-391-2 (200pcs/pack)	Blister card
CP-392	Carbon steel	CP-392-3 (500pcs/box) CP-392-4 (500pcs/box) CP-392-5 (1000pcs/box)	Blister card

▶ **900-005 Cable Tie Gun**



- Cable tie from 3/32"~3/16"(2.2~4.8mm) and thickness up to 1.6mm
- Neatly cuts end of cable tie off
- Adjustable tension control

▶ **CP-383 Cable Tie Gun**



Features:

- Adjustable tension control can be used for a variety of style cable ties
- Consistent flush cut with each use
- Durable die-cast steel construction

Cable Tie:

- Thickness up to 1.3mm(0.05")
- Width up to 4.6mm(0.18")

Model No.	Material	O.A.L (mm/inch)	Individual packing
900-005	Aluminum	160/6.3	Blister card
CP-383	Steel	168/6.6	Blister card

▶ **Cable Ties** 



Individual packing	
Header Card (100pcs/pack)	
Model No.	Description
902-012	Cable Tie 4" X 3/32" Neutral (100pc pack)
902-015	Cable Tie 7-7/8" X 3/32" Neutral (100pc pack)
902-013	Cable Tie 5-1/2" X 9/64" Neutral (100pc pack)
902-016	Cable Tie 7-7/8" X 9/64" Neutral (100pc pack)
902-014	Cable Tie 7-1/2" X 3/16" Neutral (100pc pack)
902-017	Cable Tie 11-3/4" X 3/16" Neutral (100pc pack)
902-018	Cable Tie 14-1/2" X 3/16" Neutral (100pc pack)
902-019	Cable Tie 4" X 3/32" Black (100pc pack)
902-022	Cable Tie 7-7/8" X 3/32" Black (100pc pack)
902-020	Cable Tie 5-1/2" X 9/64" Black (100pc pack)
902-023	Cable Tie 7-7/8" X 9/64" Black (100pc pack)
902-021	Cable Tie 7-12" X 3/16" Black (100pc pack)
902-024	Cable Tie 11-3/4" X 3/16" Black (100pc pack)
902-025	Cable Tie 14-1/2" X 3/16" Black (100pc pack)

ESD STATIC PROTECTION
MAGNIFICATION/LIGHTING
FIBER OPTICS
POWER TOOLS
INSTRUMENT CASE
MISCELLANEOUS
LAN/DATACOMM
CONNECTORS
WIRING INSTALLATION
TOOL CASES
TOOL KITS




900-062 Heavy Duty Cable Tie Tool

- Cuts up to .350 inch size cable ties
- Tension tool

Individual packing

Blister Card

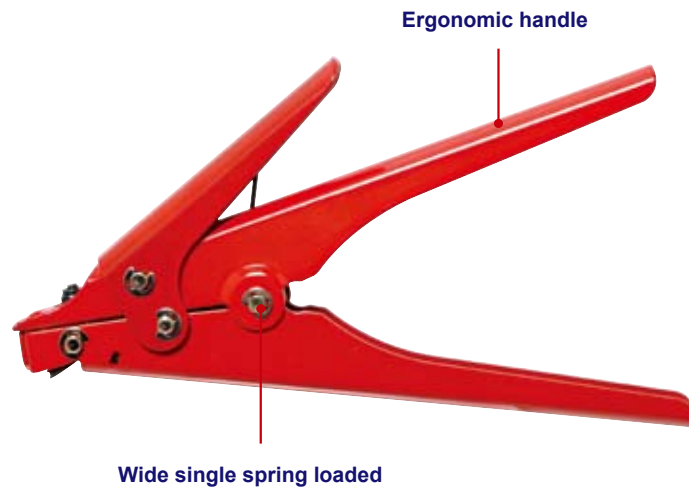

902-321 Stainless Steel Cable Tie Gun

New

Ideal for Stainless Steel Cable Ties

Cable tie holder is specially made of SKD11 steel and CNC ground

Cutting blade is made of SKD11 and CNC ground

Cable control bar

Self return spring design

Made of Carbon Steel

Non-slip TPR handles



Tensioning and cutting off stainless steel cable ties



Suitable for most application fields of stainless steel cable ties. And up to 12mm wide.

Individual packing

Blister Card


- Ideal for tensioning and cutting off stainless steel cable ties both in ball lock and ladder types.
- Heavy duty, two stage manual tensioning tool for easy operation
- Cutting blade and cable tie holder are specially made of SKD11 steel and CNC ground to provide strong, secure fixing and flush cutting.
- Suitable for most application fields of stainless steel cable ties. And up to 12mm wide.
- Non-slip TPR handle and self return spring design for user comfort
- OAL: 8.2"

**902-035/MS-V350-WH/MS-V350-BL/902-305****Hook and Loop Cable Tie****902-035**
(50 feet long-1/2" wide)**MS-V350-WH**
(50 feet long-1/2" wide)**MS-V350-BL**
(50 feet long-1/2" wide)**902-305**
(50 feet long-3/4" wide)

Model No.	Description	Individual packing
902-035	Hook and Loop Cable Ties Material-Bulk Roll-Black	Poly bag with header
MS-V350-WH	Hook and Loop Cable Ties Material-Bulk Roll-white	Poly bag with header
MS-V350-BL	Hook and Loop Cable Ties Material-Bulk Roll-Blue	Poly bag with header
902-305	Hook and Loop Cable Ties Material-Bulk Roll-Black	Poly bag with header

**Hook and Loop Cable Ties**

Model No.	Description	Individual packing
900-098-BK	Hook And Loop Cable Ties-8" Black (25pc pack)	Poly bag with header
900-098-BU	Hook And Loop Cable Ties-8" Blue (25pc pack)	Poly bag with header
900-098-GN	Hook And Loop Cable Ties-8" Green (25pc pack)	Poly bag with header
900-098-OR	Hook And Loop Cable Ties-8" Orange (25pc pack)	Poly bag with header
900-098-RD	Hook And Loop Cable Ties-8" Red (25pc pack)	Poly bag with header
900-098-WH	Hook And Loop Cable Ties-8" White (25pc pack)	Poly bag with header
900-098-YL	Hook And Loop Cable Ties-8" Yellow (25pc pack)	Poly bag with header

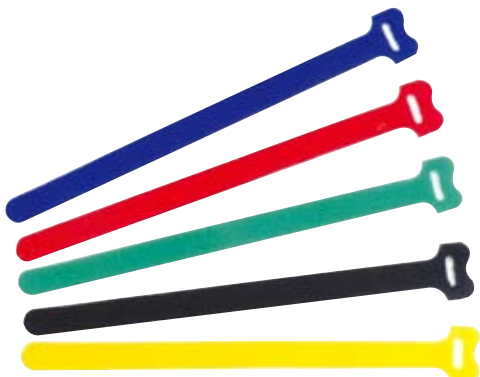**MS-V308 Hook and Loop Cable Ties (Assortment Pack)****Individual packing**

Poly bag (15pcs/pack)

The hook and loop cable ties are made by Nylon/P.P. material and offered 5 colors combination pack (Black, Blue, Green, Red, and Yellow). They are good for use in binding the cables and patch cables and won't even affect the transmittance performance because of over tight binding. Reusable, the back-to-back design provides instant installation without using tools.



TOOL CASES




900-262

Heavy-Duty ABS Case With Wheels And Telescoping Handle


- Heavy-duty black scuff resistant molded ABS thermoplastic forms the tough shell of this case.
- Extruded aluminum rim, drawbolt key locks and strong molded handle.
- Locking telescoping handle extends to 1000mm.
- Loading capacity: 12kg
- Rotationally molded heavy-duty polyethylene shell.
- Not designed to be checked as airline baggage.
- Individual Packing : Color box



Disassemble

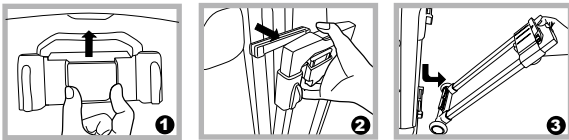

Assemble

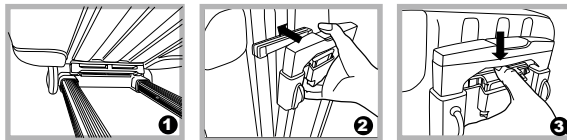


The loading capacity of this tool case is 12kg maximum.



900-261

Multi-Purpose Tool Case With Wheels And Telescoping Handle

- Material: 600D polyester with water repellent treatment
- Multi function bag with 4 inner layers, ideal for storing tools, books, personal computers etc
- 2 PCS removable tool pallets
- Recessed rubber wheels and telescoping handle for convenient transportation
- Carry your tools, laptop and business material in one convenient case
- Locking telescoping handle extends to 960mm
- Individual Packing : Plain box + Color label

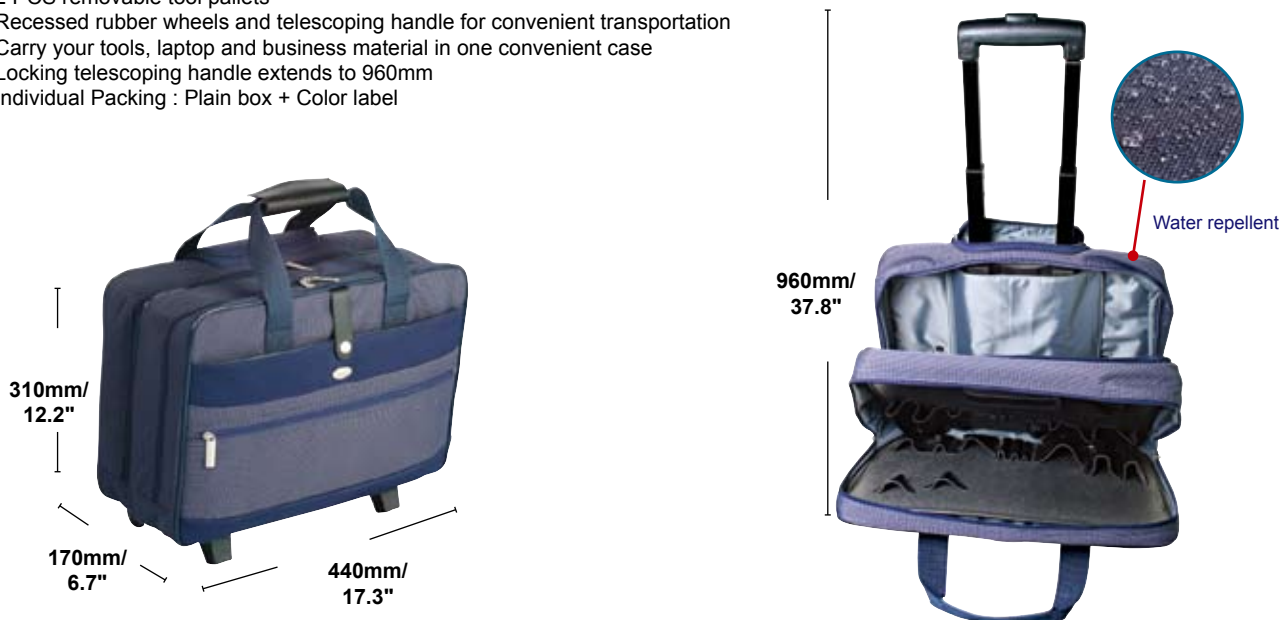

ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS

▶ TC-765 Aluminum Frame Drawer Case



- Made of ABS plastic for strength and durability.
- Sturdy aluminum frame construction.
- Foam padding on lid provides better tool protection.
- The drawer locks automatically when lid is closed to prevent slide out for easy mobility.
- Ball-bearing slides make drawer easy to open and close tightly.
- Non-slip lining helps you to keep tools in place.



Heavy duty lockable latches Ball-bearing slides make drawer easy to open and close tightly. Cushioned carrying handle Plastic protective corner



Drawer auto-locking design when lid is closed to prevent slide out for easy mobility.



▶ 900-199 ABS Carrying Tool Case W/1 Pallet

Attractive and functional multipurpose cases

- Material: ABS
- Functional for both personal and professional business
- Complete with one tool pallet and interior dividers
- Both the tool pallet and dividers are removable



Latch lock Durable handle Injection molding tool case stands. Aluminum corner frames to protect tools.




▶ 900-141 ABS Carrying Tool Case W/2 Pallets

- Material: ABS for case, durable silver aluminum for frame



Stylish draw bolt key locks Removeable rugged pallet. With shoulder strap for convenient transportation Deluxe die-cast chrome golf grip handle

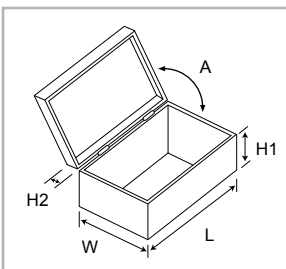

Model No.	Size	L (mm/inch)	W (mm/inch)	H1 (mm/inch)	H2 (mm/inch)	A	Individual packing
TC-765	O.D	430/16.9	300/11.8	163/6.4	57/2.2	90°	Color box
	I.D	410/16.1	280/11.0	70/2.8	49/1.9		
	I.D(Drawer)	337/13.3	255/10.0	40/1.6	-		
900-199	O.D	463/18.2	331/13.0	96/3.8	75/3.0	98°	Color box
	I.D	453/17.8	323/12.7	90/3.5	67/2.6		
900-141	O.D	435/17.1	310/12.2	83/3.3	70/2.8	105°	Color box
	I.D	420/16.5	293/11.5	76/3.0	59/2.3		

▶ 900-048 Aluminum Frame Tool Case W/1 Pallet

- Material: Aluminum (frame)



Reinforced construction
3 hinges and corner protector.



Removeable
rugged pallet.



Key lock



EVA

▶ 900-011 Aluminum Frame Tool Case W/1 Pallet

- Material: Aluminum (frame)



Removeable
rugged pallet.



Key lock

8 Brackets
(Corner protector)

4 Brackets
(Reinforced construction)



EVA

▶ 900-203 Aluminum Frame Tool Case


- Material: Aluminum (frame)

4 Brackets
(Reinforced construction)



Key lock



8 Brackets
(Corner protector)

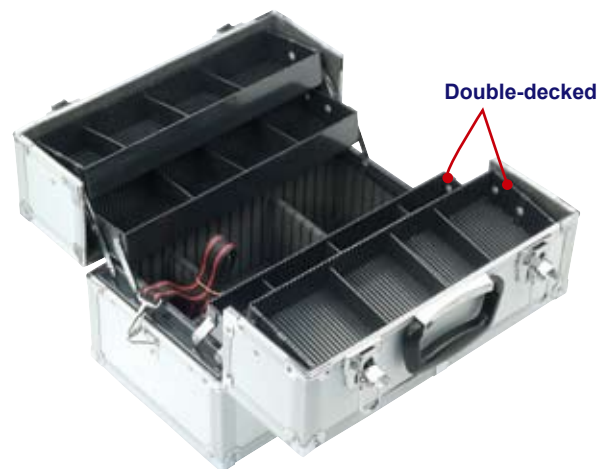

Double-decked

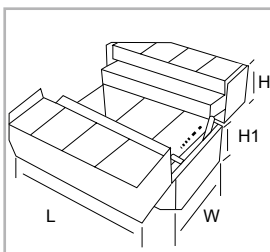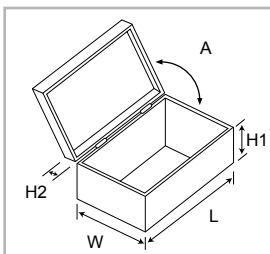

Model No.	Size	L (mm/inch)	W (mm/inch)	H1 (mm/inch)	H2 (mm/inch)	A	Second Pallet	Individual packing
900-048	O.D	458/18.0	330/13.0	90/3.5	60/2.4	97°	900-045	Plain box + Color label
	I.D	434/17.1	308/12.1	82/3.2	53/2.1			
900-011	O.D	458/18.0	330/13.0	101/4.0	49/1.9	97°	900-045	Color box
	I.D	438/17.2	312/12.3	95/3.7	41/1.6			
900-203	O.D	360/14.2	220/8.7	120/4.7	110/4.3	-	-	Plain box + Color label
	I.D	335/13.2	200/7.9	110/4.3	85/3.3			

▶ 900-054 2 In 1 Zipper Bag W/2 Pallet



• Material: PVC leather



Separate compartments provide multi-function for tool kit and document storage



▶ 900-052 Heavy Duty Zipper Bag



• Material: PVC leather




▶ 900-225 Blow Molded Case With Pre-Cut Soft Foam

• Material: H.D.P.E



Demo only

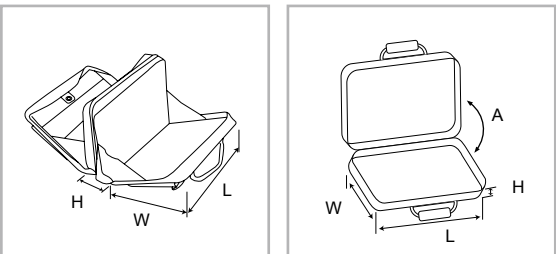

Model No.	L (mm/inch)	W (mm/inch)	H (mm/inch)	A	Individual packing
900-054	400/15.7	395/15.6	120/4.7	-	Poly bag
900-052	435/17.1	325/12.8	90/3.5	93°	Color box
900-225	442/17.4	279/11.0	89/3.5	-	Color Label

**902-118****Zipper Bag W/2 Pallets**


Demo only

**902-119****Tool Bag**

- Intensive structure for strap, zipper and handle designed to enhance the durability.
- High capacity and affordable price make it the best match for students.



Demo only

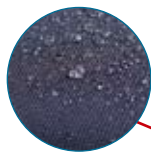


Water repellent

**900-260****Tool Bag**


- Multi function bag with 4 inner layers ideal for storing tools, books, mobile computers, clothes, etc.
- Intensive structure for strap, zipper and handle designed to enhance the durability.



Demo only

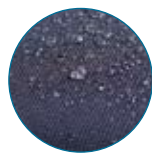

Water repellent

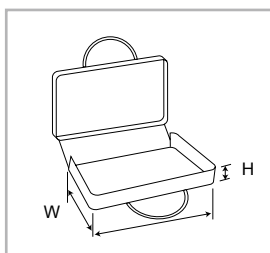

Model No.	Material	L (mm/inch)	W (mm/inch)	H (mm/inch)	Individual packing
902-118	600D polyester	390/15.4	280/11.0	70/2.8	Color box
902-119	600D polyester	360/14.2	260/10.2	87/3.4	Poly bag
900-260	600D polyester	400/15.7	275/10.8	90/3.5	Poly bag

▶ 900-106 Deluxe Portable Tool Bag



- Material: 600D Polyester
- Ruggedly constructed with heavy duty zipper and sturdy padded handles, hard bottom to keep shape and large opening interior.
- Designed to provide multi-function and flexible adjustment space.
- 12 pocket holes for versatility



Demo only



▶ MTB-1 Mechanic's Tool Bag



Demo only


- Material: 600D Polyester
- Rugged construction
- Heavy-duty zipper
- Sturdy padded handles
- Hard bottom to maintain shape
- Soft sides to allow flexibility
- 13 pocket holes for versatility



▶ 9ST-902



Demo only

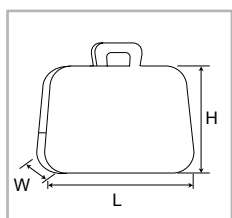

▶ Case001




Demo only



Model No.	Material	L (mm/inch)	W (mm/inch)	H (mm/inch)	Individual packing
900-106	600D Polyester	390/15.4	250/9.8	245/9.6	Poly bag
MTB-1	600D Polyester	305/12.0	152/6.0	165/6.5	Poly bag
9ST-902	PVC leather	260/10.24	170/6.69	38/1.5	Poly bag
Case001	600D Polyester	305/12.0	255/10.0	75/3	Poly bag

▶ 902-254 Black Tool Pouch

- Large capacity, general purpose pouch with Tape Measure clip, Butt-Set hook, and Tape Roll holder.
- Made from durable fabric.

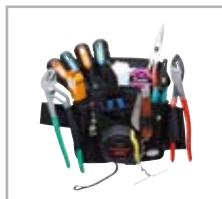

Demo only



▶ 900-246 Soft Sided Tool Pouch



Demo only

Dual purpose belt for easy carrying on shoulder or waist

- Keep your tools and supplies handy.
- Made from strong durable fabric.
- complete with universal tool belt system.



Model No.	Size	L (mm/inch)	W (mm/inch)	H (mm/inch)	Individual packing
902-254	O.D	350/13.8	240/9.5	-	Poly bag + Color label
900-246	O.D	305/12.0	235/9.3	95/3.7	Poly bag + Hanger



902-314

25 Pocket Electrical & Maintenance Tool Carrier



Demo only



Square design enables firmly standing

- Made of 600D polyester
- With a padded carrying handle
- With multi-pocket for versatility
- A space in the bottom for storage box
- Size: 216x216x406mm/8.5"x8.5"x16"

• Individual packing: Poly bag+Hanger

16"



8.5"

8.5"



902-311

Master Tool Belt

- Made of 600D polyester
- Leather waist belt with 13 adjustment holes (from 32" to 44")
- With roller metal double-tongue buckle
- With multi-pocket for versatility
- Size: 356x330mm/14.0"x13.0"(Individual bag size)
- Individual packing: Poly bag+Hanger



Demo only



902-312

4 Pocket Pouch

- Made of 600D polyester
- 3 mesh pockets for light tools
- Ideal for packing pliers with a padded & reinforced pouch design
- Size: 229x102mm/9.4"x4.0"
- Individual packing: Poly bag+Hanger



Demo only



ST-5203

Power Tool Holster

New



Demo only



Water repellent

PATENTED Product

PATENT NO. M285261



ST-5601 **Magnetic Wrist Band**



Demo only

Powerful magnet lifts: 1kg

New



Water repellent



Model No.	Material	Loading capacity	Dimension (mm/inch)	Individual packing
ST-5203	600DX600D Polyester	3kg	280x180x50/11.0x7.1x2.0	Poly bag+Hanger
ST-5601	600DX600D Polyester	-	Width: 5cm / Length: 30cm (Width: 2.0" / Length: 11.8")	Poly bag+Hanger

ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS



TOOL KITS

PK-ST902 contents

- 5" Bent nose
- 4 1/2" Diagonal cutting
- 4 1/2" Pointed diagonal pliers
- 5" Flat nose pliers
- Case size: 260x170x38 mm (11.4"x8.7"x2.6")
- Individual packing: Color label+Srink



PK-ST902 4 Pc Ergonomic ESD Safe Plier and Cutter Kit



ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS

PK-2013H contents

- ⊕ Pro-soft screwdriver #1x75mm (#1x3.0")
- ⊕ Pro-soft screwdriver #2x100mm (#2x4.0")
- ⊖ Pro-soft screwdriver 5x75mm (5x3.0")
- ⊖ Pro-soft screwdriver 6x100mm (6x4.0")
- Professional 3 1/2 digital multimeters
- Dual color side cutting pliers
- Dual color long nose pliers
- Dual color lineman's pliers
- PVC insulated tape
- Measuring tape
- Soft Sided Tool Pouch
- Case size: 305x235x95mm (12"x9.3"x3.7")
- Individual packing: Color box



PK-2013H Maintenance Tool Kit



Built for electrician, home use and DIY users, the handy soft sided tool pouch includes basic tools of multimeter, pliers and screwdrivers.

902-121 contents

- Dual color long nose plier 136mm (5.4")
- Dual color diagonal cutting Plier 125mm (4.9")
- ⊕ Precision screwdriver #0x20mm (#0x0.79")
- ⊕ Precision screwdriver #00x20mm (#00x0.79")
- ⊖ Precision screwdriver 2.0x20mm (2.0x0.79")
- ⊖ Precision screwdriver 3.0x20mm (3.0x2.79")
- ⊕ Double-end reversible screwdriver #2/6 mm
- Fine tip straight tweezer
- Carrying zipper bag
- Case size: 121x206x35mm (4.8"x8.1"x1.4")
- Individual packing: Color sleeve shrink



902-121 Compact Tool Kit



500-025 contents

- Long nose plier 135mm (5.3")
- Diagonal cutting plier 110mm (4.3")
- Fine tip straight tweezer
- ⊖ Pro-soft s/d 3.2x75mm (3.2x3.0")
- ⊕ Pro-soft s/d #0x75mm (#0x3.0")
- Precision screwdriver 2.4mm
- Precision screwdriver #0
- Needle file flat
- Needle file round
- Utility knife (3 blades self loading)
- Zippered carrying bag
- Case size: 205x144x32mm (8.1"x5.7"x1.3")
- Individual packing: Inner box & Color label shrink



500-025 10 PCS Compact Tool Kit



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

PK-2015 Deluxe Basic Tool Kit

New



PK-2015 contents

- 8" Adjustable wrench
- LED Flash Light
- Long nose plier 165mm (6.5")
- Utility Knife (3 Blades self loading)
- Lineman's plier 165mm (6.5")
- Screwdriver Probe Voltage Tester
- Measuring tape 3M/10FT
- Double-End Reversible Screwdriver \oplus #2 / \ominus 6.0x100mm (4.0")
- 8PCS Aluminum Case Folding Hex Key
- 9 in 1 Aluminum Handle Precision Screwdriver Set
- PVC Insulated Tape
- Junior Multi-Purpose Saw
- 8 oz curved claw Hammer
- Pallet for PK-2015
- Pallet for PK-2015
- Plastic Tool Box

- Case size: 320x260x60mm (12.6"x10.2"x2.4")
- Individual packing: Color sleeve shrink

500-047 Basic Electronics Kit



500-047 contents

- Lineman's plier 165mm (6.5")
- Side cutting plier 165mm (6.5")
- Long nose plier 165mm (6.5")
- 6" Adjustable wrench
- Desoldering braid
- Solder core 63%, SN
- \ominus Pro-soft screwdriver 3.0x100mm (3.0x4.0")
- \oplus Pro-soft screwdriver #0x100mm (#0x4.0")
- \oplus Pro-soft screwdriver #2x100mm (#2x4.0")
- \ominus Pro-soft screwdriver 5.0x100mm (5.0x4.0")
- \oplus Pro-soft screwdriver #1x100mm (#1x4.0")
- Convertible soldering iron/gun 110V
- Fine tip straight tweezer
- Zippered carrying bag
- Case size: 195x305x50mm (7.7"x12.0"x2.0")
- Individual packing: Color sleeve shrink

500-042 ESD Precision Tool Kit



500-042 contents

- Long nose plier
- Flat nose plier
- Bent nose plier
- Clean cut micro nipper
- Micro cutting plier 125mm (4.9")
- 4 pcs conductive tweezer set
- Wrist strap 10FT
- \oplus ESD safe precision screwdriver #00
- \oplus ESD safe precision screwdriver #0
- \oplus ESD safe precision screwdriver #1
- \ominus ESD safe precision screwdriver 2.0mm
- \ominus ESD safe precision screwdriver 2.4mm
- \ominus ESD safe precision screwdriver 3.0mm
- Tool bag
- Case size: 288x203x40mm (11.3"x8.0"x1.6")
- Individual packing: Inner box & Color label shrink

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

PK-2096AI contents

Long Nose Plier 135mm (5.3")
Diagonal Cutting Plier 110mm (4.3")
Needle Nose Plier 150mm (5.9")
Super Fine Tip Straight Tweezer 120mm (4.7")
Soldering Iron 30W (110V)
IC Extractor
Square scraper/Stainless steel brush
Slotted shaft/Split 45 lever
Tapered reamer/Tapered needle
Offset chip holder/45 chip holder
3 Prong Holder
Screwdriver handle
4pcs 1/4"x50mm(2.0") bits:
⊕ #1, #2, ⊖ 5.0, 6.0mm
Extension blade 1/4"x30mm (1.18")
9pcs 1/4"x25mm (0.98") socket set:
⊕ 3/16", 7/32", 1/4", 9/32", 5/16", 11/32", 3/8", 7/16", 1/2"
Wrist Strap 10FT
Desoldering Pump
3.6V Cordless Screwdriver (110V)
Zippered carrying bag

- Case size: 320x233x60mm (12.6"x9.2"x2.4")
- Individual packing: Color box

500-003 contents

Long nose plier 135mm(5.3")
Diagonal cutting plier 110mm(4.3")
Fine tip straight tweezers
3 pcs Soldering aid tools
6" Adjustable wrench
Quick heat ceramic soldering iron 110V
Screwdriver handle
⊖ Pro-soft s/d 5.0x75mm(3.0")
⊕ Pro-soft s/d #1x75mm(3.0")
Desoldering braid
Crimping tool (inch)
Desoldering pump
IC extractor
3 prong holder
IC insert tool
Solder core 63%, SN
Parts tube
Heat sink
8 pcs bits pack
Zippered carrying bag

- Case size: 325x195x48mm(12.8"x7.7"x1.9")
- Individual packing: Inner box & Color label shrink

500-016 contents

Utility component storage box
Fine tip straight tweezers
Side Cutter 125mm (4.9")
Long nose plier 138mm (5.4")
Quick heat ceramic soldering iron 110V
⊖ Pro-soft s/d 3.2x75mm (3.0")
⊕ Pro-soft s/d #0x75mm (3.0")
⊖ Pro-soft s/d 5.0x75mm (3.0")
⊕ Pro-soft s/d #1x75mm (3.0")
⊖ Pro-soft s/d 6.0x100mm (4.0")
⊕ Pro-soft s/d #2x100mm (4.0")
Brush
Mini soldering stand with sponge
Desoldering pump
IC extractor
7 pcs folding type hex key set (inch)
Solder core 63%, SN
Utility knife (3 blades self loading)
Zippered carrying bag

- Case size: 330x220x48mm (13.0"x8.7"x1.9")
- Individual packing: Inner box & Color label shrink



PK-2096AI

Computer & Notebook Service Kit

New



500-003

Computer Service Tool Kit



500-016

School Tool Kit



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

ESD STATIC PROTECTION
MAGNIFICATION/LIGHTING
FIBER OPTICS
POWER TOOLS
INSTRUMENT CASE
MISCELLANEOUS
LAN/DATACOMM
CONNECTORS
WIRING INSTALLATION
TOOL CASES
TOOL KITS

▶ 500-032

Professional Electronic Tool Kit**500-032 contents**

Lineman's plier 165mm (6.5")

Side cutter 125mm (4.9")

Long nose plier 165mm (6.5")

Soldering iron stand with sponge

Desoldering pump

Quick heat ceramic soldering iron 110V

⊖ Line color screwdriver 3.2x75mm (3.0")

⊕ Line color screwdriver #0x75mm (3.0")

⊖ Line color screwdriver 5.0x75mm (3.0")

⊕ Line color screwdriver #1x75mm (3.0")

⊖ Line color screwdriver 6.0x100mm (4.0")

⊕ Line color screwdriver #2x100mm (4.0")

● Line color screwdriver nut 3/16"

● Line color screwdriver nut 1/4"

6 pcs electronic screwdriver set

3-1/2 compact digital multimeter

7 pcs folding type hex key set (inch)

PVC insulated tape

Solder core 63%, SN

Zippered carrying bag

- Case size: 375x250x60mm (14.8"x9.8"x2.4")
- Individual packing: Inner box & Color label shrink

▶ 500-026

Computer Maintenance Kit**500-026 contents**

Fine tip straight tweezer

Side cutter 125mm (4.9")

Long nose plier 138mm (5.4")

Spring hook

6" Adjustable wrench

Quick heat ceramic soldering iron 110V

Desoldering braid

Micro cutting plier 130mm (5.1")

Wire stripper/cutter

PLCC extractor

Field service kit

Mini flash light

7 pcs folding type hex key set (inch)

Blowing brush

IC extractor

Extension blade 7" (175mm)

● Nut blade 1/4", 3/8", 3/16", 5/16", 7/16", 11/32"

● Driver blade T6

● Driver blade T7

● Driver blade T8

● Driver blade T9

Super torque ratchet handle

8 pcs screwdriver blades:

⊕ #0, #1, #2

⊖ 3, 5, 6mm

● T10, T15

Inspection mirror

2 pcs pallets

Empty tool bag

- Case size: 400x295x70mm (15.8"x11.6"x2.8")
- Individual packing: Color box

500-017 contents

- Reverse action tweezer
- Fine tip straight tweezer
- Brush
- 7 in 1 crimping tool
- IC extractor
- PLCC extractor
- Screwdriver handle
- ⊖ Pro-soft s/d 5.0x75mm (3.0")
- ⊕ Pro-soft s/d #1x75mm (3.0")
- ⊙ Pro-soft s/d 3/16"(inch)
- Wrist strap 10FT
- Utility knife (3 blades self loading)
- LED Flash light
- 7 pcs folding type hex key set (inch)
- 3 prong holder
- 8"Adjustable wrench
- Mini hammer set (including 6 parts)
- 5 pcs needle file set
- Long nose plier 135mm (5.3")
- Diagonal cutting plier 110mm (4.3")
- Lineman's plier 210mm (8.3")
- Flat nose plier 135mm (5.3")
- Bent nose plier 130mm (5.1")
- 6 pcs electronic screwdriver set
- Desoldering pump
- Quick heat ceramic soldering iron 110V
- Solder core 63%, SN
- 3 pcs soldering aid tools
- Heat sink
- ⊖ / ⊙ Double-end blade 175mm length 4mm/T6
- ⊕ / ⊙ Double-end blade 175mm length #1/#2
- ⊖ / ⊙ Double-end blade 175mm length 6mm/T8
- ⊙ / ⊙ Double-end blade 175mm length T10/T15
- Extension blade 175mm (7")
- Heavy duty zipper bag
- Case size: 435x325x90mm (17.1"x12.8"x3.5")
- Individual packing: Color box



500-017

Technician's Tool Kit



500-029 contents

- Utility component storage box
- Desoldering pump
- Cutting plier 125mm (4.9")
- Long nose plier 140mm (5.5")
- Soldering iron 30W 110V
- IC extractor
- ⊖ PVC screwdriver 3.2x75mm (3.0")
- ⊕ PVC screwdriver #0x75mm (3.0")
- ⊖ PVC screwdriver 5.0x75mm (3.0")
- ⊕ PVC screwdriver #1x75mm (3.0")
- ⊖ PVC screwdriver 6.0x100mm (4.0")
- ⊕ PVC screwdriver #2x100mm (4.0")
- Solder core 63%, SN
- Round hole bread board (1580 tie points)
- Protective function analog multimeter
- 2 pcs soldering aid kit
- Soldering iron box
- Tool bag
- Case size: 400x275x90mm (15.7"x10.8"x3.5")
- Individual packing: Poly bag + Color label



500-029

Deluxe Education Tool Kit



ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

▶ 1PK-1700NA

Electronics Master Kit



New



Replaces 902-124 kit

**1PK-1700NA contents**

- Utility component storage box
- Long nose plier 135mm (5.3")
- Diagonal cutting plier 110mm (4.3")
- Dual Color Lineman's Plier
- Bent nose plier 130mm (5.1")
- Side cutting plier 150mm (5.9")
- Dual color long nose plier
- Reverse action tweezers
- 3 pcs soldering aid tools
- Soldering iron stand with sponge
- Adjustable wrench 6"
- Ceramic Soldering Iron 110V
- Pro-soft s/d 3/16"(inch)
- Pro-soft s/d 1/4"(inch)
- ⊖ Pro-soft s/d 3.2x75mm (3.0")
- ⊕ Pro-soft s/d #0x75mm (3.0")
- ⊖ Pro-soft s/d 5.0x75mm (3.0")
- ⊕ Pro-soft s/d #1x75mm (3.0")
- ⊖ Pro-soft s/d 6.0x100mm (4.0")
- ⊕ Pro-soft s/d #2x100mm (4.0")
- ⊖ Pro-soft screwdriver 6.0x40mm (1.6")
- ⊕ Pro-soft screwdriver #2x40mm (1.6")
- Desoldering braid
- Brush
- 6 pcs electronic screwdriver set
- Crimping tool (inch)
- Desoldering pump
- 5 pcs needle file set
- Testing screwdriver
- Alignment tool 2.0mmx200mm (2.0mmx7.9")
- IC extractor
- Oil can
- LED Flash light
- 7 pcs folding type hex key set (inch)
- 3 prong holder
- 6 pcs open-end wrench set
- Heavy duty curved-claw hammer
- PVC insulated tape
- Stainless scissors 6"
- Solder core 63%, SN
- Parts tube
- Heat sink
- Utility knife (3 blades self loading)
- Measuring tape 3M/10FT
- Inspection mirror
- Slip-channel pump pliers 254mm (10")
- 2 pcs pallets
- Carrying tool case
- Case size (O.D): 450x325x132mm (17.7"x12.8"x5.2")
- Individual packing: Color box

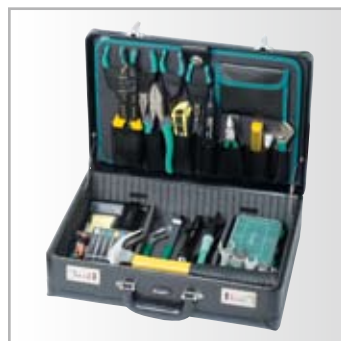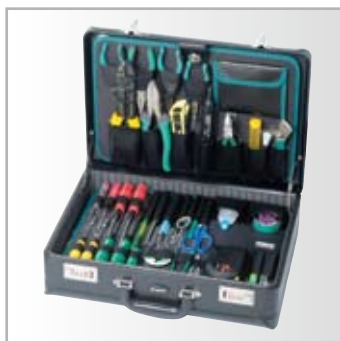

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

500-030 contents

Utility component storage box

Reverse action tweezer

3 pcs anti-static alignment tool kit

Micro cutting plier

Long nose plier

Diagonal cutting nipper

Long nose plier

Long nose plier 165mm (6.5")

Cabling splicing knife

4" Adjustable wrench

8" Adjustable wrench

Solder aid tool

Quick heat ceramic soldering iron 110V

DMM with mechanical mistake prevention operation

⊖ Line color screwdriver 3.2x75mm (3.0")

⊕ Line color screwdriver #0x75mm (3.0")

⊖ Line color screwdriver 5.0x75mm (3.0")

⊕ Line color screwdriver #1x75mm (3.0")

⊖ Line color screwdriver 3.2x100mm (4.0")

⊖ Line color screwdriver 6.0x100mm (4.0")

⊕ Line color screwdriver #2x100mm (4.0")

⊖ Line color screwdriver 3.2x200mm (8.0")

⊖ Line color screwdriver 6.0x38mm (1.5")

⊕ Line color screwdriver #2x38mm (1.5")

⊖ Line color screwdriver 8.0x150mm (6.0")

Brush

6 pcs electronic screwdriver set

Snap ring plier set

Precision wire stripper

Multi-purpose crimping tool (inch)

23 pcs 1/4" socket set

Oil can

Mini flash light

7 pcs folding type hex key set (inch)

Center punch tool

Feeler gauge

Ball peen hammer with fiberglass handle

Spring hook

Spring hook

6" Steel ruler

3 pcs soldering aid tools

Super torque ratchet handle

4 pcs hex driver blades: 1/16", 5/64", 3/32", 1/8"

● 7 pcs nut driver blades:
1/4", 3/8", 3/16", 5/16", 7/16", 11/32", 1/2"

⊖ Double ended screwdriver 3mm/#0

Electrician's scissors

10 pcs electronic combination wrench (inch)

Inspection mirror

Slip-channel pump pliers 254mm (10")

ABS tool carrying case with second pallet



500-030

Service Technician's Tool Kit



- Case size (O.D): 463x331x171mm (18.2"x13.0"x6.7")
- Individual packing: Color box



ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.



PK-15307EI Electronic Tool Kit



New



Replaces 902-123 kit



PK-15307EI contents

Long nose plier 135mm (5.3")
 Diagonal cutting plier 110mm (4.3")
 Dual color lineman's plier 210mm (8.3")
 Dual color long nose plier 165mm (6.5")
 6" Adjustable wrench
 Dual color side cutting plier 165mm (6.5")
 5 pcs needle file set
 Ceramic Soldering Iron 110V
 3-1/2 compact digital multimeter
 Measuring tape (3M/10FT)
 Solder core 63%, SN
 7 pcs hex key set (inch)
 Wire stripper cutter
 Utility knife (3 blades self loading)
 All Purpose Snip
 Solder aid tools
 Desoldering pump
 10 pcs electronic combination wrench (inch)
 Flux bottle (2 pcs/pack)
 Blow brush (Ø62mm/Ø2.4")
 IC extractor
 Slip joint plier 154mm (6")
 ⊖ Pro-soft screwdriver 3.0x75mm (3.0")
 ⊕ Pro-soft screwdriver #0x75mm (3.0")
 ⊖ Pro-soft screwdriver 5.0x75mm (3.0")
 ⊕ Pro-soft screwdriver #1x75mm (3.0")
 ⊖ Pro-soft screwdriver 6.0x100mm (4.0")
 ⊕ Pro-soft screwdriver #2x100mm (4.0")
 ⊕ Pro-soft screwdriver #2x250mm (10")
 ⊖ Pro-soft screwdriver 6.0x40mm (1.6")
 ⊕ Pro-soft screwdriver #2x40mm (1.6")
 ⊖ ProSoft Precision Screwdriver 2.0x50mm (2.0")
 ⊖ ProSoft Precision Screwdriver 2.4x75mm (3.0")
 ⊖ ProSoft Precision Screwdriver 3.0x100mm (4.0")
 ⊕ ProSoft Precision Screwdriver #00x50mm (2.0")
 ⊕ ProSoft Precision Screwdriver #0x75mm (3.0")
 ⊕ ProSoft Precision Screwdriver #1x150mm (6.0")
 Soldering tip cleaner
 Fine tip straight tweezer
 Utility component storage box
 Hobby vise
 2 pcs pallets
 Aluminum frame tool case

- Case size (O.D): 458x330x150mm (18"x13"x5.9")
- Individual packing: Color box



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

1PK-1900NA contents

- Utility component storage box
- Long nose plier 135mm (5.3")
- Diagonal cutting plier 110mm (4.3")
- Flat nose plier 135mm (5.3")
- Bent nose plier 130mm (5.1")
- Dual Color Lineman's Plier
- Reverse action tweezer
- Super drill set w/adaptor 110V
- 3 pcs soldering aid tools
- Soldering iron stand with sponge
- 6" Adjustable wrench
- Ceramic Soldering Iron 110V
- Screwdriver handle
 - Pro-soft s/d 3/16" (inch)
 - Pro-soft s/d 1/4" (inch)
 - ⊖ Pro-soft s/d 3.2x75mm (3.0")
 - ⊕ Pro-soft s/d #0x75mm (3.0")
 - ⊖ Pro-soft s/d 5.0x75mm (3.0")
 - ⊕ Pro-soft s/d #1x75mm (3.0")
 - ⊖ Pro-soft s/d 6.0x57mm (2.2")
 - ⊕ Pro-soft s/d #2x57mm (2.2")
 - ⊕ Pro-soft s/d #2x157mm (6.2")
 - ⊕ Pro-soft s/d #1x150mm (6.0")
 - ⊖ Pro-soft screwdriver 6.0x40mm (1.6")
 - ⊕ Pro-soft screwdriver #2x40mm (1.6")
- Brush
- Crimping tool (inch)
- Desoldering pump
- Precision s/d set 6 pcs
- 5 pcs needle file set
- Mini-vacuum cleaner
- Cleaning fluid, head (60cc)
- Cleaning fluid, head (18cc)
- 3-1/2 compact digital multimeter
- Testing screwdriver
- IC extractor
- LED Flash light
- 7 pcs folding type hex key set (inch)
- 3 prong holder
- PVC insulated tape
- 6" Stainless scissors
- Solder core 63%, SN
- Bit T10x30mm (1.2")
- Bit T15x30mm (1.2")
- Wrist strap 10FT
- Utility knife (3 blades self loading)
- 10 pcs electronic combination wrench (inch)
- Hobby vise (Jaw opening 40mm/1.6", width 60mm/2.4")
- 2pcs pallets
- Aluminum frame tool case
- Case size (O.D): 458x330x150mm (18"x13"x5.9")
- Individual packing: Color box




1PK-1900NA

Pro's Electronic Tool Kit



Replaces 500-007 kit

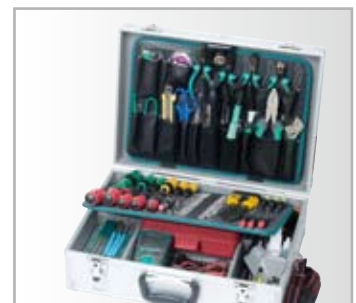

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS



PK-4027AI Master Electrical Tool Kit



PK-4027AI contents

- Utility knife (3 blades self loading)
- Electrician's scissors
- LED flash light
- 8" Adjustable wrench
- PVC insulated tape
- Contact voltage tester
- Lineman's plier
- Side cutting plier
- Long nose plier 165mm (6.5")
- Quick heat ceramic soldering iron 110V
- 6" Slip joint plier
- 8" Slip-channel pump plier
- Pen solder 63%
- ⊖ Pro-soft screwdriver 3.0x75mm (3.0")
- ⊕ Pro-soft screwdriver #0x75mm (3.0")
- ⊖ Pro-soft screwdriver 5x75mm (3.0")
- ⊕ Pro-soft screwdriver #1x75mm (3.0")
- ⊖ Pro-soft screwdriver 6x100mm (4.0")
- ⊕ Pro-soft screwdriver #2x100mm (4.0")
- ⊕ Pro-soft screwdriver #2x200mm (8.0")
- Heavy duty wire strippers/crimpers 206mm (8.1")
- Measuring tape (5m/16ft)
- 9pcs ball point long arm hex key set:
1/16", 5/64", 3/32", 1/8", 5/32", 3/16", 1/4", 5/16", 3/8"
- Flex head gear wrench:
5/16", 3/8", 7/16", 1/2", 9/16", 5/8", 3/4"
- 3-3/4 autorange digital multimeter
- Ball peen hammer with fiberglass handle
- Utility component storage box
- Plastic pipe cutter Ø6mm~25mm (Ø0.24"~1.4")
- All purpose snip
- Aluminum frame tool case w/2 pallets
- Case size (O.D): 486x325x159mm (19.1"x12.8"x6.3")
- Individual packing: Color box



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

PK-15308EM contents

3-3/4 autorange digital multimeter
23 pcs 1/4" driver socket set
Heavy duty curved-claw hammer W/fiberglass handle
8" Adjustable wrench
IC extractor
Hobby vise
Slip-channel pump pliers 254mm (10")
⊖ ProSoft Precision Screwdriver 2.0x50mm (2.0")
⊖ ProSoft Precision Screwdriver 2.4x75mm (3.0")
⊖ ProSoft Precision Screwdriver 3.0x100mm (4.0")
⊕ ProSoft Precision Screwdriver #00x50mm (2.0")
⊕ ProSoft Precision Screwdriver #0x75mm (3.0")
⊕ ProSoft Precision Screwdriver #1x150mm (6.0")
Wire Stripper Cutter
⊖ Pro-Soft Screwdriver 5.0x75mm (3.0")
⊕ Pro-Soft Screwdriver #1x75mm (3.0")
⊖ Pro-Soft Screwdriver 5.0x100mm (4.0")
⊕ Pro-Soft Screwdriver #1x100mm (4.0")
⊖ Pro-Soft Screwdriver 6.0x100mm (4.0")
⊕ Pro-Soft Screwdriver #2x100mm (4.0")
⊖ Pro-Soft Screwdriver 6.0x40mm (1.6")
⊕ Pro-Soft Screwdriver #5x40mm (1.6")
⊕ Pro-Soft Screwdriver #2x250mm (9.8")
⊖ Pro-soft screwdriver 5.0x75mm (3.0")
⊕ Pro-soft screwdriver #1x75mm (3.0")
⊖ Pro-soft screwdriver 5.0x100mm (4.0")
⊕ Pro-soft screwdriver #1x100mm (4.0")
⊖ Pro-soft screwdriver 6.0x100mm (4.0")
⊕ Pro-soft screwdriver #2x100mm (4.0")
⊕ Pro-soft screwdriver #2x250mm (9.8")
⊖ Pro-soft screwdriver 6.0x40mm (1.6")
⊕ Pro-soft screwdriver #2x40mm (1.6")
Fine tip straight tweezer
Utility component storage box
Long nose plier 135mm (5.3")
Diagonal cutting plier 110mm (4.3")
Lineman's plier 165mm (6.5")
Dual color cutting plier
Dual color long nose plier
9 pcs ball point long arm hex key set
10 pcs electronic combination wrench (inch)
5 pcs needle file set
Ceramic Soldering Iron 110V
Desoldering braid
Solder core 63%, SN
PVC insulated tape
Utility knife (3 blades self loading)
Measuring tape 3M/10FT
All Purpose Snip
Desoldering pump
Flux bottle (2 pcs/pack)
Blow brush (Ø62mm/Ø2.4")
Telescopic magnetic pick up tool
Inspection mirror
1pc Pallet
Heavy-duty ABS cases with wheels and telescoping handle



PK-15308EM

Field and Maintenance Service Kit



- Case size (O.D): 465x335x190mm (18.3"x13.2"x7.5")
- Individual packing: Color box
- Not designed to be checked as airline baggage.



Replaces 902-126 kit



• NOTE : For quality reason. we reserve the right to change the above specifications without notice.

ESD STATIC PROTECTION

MAGNIFICATION/ LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/ DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS

▶ PK-9102 110 Punch Down Tool Bundle



- Combines Pro'sKit prime selections, providing expert quality and durability
- For 110/88-style jacks and patch panels use

PK-9102 contents

Wire Stripper Tool
UTP/STP Multiconductor cable from 3.2~9mm(0.13"~0.35")max.
Punch Down Tool 110/88

- **Individual packing: Double blister card**

▶ PK-9103 DIY Crimp Bundle for Phone & Computer



- Great value for money
- Varied selections of tools for easy operation

PK-9103 contents

Wire Stripper Tool
UTP/STP Multiconductor cable from 3.2~9mm(0.13"~0.35")max.
Modular Crimping Tool
8P8C, 6P6C, 6P4C, 6P2C
RJ-45 Connector (10 pcs / bag)
RJ-11 Connector (10 pcs / bag)

- **Individual packing: Double blister card**

▶ PK-9104 Weatherproof Compression Tool Bundle



- Excellent durability and flexibility
- Combines varied selections of tools for easy operation
- Made of high quality materials with longer product life

PK-9104 contents

All Purpose Snip
Coaxial Stripping Tool For RG-58, 89, 62 & 6 type
Compression Connector Crimping Tool For RG-59 & 6,
Compressed distance: 0.8"±0.06"
F Type Connector for RG6 Quad Coaxial (10 pcs / bag)

- **Individual packing: Double blister card**

▶ PK-9105 Network Tool Bundle



- Highly integrated combinations of network tools offers great convenience
- Total solution for cutting, stripping and crimping jobs.
- Structured of high quality materials with outstanding mechanism design for comfort and easy operation

PK-9105 contents

Wire Stripper Tool
UTP/STP Multiconductor cable from 3.2~9mm(0.13"~0.35")max.
Modular Crimping Tool
8P8C, 6P6C, 6P4C, 6P2C
Punch Down Tool 110/88
RJ-45 Connector (10 pcs / bag)
RJ-11 Connector (10 pcs / bag)

- **Individual packing: Double blister card**

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

500-045 contents

Modular plug crimping tool
 economy UTP stripper
 Modular plug 50pcs

- Individual packing: Blister card



500-045 Modular Crimp Tool Bundle



500-001 contents

Crimper tool
 Rotary coaxial cable stripper
 Round cable cutter
 Screwdriver #1x125

DIE:
 .255", .213", .187", .068" (Hex)
 .319", .256", .213", .068" (Hex)
 .043" (SQ), .100", .213", .068", .137", .255" (Hex)
 .042" (SQ), .078", .151", .068", .128", .178" (Hex)
 .10", .128", .429"

Carrying case

- Case size: 305x210x58mm (12.0"x8.3"x2.3")
- Individual packing: Color label shrink



500-001 Coaxial Crimping Tool Kit



500-031 contents

RJ-45 die set
 RJ-11 die set
 RJ-11 DEC die set
 AMP RJ-45 die set
 RJ-22 die set
 Supercrimp crimp tool frame
 Punch down tool with 110/66 blades
 Multi-function wire strippers
 6-position 4 contact flat stranded (50 pcs/bag)
 8-position 8 contact round stranded (25 pcs/bag)
 Blowing case

- Case size: 340x250x65mm (13.4"x9.8"x2.6")
- Individual packing: Color label shrink



500-031 Professional Twisted Pair Installer Kit



500-021 contents

Multi-network cable tester
 Punch down tool with 110/66 blades
 Modular crimping tool
 UTP/STP cable stripper
 4-position 4 contact flat stranded (50 pcs/bag)
 8-position 8 contact round stranded (25 pcs/bag)
 RJ-45 protection cap. (20 pcs/bag)
 Zippered carrying bag

- Case size: 280x197x70mm (13.4"x9.8"x2.6")
- Individual packing: Inner box & Color label shrink



500-021 Category 5 Termination Kit



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

▶ 902-297 DataGo Kit



902-297 contents

Modular plug 8P8C round cable, solid wire, 50u"(unit:10 pcs/bag)

Pro-crimper modular tool

Punch down tool with 110/66 blades

Multi-modular cable tester

Wire stripper tool

Spare pocket and tool holders allow user to expand the tool kit usage as they learn new applications

Zipper bag

- Case size: 305x255x75mm (12"x10"x3")
- Individual packing: Color label shrink

▶ MT-7810 Satellite Finder Kit



For Satellite test



- 950-2400 MHz bandwidth, high sensitivity, and perfect for setting up satellite dishes anywhere you want.
- Pocket size and lightweight, built-in light for night dish adjustment
- Audible tune-in signal makes it easy and quick to find the best signal reception by changing the antenna direction.

MT-7810 Contents


Satellite Finder

Lensatic Compass

15V DC battery pack (Battery not included)

6ft RF jumper cable

- Individual packing: Plain box+Color label

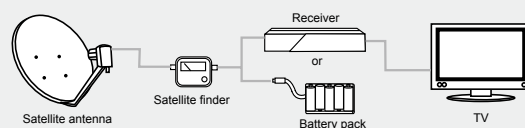

▶ PK-2097 Satellite Installation Tool Kit



PK-2097 contents

Pro-Crimper For CATV F Connectors RG59,6

Rotary Coaxial Cable Stripper (RG-58/59/62/ 3C2V/4C/5C)

Dual Color Side Cutting Plier 165mm (6.5")

Electronic Hex Nut Driver Set

8Pcs Bits Pack

⊖ 6.0 ⊕ #1 ⊕ T10,T15,T8 ⊕ M5,M6,M7

8" Adjustable Wrench

Electrician's Knife 190mm (7.5")

Satellite Finder Kit

Zippered carrying bag

- Case size: 311x216x60mm (12.2"x8.5"x2.4")
- Individual packing: Color box

902-301 contents

Coax flaring tool

Round cable cutter (165mm)

Universal stripping tool(UTP/STP/RG-59/6/7/11)

Compression tool for RG59/RG6/RG11 type waterproof connectors

Pocket cable tone tester

Zippered carrying bag with room for expansion

- Case size: 305x255x75mm (12"x10"x3")
- Individual packing: Color label shrink



902-301

Professional Satellite and Cable TV Compression Kit



902-300 contents

Universal stripping tool(UTP/STP/RG-59/6/7/11)

Coax flaring tool

Waterproof connector crimping tool for RG-59(4c),RG-6(5c)

Pocket cable tone tester

Zipper bag

- Case size: 305x152x165mm (12"x6"x6.5")
- Individual packing: Color label shrink



902-300

Satellite and Cable TV Compression Kit



902-310 contents

Coax flaring tool

Round cable cutter (165mm)

Universal stripping tool(UTP/STP/RG-59/6/7/11)

Compression tool for RG59/RG6/RG11 Type waterproof connectors

Zipper bag

- Case size: 305x152x165mm (12"x6"x6.5")
- Individual packing: Color label shrink



902-310

Universal Compression Kit



ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

▶ 500-006

Network Maintenance Kit**500-006 contents**

Diagonal cutting nipper
 Long nose plier
 6" Adjustable wrench
 Quick heat ceramic soldering iron 110V
 6" Straight forceps
 For crimping coax connectors
 Rotary coaxial cable stripper
 ● Pro-soft s/d 3/16"(inch)
 ● Pro-soft s/d 1/4"(inch)
 ● Pro-soft s/d T10
 ● Pro-soft s/d T15
 ● Pro-soft s/d T20
 ⊖ Pro-soft s/d 3.2x75mm (3.0")
 ⊕ Pro-soft s/d #0x75mm (3.0")
 ⊖ Pro-soft s/d 5.0x75mm (3.0")
 ⊕ Pro-soft s/d #1x75mm (3.0")
 ⊖ Pro-soft s/d 6.0x100mm (4.0")
 ⊕ Pro-soft s/d #2x100mm (4.0")
 Precision wire stripper
 Desoldering pump
 Pro-crimper modular tool
 IC extractor
 Mini flash light
 7 pcs folding type hex key set (inch)
 Inspection mirror
 Zippered carrying bag

- Case size: 375x250x60mm (14.76"x9.84"x2.36")
- Individual packing: Inner box & Color label shrink

▶ 500-018

Master Network Installation Kit**500-018 contents**

RJ-45 die set
 RJ-11 die set
 RG-58, RG-59/62, BNC/TNC die set
 Supercrimp crimp tool frame
 Multi-network cable tester
 Round cable cutter
 Rotary coaxial stripper
 Precision wire stripper
 Punch down tool with 110/66 blades
 Mini flash light
 7 pcs folding type hex key set (inch)
 Extension blade 7" (175mm)
 ● Nut blade:
 1/4", 3/8", 3/16", 7/16", 11/32", 5/16" (inch)
 ● Driver blade T6
 ● Driver blade T7
 ● Driver blade T8
 ● Driver blade T9
 Super torque ratchet handle
 8 pcs screwdriver blades:
 ⊕ #0, #1, #2 ⊖ 3, 5, 6mm ● T10, T15
 Inspection mirror
 Zippered carrying bag

- Case size: 375x250x60mm (14.76"x9.84"x2.36")
- Individual packing: Inner box & Color label shrink

902-241 contents

- All-in-one toner & probe kit
- Pro-crimper modular tool
- Impact & punch down tool
- Universal stripping tool (UTP/STP, RG-59/6/7/11)
- 6-in-1 magnetic quick change screwdriver
- All purpose snip
- Zippered carrying bag
- Case size: 333x210x50mm (13.1"x8.3"x2.0")
- Individual packing: Inner box & Color label shrink

▶ 902-241 Cable Service Kit


Copper cabling detecting, including shielded (STP) and UTP cable



10 Base-T or 10/100 Base-T datacom networks



Locates and isolates cables quickly and easily

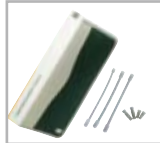

Accessories:
1 zipper bag,
2 RJ-45 cables,
2 BNC connectors, and
2 RCA connectors

902-298 contents

- Wire stripper tool
- In-line modular adapters 4/6/8 pin 3in1
- All-in-one toner & probe kit
- Punch down tool with 110/66 blades
- Modular crimping tool
- Zippered carrying bag
- Case size: 305x255x75mm (12"x10"x3")
- Individual packing: Color label shrink

▶ 902-298 DataTel Pro Kit

- Detec 10Mb and 100Mb Ethernet signals
- Tone, trace and test all telephone, and data cables with the Universal Cable Tester including USB, and Modular Plug cables
- Tap into data and telephone lines for monitoring and testing using the 8-way modular adaptor with all patch cables included

PK-4012 HDTV Video RF Coaxial Cable Tool Kit



New



- PK-4012 contents**
- Die Set (SQ.041",HEX.068",.178",.255",.278")
 - Die Set (SQ.042",HEX.197",.278")
 - Die Set (SQ.042",HEX.068",.275",.278")
 - Die Set (SQ.042",.052", HEX.068",.255",.324")
 - Die Set (SQ.042",HEX.178",.275")
 - Die Set (SQ.042", HEX.068",.0178",.197",.255")
 - Supercrimp Crimp Tool Frame
 - Rotary Coaxial Cable Stripper(RG-58/59/62/3C/4C)
 - Rotary Coaxial Cable Stripper(RG-58/59/62/3C2V/4C/5C)
 - Forged Cable Cutter 160mm(6.3")
 - All-in-one Toner & Probe Kit
 - Zippered carrying bag

- Case size: 311x216x60mm (12.2"x8.5"x2.4")
- Individual packing: Color box




Copper cabling detecting, including shielded (STP) and UTP cable



10 Base-T or 10/100 Base-T datacom networks



Locates and isolates cables quickly and easily

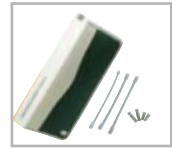

Accessories:
1 zipper bag,
2 RJ-45 cables,
2 BNC connectors, and
2 RCA connectors

902-296 Premise Pro Kit



- 902-296 contents**
- 4P/6P/8P telcom crimping tool
 - Punch down tool with 110/66 blades
 - All-in-one toner & probe kit
 - In-line modular adapters 4/6/8 pin 3 in 1
 - Compression tool for RG59/RG6/RG11 type waterproof connectors
 - Universal stripping tool(UTP/STP/RG-59/6/7/11)
 - Zipper bag

- Case size: 305x255x75mm (12"x10"x3")
- Individual packing: Color label shrink



Copper cabling detecting, including shielded (STP) and UTP cable



10 Base-T or 10/100 Base-T datacom networks



Locates and isolates cables quickly and easily



Accessories:
1 Zipper bag,
2 RJ-45 cables,
2 BNC connectors, and
2 RCA connectors

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

500-027 contents

- Network cable tester(patch cord not include)
- Side cutter 125mm (4.92")
- Long nose plier 138mm (5.43")
- RJ-45 die set
- RJ-11 die set
- AMP RJ-45 die set
- RG-58, RG-59/62, BNC/TNC die set
- Supercrimp crimp tool frame
- Multi-network cable tester
- Round cable cutter
- Rotary coaxial stripper
- Wire stripper tool
- Precision wire stripper
- Punch down tool with 110/66 blades
- 7 pcs folding type hex key set (inch)
- A roll of Cat.5 STP24x4P (7/0.2) length: 10M
- A roll of Cat.5 UTP24x4P (7/0.2) length: 10M
- 1pc pallet
- ABS tool carrying case w/1 pallet
- Case size: 435x310x153mm (17.13"x12.2"x6.02")
- Individual packing: Color box

500-020 contents

- Network cable tester (patch cord not include)
- Side cutter 125mm (4.92")
- Long nose plier 138mm (5.43")
- RJ-45 die set
- RJ-11 die set
- RG-58, RG-59/62, BNC/TNC die set
- RJ-22 die set
- RG-58, RG-59/62 AU BNC/TNC die set
- Supercrimp crimp tool frame
- Desoldering pump
- Quick heat ceramic soldering iron 110V
- 6" Curved forceps
- Multi-network cable tester
- Round cable cutter
- Rotary coaxial stripper
- Desoldering braid
- Precision wire stripper
- Punch down tool with 110/66 blades
- Mini flash light
- 7 pcs folding type hex key set (inch)
- Blowing brush
- Extension blade 7" (175mm)
- Nut blade:
1/4", 3/8", 3/16", 7/16", 11/32", .5/16"
- Super torque ratchet handle
- 8 pcs screwdriver blades:
⊕ #0, #1, #2 ⊖ 3, 5, 6mm ⊕ T10, T15
- ⊕ Driver blade T6
- ⊕ Driver blade T7
- ⊕ Driver blade T8
- ⊕ Driver blade T9
- Wrist strap 10FT
- Inspection mirror
- 3- 3/4 autorange digital multimeter
- 2pcs pallets
- ABS tool carrying case w/1 pallet
- Case size: 435x310x153mm (17.13"x12.2"x6.02")
- Individual packing: Color box



500-027

Master Network Installation Tool Kit



500-020

Master Network Installation Tool Kit



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS

▶ 902-299 VoIP Kit



902-299 contents

- 6" Long nose plier
- 6" Side cutting plier
- Utility component storage box
- Probe-pic spudger
- 6 In 1 magnetic quick change screwdriver
- Telecom mini-test set
- Connector-crimping plier
- Double end socket can wrench
- 3 in 1 Wire stripper tool
- In-line modular adapters 4/6/8 pin
- All-in-one toner & probe kit
- Punch down tool with 110/66 blades
- 4P/6P/8P telcom crimping tool
- Deluxe portable tool bag

- Case size: 390x250x245mm (15.4"x9.8"x9.6")
- Individual packing: Color label+shink

PK-4302AI contents

Dual Color Side Cutting Plier 165mm (6.5")

Dual Color Long Nose Plier 165mm (6.5")

Soldering Iron 30W (110V)

Die Set for RJ45/8P8C

Die Set for RG 58,59,62,6

Die Set for RG 59, 6, F Type

Die Set for Fiber optic connector

Supercrimp Crimp Tool Frame

Wire Stripper Tool

Pen Solder 63%

Pro-Soft Screwdriver \bullet 3/16"(inch)

Pro-Soft Screwdriver \bullet 1/4"(inch)

Pro-Soft Screwdriver \bullet 3.0x75mm (3.0x3.0")

Pro-Soft Screwdriver \oplus #0x75mm (#0x3.0")

Pro-Soft Screwdriver \bullet 5.0x100mm (5.0x4.0")

Pro-Soft Screwdriver \oplus #1x100mm (#1x4.0")

Pouch Down Tool with 110 Blades

Ball Peen Hammer

Wire Stripping Tool for 0.5, 1.2,1.6,2.0mm

Utility Knife (3 Blades Self Loading)

Measuring Tape (3M/10FT)

Desoldering Pump

7 pcs Folding Type Hex Key Set (inch)

3 1/2 Compact Digital Multimeter

Multi-Modular Cable Tester

Utility Component Storage Box

All Purpose Snip

Aluminium Frame Tool Case W/1 Pallet

- Case size: 458x330x150mm (18.0"x13.0"x5.9")
- Individual packing: Color box



PK-4302AI

PC Networking Tool Kit



New



ESD STATIC PROTECTION

MAGNIFICATION/LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES


TOOL KITS

• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

- PK-2016 contents**
- Telecom test set
 - Punch down tool with 110/66 blades
 - Cable splicing knife
 - Electrician scissors
 - Tone probe kit
 - Soft sided tool pouch
 - Case size: 390x190x85mm (15.35"x7.48"x0.33")
 - Individual packing: Color box

Ideal for installing, maintaining, and troubleshooting voice networks

The handy pouch includes essential telecom tools, built for communication installers, telecom installers, and telephone linesmen In this handy belt kit.

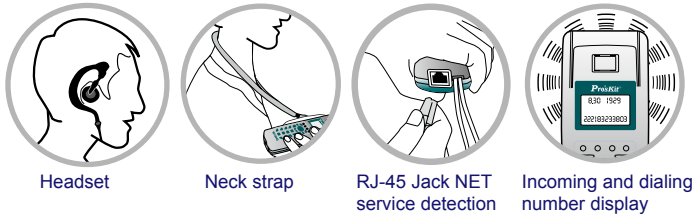

- PK-4022EI contents**
- Telecom test set
 - 6" straight forceps
 - Electrician's knife
 - 5" cutting plier
 - 5.5" long nose plier
 - 6" long nose plier 170mm (6.7")
 - Probe-pic spudger
 - Electrician scissors
 - Double-end screwdriver
 - ⊕ Pro-soft screwdriver #1x75mm (3.0")
 - ⊕ Pro-soft screwdriver #2 6x100mm (4.0")
 - ⊖ Pro-soft screwdriver 8x150mm (6.0")
 - ⊖ Pro-soft screwdriver 6x150mm (6.0")
 - Precision wire stripper (AWG 30/28/26/24/22/20)
 - Punch down tool with 110/66 blades
 - Tone probe kit (battery not include)
 - In-line modular adapters 4/6/8 pin 3 in 1
 - 8 pcs folding hex key set
 - Soldering iron 110V
 - Double end socket can wrench
 - 2 pcs pallets
 - Deluxe carry bag with 2 pallets
 - Case size: 435x325x90mm (17.13"x12.8"x3.54")
 - Individual packing: Color box

Ideal for installing, maintaining, and troubleshooting voice networks, A convenient way for carrying tools inside the PVC handbag provides handy and compact usage to installers. PK-4022EI is a good choice for communication installers, telecom installers, and telephone linesmen.

PK-2016 Belted Telecom Maintenance Kit



PK-4022EI Deluxe Telecom Installer's Kit



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

▶ PK-12012H Telecom Installation Kit



Replaces 500-046 kit



Dual purpose belt for easy carrying on shoulder or waist

PK-12012H contents

- Dual color long nose plier 136mm (5.4")
- Dual color diagonal cutting plier 125mm (4.9")
- Professional modular plug tool crimps strips & cuts
- Punch down tool 110 blade
- Multi-modular cable tester
- Butt set
- ⊖ pro-soft screwdriver 5x75mm (3.0")
- ⊖ pro-soft screwdriver 6x100mm (4.0")
- ⊕ pro-soft screwdriver #2x100mm (4.0")
- ⊕ pro-soft screwdriver #2x40mm (1.6")
- Soft side tool pouch
- Case size: 305x235x95mm (12"x9.3"x3.7")
- Individual packing: Color box

▶ 500-043 Communications Maintenance Kit



500-043 contents

- Reverse action tweezer
- Spring hook
- 3 pcs anti-static alignment tool kit
- Micro cutting plier
- Diagonal cutting nipper
- Long nose plier
- Long nose plier 165mm (6.5")
- 6" Adjustable wrench
- Probe-pic spudger
- 5" Straight forceps
- Tone probe kit
- Replacement blade-110
- 6 pcs electronic screwdriver set
- Precision wire stripper
- Insertion/extraction tool
- Mini flash light
- 7 pcs folding type hex key set (inch)
- Impact & punch down tool w/o blade
- 6" Steel ruler
- Extension blade 7" (175mm)
- Super torque ratchet handle
- 8 pcs screwdriver blades:
 - ⊕ #0, #1, #2 ⊖ 3, 5, 6mm ⊕ T10, T15
- 7 pcs nut driver blades:
 - ⊖ 1/4", 3/8", 3/16", 5/16", 7/16", 11/32", 1/2" (inch)
- Double ended screwdriver ⊖ 3mm/⊕ #0
- Wrist strap 10FT
- Measuring tape 3M/10FT
- Electrician's scissors
- Inspection mirror
- Butt set
- Dual telephone line tester
- Electrician's knife
- Slip-channel pump pliers 204mm (8.03")
- 2 pallets
- Deluxe carrying bag
- Case size: 435x325x90mm (17.13"x12.8"x3.54")
- Individual packing: Plain box + Color label



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

ESD STATIC PROTECTION

MAGNIFICATION/ LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/ DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS

Designed specially for telecom installer, network and cable television engineers. A convenient way for carrying tools inside the rugged ABS tool case provides convenience to installers.

PK-4023EI

Master Telecom Installation and Service Kit



PK-4023EI contents

- Desoldering braid with 2.0mm
- Blowing brush
- Rotary Coaxial Stripper
- 2 pallets
- 7" Extension blade (175mm)
- Driver blade T6
- Driver blade T7
- Driver blade T8
- Driver blade T9
- 8 pcs screwdriver blades
 - ⊕ #0, #1, #2 ⊖ 3, 5, 6mm ⊕ T10, T15
- Wrist strap 10FT
- Nut blade: 1/4", 3/8", 3/16", 7/16", 11/32", 5/16"(inch)
- Super torque ratchet handle
- 5" cutting pliers
- 5.5" long nose pliers
- 8" lineman's pliers (215mm/8.46") black oxide finish
- Professional 3 3/4 auto-ranging digital multimeter
- All purpose snip
- 6" Adjustable wrench
- 8.7" fiber optic crimping tool
- 8 pcs folding hex key set
- 10" Adjustable wrenches
- Double end socket can wrench
- Utility knife(3 blades self loading)
- Punch down tool with 110/66 blades
- 4P/6P/8P Telecom crimping tool
- Testing screwdriver
- Utility component storage box
- Soldering iron 110V
- Precision wire stripper (AWG22/20/18/16/14/12/10)
- All-in-one toner & probe kit
- Telecom test set
- Tool case W/1 pallet
- Case size (O.D): 463x331x171mm (18.2"x13.0"x6.7")
- Individual packing: Color box



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.



902-242

Deluxe Telecom Installation Kit



902-242 contents

- All purpose snip
 - Double end socket can wrench
 - 8 pcs folding hex key set
 - Electrician's knife
 - 6" Long nose plier black oxide finish
 - Dual color diagonal cutting plier (110mm/4.33")
 - Micro cutting plier
 - 6" Adjustable wrench
 - Probe-pic spudder
 - Electrician's scissors
 - ⊖ Pro-soft screwdriver 6.0x100mm (4.0")
 - ⊕ Pro-soft screwdriver #2x100mm (4.0")
 - ⊖ Pro-soft screwdriver 5.0x100mm (4.0")
 - ⊕ Pro-soft screwdriver #1x100mm (4.0")
 - Double-end screwdriver
 - Precision hand drill
 - 23 pcs 1/4" driver socket set
 - All-in-one toner & probe kit
 - In-line modular adapters 4/6/8 pin 3 in 1
 - Punch down tool with 110/66 blades
 - Heavy duty curved-claw hammer W/Fiberglass handle
 - Fish tape (50FT)
 - Velcro cable tie-5" assortment (15 pcs/pack)
 - 10 pcs electronic combination wrench (Inch)
 - Utility component storage box
 - Pro-crimper (frame only)
 - Die set for CP-372G 8P8C/RJ45 plug & cable O/D around 5.2ø
 - Die set for CP-372O RG 58, 59, 62, 174
 - Die set for CP-372T CATV F connectors RG 59, 6
 - Hi-reliability tape measure 3M/10Ft
 - 6" straight forceps
 - 2 pallets
 - Aluminum frame tool case with second pallet
- Case size: 461x331x150mm (18.15"x13.03"x5.91")
 - Individual packing: Color box



• NOTE : For quality reason, we reserve the right to change the above specifications without notice.

ESD STATIC PROTECTION

MAGNIFICATION/ LIGHTING

FIBER OPTICS

POWER TOOLS

INSTRUMENT CASE

MISCELLANEOUS

LAN/ DATACOMM

CONNECTORS

WIRING INSTALLATION

TOOL CASES

TOOL KITS



PK-4028AI Telecom & Network Installation Tool Kit



PK-4028AI contents

- 5 PCS Needle File Set
 - Pro-Crimper (Frame only)
 - Die Set, RJ11
 - Die Set, RJ45 modular plugs 8 position(Standard plugs,not AMP)
 - Punch down tool (with 110 blades)
 - Replacement Blade for CP-3140 with 66 Type
 - Die Set for CP-372T CATV F Connectors RG 59,6
 - Die Set for CP-372S RG 58,59,62,6
 - Utility Knife(3 Blades Self Loading)
 - Electrician's Scissors
 - Desoldering Pump
 - LED Flash Light
 - 6" Adjustable wrenches
 - PVC Insulated tape
 - Contact Voltage Tester
 - 8" Combination Plier
 - 6" Side Cutting Plier
 - 6" Long Nose Plier
 - Quick Heat Ceramic Soldering Iron 110V
 - 8" Groove Joint Plier
 - ⊕ Pro-Soft Screwdriver 5x75mm (3.0")
 - ⊕ Pro-Soft Screwdriver #1x75mm (3.0")
 - ⊕ Pro-Soft Screwdriver 6x100mm (4.0")
 - ⊕ Pro-Soft Screwdriver #2x100mm (4.0")
 - ⊕ Pro-Soft Screwdriver 6x40mm (1.6")
 - ⊕ Pro-Soft Screwdriver #2x40mm (1.6")
 - Wire Stripper Tool
 - Measuring Tape (3M/10FT)
 - 9pcs Ball Point Long Arm Hex Key Set:
1/16", 5/64", 3/32", 1/8" 5/32", 3/16", 1/4", 5/16", 3/8"
 - Cable Sniffer-Remote
 - In-Line Modular Adapters 4/6/8 Pin 3 In 1
 - Ball Peen Hammer with Fiberglass Handle
 - All Purpose Snip
 - Soft Side Tool Pouch
 - 2 pallets for PK-4028 Series
 - Aluminum Frame Tool Case W/2 Pallets
- Case size: 486x325x159mm (19.13"x12.8"x6.26")
 - Individual packing: Color box



Pro'sKit® Symbols

	Wire spring		Open barrel, non-insulated terminals & lugs		Phillips tamper proof		Temperature °C/°F measurement
	Leaf spring		D-Sub terminal & Non-Insulated Open Barrel Connectors		Clutch		Temperature °C measurement
	Flat		Insulated terminals, Insulated & Uninsulated Flag		Spline		Duty Cycle
	Half-round		Insulated terminals		Square		Relative reference
	Round		RS-232 D-sub round barrel contact pins or sockets		TRI-wing		Continuity buzzer
	Flattening & bending		Insulated & non-insulated wire ferrules		Ball hex		Continuity check
	Gripping		Hex type coaxial & fiber optic connectors		Star		Diode test
	Cutting wires		Oval type coaxial & fiber optic connectors		Square tamper proof		Transistor hFE test
	Stripping wires		Square type coaxial connectors center contact pins		Torx plus 5 star		LED test
	Stripping flat telephone cables		Crimping pressure adjustment		ESD safe		Battery check
	Stripping twisted pair round cables		Ratcheting release knob		Non-magnetic		Inductor check
	2 blade stripping coaxial cables		Ratcheting release trigger		Magnetic		Backlight
	3 blade stripping coaxial cables		Force-saving design		Safety caution		Maximum/Minimum value
	Mini bevel		Ratcheting force-saving design		Insulated		Maximum value hold
	Full flush		Black tip		1KV insulated protection		Data hold
	Extra full flush		Slotted		RoHS directive		Auto power off
	Cross Cut		Phillips		Lead free		Low battery
	Serrated		Torx®		Complied with IEC/EN 60529 IP54 test		Zero-ohm adjuster
	Smooth		Torx® tamper proof		Professional tools		Output terminal
	Crosswise serrated		Hex		Repairing tools		RS232C connector
	4 pin(RJ22) telephone handset plugs		Hex tamper proof		DIY tools		USB connector
	6 pin(RJ11/RJ12) telephone plugs		Nut		DC voltage		Hygrometer
	8 pin(RJ45) modular plugs		Pozidriv		AC voltage		Thermometer
	10 pin(RJ50) modular plugs		Triangle		DC current		Light meter
	Telecom splice connectors		Spanner nut		AC current		Sound level meter
	Pin terminal, insulated & non-insulated ferrules		Spanner		Resistance	Standard Plug Type	
	Insulated & non-insulated wire ferrules		Torq		Frequency		
	Non-insulated terminals & lugs		Wing nut driver		Capacitance		E type AC110~120V

Torx® is a registered trademark of Camcar Textron

All rights reserved. Reproduction in whole or in part in any language without permission is prohibited.
Printed in Taiwan, April, 2011. First Edition
©2011 ProKit's Industries Co., LTD.

INDEX

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
1		2		200-067	25	300-039	47
100-002	54	200-002	28	200-068	35	300-041	47
100-003	26	200-003	59	200-069	35	300-045	47
100-004	26	200-004	61	200-070	59	300-047	47
100-006	25	200-005	61	200-071	28	300-048	47
100-007	27	200-006	36	200-072	59	300-049	47
100-008	54	200-007	58	200-080	28	300-050	47
100-009	41	200-007W	58	200-081	61	300-054	46
100-011	24	200-009	60	200-082	27	300-055	55
100-012	24	200-013	35	200-083	27	300-056	46
100-013	24	200-015	35	200-084	60	300-058	47
100-014	25	200-016	60	200-085	58	300-063	50
100-015	25	200-032	119	200-087	26	300-064	50
100-016	25	200-033	119	200-088	28	300-070	47
100-017	25	200-034	36	200-090	60	300-071	47
100-021	33	200-035	36	200-091	59	300-072	47
100-022	34	200-036	60	200-092	28	300-073	47
100-025	25	200-037	26	3		300-074	51
100-033	34	200-038	33	300-001	48	300-075	53
100-035	41/114	200-039	36	300-002	47	300-077	48
100-039	33	200-040	27	300-003	47	300-077D	48
100-040	26	200-041	27	300-004	50	300-078	50
100-042	26	200-042	62	300-004B	50/51	300-086	49
100-044	26	200-042-100	62	300-005	47	300-087	49
100-046	28	200-043	35	300-007	47	300-088	51
100-049	41	200-045	36	300-009	49	300-089	51
1PK-081-TRI0	78	200-046	35	300-010	49	300-090	51
1PK-081-TRI00	78	200-047	59/114	300-011	54	300-091	52
1PK-081-TRI000	78	200-048	60	300-015	53	300-092	53
1PK-125T	100	200-050	61	300-016	53	300-095	48
1PK-1700NA	170	200-051	61	300-018	50	300-096	46
1PK-1900NA	173	200-053	50/51	300-019	47	300-097	48
1PK-3003D30	48	200-056	24	300-021	47	300-101	48
1PK-3003D31	48	200-057	24	300-022	47	300-102	47
1PK-3003D32	48	200-058	24	300-023	47	300-103	48
1PK-3003D33	49	200-059	24	300-024	47	300-104	48
1PK-3003D34	49	200-060	25	300-028	50	300-105	49
1PK-3003D7	49	200-063	36	300-035	53	300-106	47
1PK-3003FD27	48	200-064	61	300-037	51	300-107	55
1PK-9402	84	200-065	62	300-038	47	300-108	47

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
300-109	47	300-174	49	500-018	180	700-012	64
300-112	47	300-175	49	500-020	183	700-014	65
300-115	47	300-176	49	500-021	177	700-015	64
300-116	47	300-177	48	500-023	115	700-016	65
300-117	47	300-178	48	500-024	78	700-017	64
300-118	47	300-179	48	500-025	165	700-018	65
300-119	47	300-180	48	500-026	168	700-020	64
300-120	47	300-181	48	500-027	183	700-021	64
300-130	47	300-182	48	500-029	169	700-022	64
300-131	47	300-183	48	500-030	171	700-023	64
300-132	48	300-184	49	500-031	177	700-024	65
300-133	48	300-185	49	500-032	168	700-024-25	65
300-134	48	300-186	49	500-037	55	700-025	65
300-141	48	300-187	49	500-041	78	700-025-25	65
300-142	48	300-188	49	500-042	166	700-026	64
300-143	47	300-189	49	500-043	187	700-027	64
300-144	48	300-190	49	500-045	177	700-028	64
300-145	48	300-191	49	500-047	166	700-029	65
300-146	48	300-192	49	5DP-366D-T	72	700-RA50	147
300-147	48	300-193	48	5PT-1201-BAT	117	701-001	149
300-149	53	300-194	48	5PT-1441-BAT	117	701-002	149
300-151	34	300-195	48	5SI-125T-B	69	701-003	149
300-156	52	4		5SI-125T-D	69	701-004	149
300-157	48	400-001	10	5SI-125T-SB	69	701-005	149
300-158	48	400-004	10	5SR-538-FB	37	701-006	149
300-159	48	400-007	11	5SR-538-RB	37	701-007	149
300-160	48	400-011	9	6		701-008	149
300-161	47	400-017	8	600-006	119	701-009	149
300-162	47	400-026	10	600-010	119	701-010	149
300-163	48	400-028	8	6HP-9060	17	701-011	149
300-164	49	400-029	17	6HP-9100	17	701-012	149
300-165	49	400-030	17	6HP-9150	17	701-013	149
300-166	49	400-042	7	6HP-9250	17	701-014	149
300-167	48	400-044	126	6S-2	70	701-015	149
300-168	48	5		7		701-016	149
300-169	49	500-001	177	700-007	64	701-017	149
300-170	49	500-003	167	700-008	64	701-018	149
300-171	49	500-006	180	700-009	64	701-019	149
300-172	48	500-016	167	700-010	64	701-020	149
300-173	48	500-017	169	700-011	64	701-021	149

INDEX

INDEX

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
701-022	149	701-062	149	701-115	149	705-003-BK-25	148
701-023	149	701-063	149	701-116	149	705-003-BK-50	148
701-024	149	701-064	149	701-117	149	705-004-BK	148
701-025	149	701-065	149	701-120	149	705-004-BK-25	148
701-026	149	701-066	149	701-121	149	705-004-BK-50	148
701-027	149	701-067	149	701-122	149	705-004-BU	148
701-028	149	701-068	149	701-130	149	705-004-BU-25	148
701-029	149	701-069	149	701-131	149	705-004-BU-50	148
701-030	149	701-070	149	701-132	149	705-004-GN	148
701-031	149	701-071	149	701-133	149	705-004-GN-25	148
701-032	149	701-072	149	701-998	149	705-004-GN-50	148
701-033	149	701-073	149	702-001	147	705-004-RD	148
701-034	149	701-074	149	702-008	147	705-004-RD-25	148
701-035	149	701-075	149	702-009	147	705-004-RD-50	148
701-036	149	701-076	149	702-013	147	705-004-WH	148
701-037	149	701-077	149	702-018	147	705-004-WH-25	148
701-038	149	701-078	149	702-021	147	705-004-WH-50	148
701-039	149	701-079	149	702-022	147	705-004-YL	148
701-040	149	701-080	149	702-059	147	705-004-YL-25	148
701-041	149	701-081	149	702-063	147	705-004-YL-50	148
701-042	149	701-082	149	702-066	147	705-005-BK	148
701-043	149	701-083	149	702-067	147	705-005-BK-25	148
701-044	149	701-084	149	702-079	147	705-005-BK-50	148
701-045	149	701-085	149	702-080	147	705-006-BK	148
701-046	149	701-086	149	703-001	148	705-006-BK-25	148
701-047	149	701-087	149	703-002	148	705-006-BK-50	148
701-048	149	701-088	149	703-003	148	705-007-BU	148
701-049	149	701-089	149	703-004	148	705-007-BU-25	148
701-050	149	701-090	149	703-005	148	705-007-BU-50	148
701-051	149	701-091	149	703-006	148	705-008-BK	148
701-052	149	701-097	149	703-007	148	705-008-BK-25	148
701-053	149	701-099	149	703-008	148	705-008-BK-50	148
701-054	149	701-100	149	703-009	148	711-AM-1-9	142
701-055	149	701-101	149	705-001-BK	148	711-AS-1-9	142
701-056	149	701-102	149	705-001-BK-25	148	711-FM-1-5	142
701-057	149	701-104	149	705-001-BK-50	148	711-FS-1-2	142
701-058	149	701-111	149	705-002-BU	148	711-HM-1-5	143
701-059	149	701-112	149	705-002-BU-25	148	711-HS-1-2	143
701-060	149	701-113	149	705-002-BU-50	148	711-LM-1-1	143
701-061	149	701-114	149	705-003-BK	148	711-LS-1-1	143

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
711-MM-1-1	143	788-RX50	147	7P-48TK11CEC-BK	133	7PK-318-IV	139
711-MS-1-1	143	7KJ15-C6USBL	135	7PK-300-1IV	138	7PK-318-WH	139
711-PM-1-1	143	7KJ15-C6USWH	135	7PK-300-1WH	138	7PK-342RC6US-DWH	140
711-PS-1-1	143	7KJ15-CEUSBL	135	7PK-300-2IV	138	7PK-342RC6US-MWH	140
712-AAM101-03M	145	7KJ15-CEUSWH	135	7PK-300-2WH	138	7PK-342RCEUS-DWH	140
712-AAS104-03M	145	7KJ3-C3-66IV	136	7PK-300-3IV	138	7PK-342RCEUS-MWH	140
712-FFM101-03M	145	7KJ3-C3-66WH	136	7PK-300-3WH	138	7PMV12T-K11-C6C/BK	134
712-FFS104-03M	145	7KJ8-C6USBK-Y	136	7PK-300-4IV	138	7PMV12T-K11-CEC/BK	134
712-LLM1F01-03M	145	7KJ8-C6USBL-Y	136	7PK-300-4WH	138	7URT-46F4U01M-4B6	137
712-LLS1F04-03M	145	7KJ8-C6USGN-Y	136	7PK-300-6IV	138	7URT-46F4U01M-4B8	137
713-AAM107-03M	145	7KJ8-C6USGY-Y	136	7PK-300-6WH	138	7URT-46F4U02M-4B6	137
713-AAS108-03M	145	7KJ8-C6USIV-Y	136	7PK-301AIV	141	7URT-46F4U02M-4B8	137
713-HHM107-03M	145	7KJ8-C6USRD-Y	136	7PK-301AWH	141	7URT-46F4U50C-4B6	137
713-HHS108-03M	145	7KJ8-C6USWH-Y	136	7PK-302AIV	141	7URT-46F4U50C-4B8	137
713-PPM1F07-03M	145	7KJ8-C6USYL-Y	136	7PK-302AWH	141	7URT-4EF4N01M-4B6	137
713-PPS1F08-03M	145	7KJ8-CEUSBK-Y	136	7PK-315A-C6/BK	141	7URT-4EF4N01M-4B8	137
715-01S1-1	144	7KJ8-CEUSBL-Y	136	7PK-315A-C6/WH	141	7URT-4EF4N02M-4B6	137
715-02S1-1	144	7KJ8-CEUSGN-Y	136	7PK-315A-CE/BK	141	7URT-4EF4N02M-4B8	137
715-03M1-3	144	7KJ8-CEUSGY-Y	136	7PK-315A-CE/WH	141	7URT-4EF4N50C-4B6	137
715-03S1-1	144	7KJ8-CEUSIV-Y	136	7PK-315AS-C6	141	7URT-4EF4N50C-4B8	137
715-07S1-1	144	7KJ8-CEUSRD-Y	136	7PK-315AS-CE	141	8	
715-08M1-3	144	7KJ8-CEUSWH-Y	136	7PK-317BN-IV	138	800-001	84
715-08S1-1	144	7KJ8-CEUSYL-Y	136	7PK-317BN-WH	138	800-002	84
715-10M1-3	144	7MU5-B-IV	139	7PK-317H1-IV	138	800-003	84
715-10S1-1	144	7MU5-BNC-IV	139	7PK-317H1-WH	138	800-004	84
715-12M1-3	144	7MU5-BNC-WH	139	7PK-317H2-IV	138	800-005	84
715-12S1-1	144	7MU5-B-WH	139	7PK-317H2-WH	138	800-006	84
715-15M1-3	144	7MU5-F-IV	139	7PK-317H3-IV	138	800-007	80
715-15S1-1	144	7MU5-F-WH	139	7PK-317H3-WH	138	800-009	80
744-FA03	147	7MU5-ST-IV	139	7PK-317ICON	138	800-010	84
744-FA50	147	7MU5-ST-WH	139	7PK-317V1-IV	138	800-011	84
764-RA03	147	7P-12AK11CEC-BK	132	7PK-317V1-WH	138	800-012	84
764-RX50	147	7P-12TK11C6C-BK	133	7PK-317V2-IV	138	800-013	84
788-FA03	147	7P-12TK11CEC-BK	133	7PK-317V2-WH	138	800-014	84
788-FA50	147	7P-24AK11CEC-BK	132	7PK-317V3-IV	138	800-015	84
788-FX15	147	7P-24TK11C6C-BK	133	7PK-317V3-WH	138	800-016	84
788-FX50	147	7P-24TK11CEC-BK	133	7PK-317V4-IV	138	800-017	84
788-RA03	147	7P-32TK11CEC-BK	133	7PK-317V4-WH	138	800-018	84
788-RA50	147	7P-48AK11CEC-BK	132	7PK-317V6-IV	138	800-019	84
788-RX15	147	7P-48TK11C6C-BK	133	7PK-317V6-WH	138	800-020	84

INDEX

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
800-021	84	800-075	78	800-147	77	900-055	88
800-022	84	800-076	89	800-148	88	900-056	104
800-023	84	800-077	80	800-149	80	900-057	104
800-024	84	800-078	89	800-150	80	900-058	73
800-025	84	800-079	88	9		900-059	73
800-026	84	800-080	90	900-001N	72	900-061	111
800-027	84	800-081	90	900-002	104	900-061-3X	111
800-028	87	800-091	96	900-004	72	900-061B	111
800-029	87	800-092	83	900-005	153	900-061-CLAMP	111
800-030	84	800-092-50	83	900-006N	72	900-062	154
800-032	84	800-114	77	900-008	72	900-063	107
800-033	84	800-115	77	900-011	159	900-064	107
800-034	84	800-116	77	900-012	104	900-065	129
800-035	84	800-117	77	900-015	71	900-066N	67
800-036	84	800-118	77	900-016	70	900-067	97
800-037	84	800-119	77	900-017	128	900-068	97
800-038	84	800-120	77	900-018N	69	900-069	97
800-039	88	800-121	77	900-019	126	900-070	97
800-040	82	800-122	77	900-020N	69	900-071	100
800-041	88	800-123	84	900-022	104	900-072	100
800-042	88	800-124	95	900-023	104	900-073N	67
800-043	84	800-125	96	900-026	61	900-074N	67
800-044	84	800-129	78	900-027	61	900-075	107
800-045	84	800-130	82	900-032	127	900-075A	107
800-046	84	800-131	77	900-033	129	900-076	107
800-047	84	800-132	77	900-035	68	900-077	107
800-048	89	800-133	77	900-036	68	900-078	50
800-048E	89	800-134	77	900-037	71	900-079	107
800-049	88	800-135	77	900-038	95	900-080	107
800-050	88	800-136	77	900-039	123	900-080B	107
800-052	95	800-137	77	900-040	123	900-081	107
800-060	82	800-138	77	900-041	123	900-082	107
800-065	96	800-139	77	900-043	123	900-091A	123
800-066	95	800-140	77	900-044	69	900-094	127
800-067	96	800-141	77	900-045	159	900-096	107
800-068	89	800-142	77	900-048	159	900-098-BK	155
800-070	128	800-143	77	900-049	130	900-098-BU	155
800-072	88	800-144	77	900-050	69	900-098-GN	155
800-073	79	800-145	77	900-052	160	900-098-OR	155
800-074	89	800-146	77	900-054	160	900-098-RD	155

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
900-098-WH	155	900-162B	124	900-246	162	902-024	153
900-098-YL	155	900-162C	124	900-247	74	902-025	153
900-099	70	900-164A	124	900-248	74	902-035	155
900-100	73	900-164B	124	900-249	74	902-049	33
900-101	71	900-167	107	900-250	73	902-054	47
900-103	129	900-168	114	900-251	73	902-068	111
900-106	162	900-169	40	900-252	73	902-068B	111
900-112	40	900-169B	40	900-253	73	902-069	89
900-112B	40	900-175	72	900-254	72	902-070	129
900-113	40	900-176	114	900-255	129	902-071	101
900-113B	40	900-177	130	900-257	40	902-072	100
900-114	104	900-179	130	900-257B	40	902-073	129
900-115	69	900-181	73	900-258	127	902-075	28
900-116	104	900-182	111	900-259	68	902-076	28
900-117	51/60	900-194	90	900-260	161	902-077	28
900-118A	69	900-199	158	900-261	157	902-078	22
900-123	108	900-202	126	900-262	157	902-079	22
900-124	108	900-203	159	900-263	101	902-082	41
900-125	108	900-204	100	900-264	101	902-083	41
900-125B	108	900-205	129	900-265	101	902-084	41
900-126	108	900-206	71	900-266	101	902-085	46
900-132	104	900-212	128	900-267	101	902-086	51
900-133	104	900-215	42	900-268	101	902-087	51
900-135	40	900-216	126	900-269	101	902-088	54
900-137	115	900-217	97	900-270	72	902-090	58
900-138	114	900-219	115	900-271	74	902-091	67
900-140	65	900-222	73	900-272	74	902-092	67
900-141	158	900-223	97	902-011	28	902-093	67
900-142	107	900-224	97	902-012	153	902-094	71
900-146	68	900-225	160	902-013	153	902-095	70
900-147	151	900-229	42	902-014	153	902-096	87
900-147A	107	900-230	73	902-015	153	902-097	87
900-148	151	900-235	107	902-016	153	902-099	85
900-149	151	900-236	107	902-017	153	902-100	95
900-150	126	900-238	72	902-018	153	902-101	95
900-151	126	900-239	107	902-019	153	902-108	109
900-157	114	900-242	70	902-020	153	902-109	110
900-158	129	900-243	70	902-021	153	902-110	110
900-161	72	900-244	7	902-022	153	902-111	118
900-162A	124	900-245	68	902-023	153	902-112	123

INDEX

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
902-113	123	902-186N	114	902-247	58	902-325	60
902-114	123	902-187	68	902-253	39	902-326	60
902-115	72	902-189	42	902-254	162	902-330	49
902-116	130	902-197	151	902-255	128	902-331	49
902-117	130	902-201	47	902-256	128	902-332	49
902-117-JAWS	130	902-202	31	902-257	128	902-334	61
902-118	161	902-203	31	902-260	115	902-334-BLADES	61
902-119	161	902-204	31	902-261	39	902-335	70
902-121	165	902-205	31	902-265	52	902-337	49
902-127	67	902-206	31	902-267	8	9BX-3018B	121
902-128	67	902-207	31	902-268	62	9CP-336DF4	48
902-129	67	902-208	31	902-269	62	9PK-3003D26	48
902-130	67	902-209	85	902-270	51	9PK-3003D27	48
902-131	67	902-210	85	902-275	48	9PK-3003D29	48
902-132	67	902-211	85	902-276	48	9PK-3003D36	49
902-133	67	902-212	85	902-277	47	9PK-3003D42	49
902-134	67	902-213	85	902-278	47	9PT-5201-P2	119
902-135	67	902-214	85	902-279	47	9ST-902	162
902-137	47	902-215	86	902-296	182	B	
902-138	47	902-216	85	902-297	178	BHX1/4X3-1/2	93
902-139	47	902-217	85	902-298	181	BHX1/8X3-1/2	93
902-143	47	902-218	86	902-299	184	BHX2.5X3-1/2	93
902-145	47	902-219	82	902-300	179	BHX2X3-1/2	93
902-146	47	902-220	85	902-301	179	BHX3/16X3-1/2	93
902-147	47	902-221	109	902-303	35	BHX3/32X3-1/2	93
902-148	47	902-222	79	902-305	155	BHX3X3-1/2	93
902-152	47	902-224	127	902-306	37	BHX4X3-1/2	93
902-158	47	902-225	127	902-307	34	BHX5/32X3-1/2	93
902-159	47	902-226	95	902-309	42	BHX5/64X3-1/2	93
902-160	48	902-227	71	902-310	179	BHX5X3-1/2	93
902-161	48	902-228	9	902-311	163	BHX6X3-1/2	93
902-162	48	902-229	62	902-312	163	BHX7/32X3-1/2	93
902-166	48	902-230	42	902-314	163	BHX7/64X3-1/2	93
902-167	47	902-238	108	902-317	39	BHX9/64X3-1/2	93
902-168	48	902-239	108	902-318	39	Bulb-T4	109
902-169	48	902-240	109	902-319	39	Bulb-T5	110
902-171	48	902-241	181	902-321	154	C	
902-172	47	902-242	189	902-322	40	CAT6-100	147
902-173	67	902-245	52	902-323	60	Case001	162
902-174	67	902-246	33	902-324	60	CE-0275	127

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
CP-231	51	HW-312S	97	MT-1232	14	PK-2015	166
CP-3005F	45	HW-5912E	97	MT-1270	14	PK-2016	186
CP-301G	58	HW-928	96	MT-1280	14	PK-2096AI	167
CP-302G	58	HX1.5X1	93	MT-1610	15	PK-2097	178
CP-313	52	HX1/16X1	93	MT-1630	13	PK-4012	182
CP-3145A	65	HX1/16X1-15/16	93	MT-1820	12	PK-4022EI	186
CP-315	52	HX1/4X1	93	MT-1860	12	PK-4023EI	188
CP-3150	64	HX1/8X1	93	MT-3102	16	PK-4027AI	174
CP-336FD27	48	HX1/8X1-15/16	93	MT-3266	16	PK-4028AI	190
CP-351B	55	HX2.5X1	93	MT-4017	15	PK-4302AI	185
CP-367A	59	HX2X1	93	MT-4018	15	PK-6940	115
CP-372FD27	48	HX3/16X1	93	MT-5110	13	PK-6942	115
CP-376M	50	HX3/16X1-15/16	93	MT-5210	13	PK-9102	176
CP-383	153	HX3/32X1	93	MT-7057	10	PK-9103	176
CP-391	152	HX3/32X1-15/16	93	MT-7509	114	PK-9104	176
CP-391-1	152	HX3X1	93	MT-7810	178	PK-9105	176
CP-391-2	152	HX4X1	93	MT-8002	8	PK-ST902	23/165
CP-392	152	HX5/32X1	93	MT-8100	6	PM-023CN	23
CP-392-3	152	HX5/32X1-15/16	93	MTB-1	162	PM-029CN	23
CP-392-4	152	HX5/64X1	93	N		PM-036CN	23
CP-392-5	152	HX5/64X1-15/16	93	NT-302	11	PM-037CN	23
CP-412G	54	HX5X1	93	NT-306	16	PM-046CN	23
CP-413G	54	HX6X1	93	NT-3200	11	PM-053CN	23
CP-415	54	HX7/32X1	93	P		PM-055CN	23
CP-416	53	HX7/32X1-15/16	93	PD-155	126	PM-251	27
CP-463	53	HX7/64X1	93	PD-372	130	PM-252	27
CP-511A	60	HX7/64X1-15/16	93	PD-395A	40	PM-254	27
CP-5S1D	49	HX7X1	93	PD-998	39	PM-721	22
CP-5S2D	49	HX9/32X1-15/16	93	PH0X1	92	PM-723	22
CP-808	52	HX9/64X1	93	PH0X1-15/16	92	PM-727	22
D		HX9/64X1-15/16	93	PH1X1	92	PM-728	22
DK-2053A	151	M		PH1X1-15/16	92	PM-731	21
DK-2112	39	MA-016	107	PH2X1	92	PM-736	21
DP-336D	72	MA-018	109	PH2X1-15/16	92	PM-737	21
G		MA-1205CA-B	111	PH3X1	92	PM-746	21
GS-200K	70	MS-3207	62	PH3X1-15/16	92	PM-754	21
GS-210	70	MS-V308	155	PK-12012H	187	PM-755	21
GS-520	70	MS-V350-BL	155	PK-15307EI	172	PM-923	34
H		MS-V350-WH	155	PK-15308EM	175	PM-931	32
HW-312B	97	MT-1210	14	PK-2013H	165	PM-934	32

INDEX

INDEX

<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>	<u>Cat.#</u>	<u>page</u>
PM-936	32	SD-2400-S6	87	SSP10X1	93	T8HX1-15/16	93
PM-937	32	SD-2400-S8	87	SSP4X1	93	T8X1	92
PM-938	32	SD-2404	87	SSP6X1	93	T8X1-15/16	92
PT-0721A	118	SD-3102	80	SSP8X1	93	T9HX1	93
PT-1136A	118	SD-7213A	87	ST-5203	163	T9HX1-15/16	93
PT-1201A	117	SD-7213B	87	ST-5601	163	T9X1	92
PT-1441A	117	SD-7222A	87	T		T9X1-15/16	92
PT-5201A	119	SD-7222B	87	T10HX1	93	TC-765	158
PT-5721A	119	SD-800-S3.0	85	T10HX1-15/16	93	TS10HX1	92
PZ0X1-15/16	92	SD-800-S5.5	85	T10X1	92	TS15HX1	92
PZ1X1-15/16	92	SD-804	83	T10X1-15/16	92	TS20HX1	92
PZ2X1-15/16	92	SD-804-1	83	T15HX1	93	TZ-202N	99
PZ3X1-15/16	92	SD-807	86	T15HX1-15/16	93	TZ-204N	99
PZ4X1-15/16	92	SD-9312	81	T15X1	92	TZ-205N	99
S		SD-9313	81	T15X1-15/16	92	TZ-212N	99
SB-2419	122	SD-9701M	90	T20HX1	93	TZ-225N	99
SB-2918	121	SD-9802	82	T20HX1-15/16	93		
SB-3218	121	SD-9810A	83	T20X1	92		
SB-3428SB	122	SD-9811	79	T20X1-15/16	92		
SB-4536B	122	SD-9812	81	T25HX1	93		
SD-081E	78	SD-9813M	81	T25X1	92		
SD-0839	77	SD-9814	81	T25X1-15/16	92		
SD-083-P2	77	SD-9815	79	T27HX1	93		
SD-083-P3	77	SD-9824	79	T27HX1-15/16	93		
SD-083-P4	77	SI-125A-15	69	T27X1	92		
SD-083-S3	77	SI-125A-20	69	T27X1-15/16	92		
SD-083-S4	77	SL1012X1-15/16	92	T30HX1	93		
SD-083-S5	77	SL1214X1-15/16	92	T30HX1-15/16	93		
SD-083-T4	77	SL12X1-15/16	92	T30X1	92		
SD-083-T5H	77	SL23X1-15/16	92	T30X1-15/16	92		
SD-083-T6H	77	SL34X1-15/16	92	T5X1	92		
SD-2306M	90	SL45X1-15/16	92	T5X1-15/16	92		
SD-2307M	91	SL56X1-15/16	92	T6X1	92		
SD-2308M	91	SL68X1-15/16	92	T6X1-15/16	92		
SD-2309	91	SL810X1-15/16	92	T7HX1	93		
SD-2310	91	SR-008	36	T7HX1-15/16	93		
SD-2313	90	SR-333	41	T7X1	92		
SD-2400-S10	87	SR-538	37	T7X1-15/16	92		
SD-2400-S4	87	SS-611A	68	T8HX1	93		



Eclipse Enterprises, Inc.

13302 Chula Road, Amelia Court House, VA 23002

Phone: 804-561-2610 Fax: 804-561-2642

Web Site: www.eclipsetools.com