


**CLASS
388 & 283**

SQUARE BASE FLANGE MOUNT RELAYS

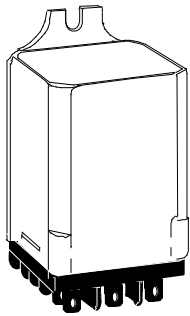

FLANGE MOUNT RELAY
13 AMP CONTACT RATING
.187 Q.C. /SOLDER TERMINALS

UL Recognized
 File No. E43641


UL Recognized to Canadian safety requirements under the Component Recognition Program of Underwriters Laboratories Inc.



COMPLIES WITH REQUIREMENTS OF
 * IEC STANDARDS
 947-4-1 AND 947-5-1
 LOW VOLTAGE DIRECTIVE


* IEC = INTERNATIONAL ELECTROTECHNICAL COMMISSION

TOP FLANGE COVER AVAILABLE ON SPECIAL ORDER. CONSULT FACTORY

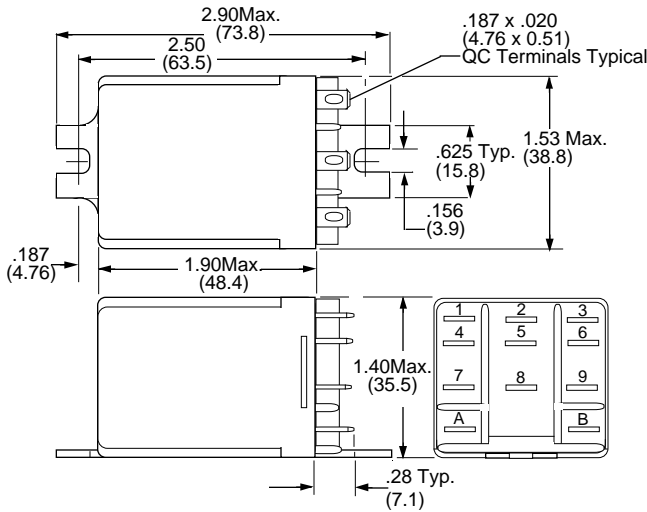

WIRING DIAGRAM

Viewed from terminal end

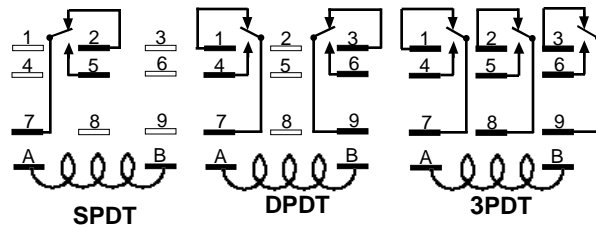

OPTIONAL INDICATOR LAMP AND PUSH TO TEST BUTTON AVAILABLE ON SPECIAL ORDER.

*** RELEVANT IEC CONTACT UTILIZATION CATEGORIES**

CE	AC-1, AC-3, DC-1, AC-15
	(SEE SECTION 11, PAGES 174 & 175 FOR UTILIZATION CATEGORIES.)

Magnecraft & Struthers-Dunn

DUAL MARKED PART NUMBERS	S-D PART NUMBERS	CONTACT CONFIGURATION	COIL Measured @ 25°C			CROSS REFERENCE TO	
			NOMINAL INPUT VOLTAGE	NOMINAL RESISTANCE (OHMS)	NOMINAL POWER	POTTER & BRUMFIELD*	IDEC
AC OPERATED							
W388ACQX-4	A283XAXC1-120A	SPDT	120 VAC	-	2.0VA	KUP5A55 (or F) - 120	RR1BA-US-AC120V
W388ACQX-5	A283XAXC1-240A	SPDT	240 VAC, 60Hz 220 VAC, 50 Hz	-	2.0VA	KUP5A55 (or F) - 240	RR1BA-US-AC240V
W388ACQX-9	A283XBXC1-120A	DPDT	120 VAC	-	2.0VA	KUP11A55 (or F) - 120	RR2BA-US-AC120V
W388ACQX-10	A283XBXC1-240A	DPDT	240 VAC, 60 Hz 220 VAC, 50 Hz	-	2.0VA	KUP11A55 (or F) - 240	RR2BA-US-AC240V
W388ACQX-14	A283XCXC1-120A	3PDT	120 VAC	-	2.75VA	KUP14A55 (or F) - 120	RR3B-US-AC120V
W388ACQX-15	A283XCXC1-240A	3PDT	240VAC, 60Hz 220 VAC, 50Hz	-	2.75VA	KUP14A55 (or F) - 240	RR3B-US-AC240V
DC OPERATED							
W388CQX-2	A283XAXC1-12D	SPDT	12 VDC	120	1.2W	KUP5D55 (or F) - 12	RR1BA-US-DC12V
W388CQX-3	A283XAXC1-24D	SPDT	24 VDC	472	1.2W	KUP5D55 (or F) - 24	RR1BA-US-DC24V
W388CQX-6	A283XBXC1-12D	DPDT	12 VDC	120	1.2W	KUP11D55 (or F) - 12	RR2BA-US-DC12V
W388CQX-7	A283XBXC1-24D	DPDT	24 VDC	472	1.2W	KUP11D55 (or F) - 24	RR2BA-US-DC24V
W388CQX-11	A283XCXC1-24D	3PDT	24 VDC	472	1.2W	KUP14D55 (or F) - 24	RR3B-US-DC24V

*F = GOLD FLASHED

SEE CLASS 388 & 283 GENERAL SPECIFICATIONS FOR COMPLETE SPECIFICATIONS.
 RELAYS CAN BE ORDERED EITHER BY MAGNECRAFT OR STRUTHERS-DUNN PART NUMBERS LISTED ABOVE.
 PART NUMBERS SHOWN ALSO AVAILABLE THRU STOCKING DISTRIBUTION.