



Electrical Commercial and Industrial

- Products
- Documentation & Literature
- News & Tradeshow
- Support

United States > Products & Services > Electronics, Electrical and Communications > Electrical Commercial and Industrial > Products > Electrical Commercial & Industrial Products Catalog > Terminals, Kits and Tools > Terminals > 3M™ Scotchlok™ Female Disconnects > 3M™ Scotchlok™ Female Disconnect Vinyl Insulated, 100/bottle, MVU18-187DFX


[Find An Account Rep](#) [Where To Buy \(Find A Distributor\)](#) [Contact Us](#)

3M™ Scotchlok™ Female Disconnect Vinyl Insulated, 100/bottle, MVU18-187DFX

UPC# 00051128590133 3M Product Number MVU18-187DFX 3M ID 80611466592

• Print

• Share

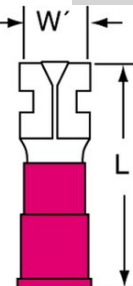

Female Disconnect Vinyl Insulated, 100/bottle, MVU18-187DFX

Need Help?

Network Access Message: The page cannot be displayed

Questions? We can help
[Contact Us](#)

- Overview
- Support

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.085 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Scotchlok
China RoHS - Below MCV	No
Conductor Sizes	22 - 18 AWG
CSA File Number	LR22190
EU RoHS Compliant	Yes
Fastener Orientation	Female
Insulation Material	Vinyl
Length (L)	0.78 Inch
Mates with Male Tab Width (W')	0.187 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	100 per bottle
Pad Width	0.187 Inch
Terminal Style	Standard
Terminal Type	Disconnect
Thickness	0.02 Inch
UL File Number	E70512

People who viewed this item also viewed



3M™ QS Molded Rubber Splice Kit 5408-CI-750, CN and JCN Cable, 15 kV, 750 kcmil, Cable Insulation O.D.



3M™ Scotchlok™ Male Disconnect, Fully Nylon Insulated w/Insulation Grip MNG18-187DMK, 22-18 AWG



3M™ Molded Rubber Splice QS II 5412-CI-2/0, CN and JCN Cable, 15 kV, 1 per case

3M™ Cold Shrink OS



3M™ Cold Shrink OS-III Splice Kit 5456A-250-CU, 250 kcmil, 1 per case

3M™ Cold Shrink Silicone Insulator 8447-3.2, Tape, Wire, Unshield, Standard, 12 per case

