

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022013207](#)
Status: **Obsolete**
Overview: [kk](#)
Description: 2.54mm (.100") Pitch KK® Crimp Terminal Housing, Friction Ramp, 20 Circuits, Use with 2759|41572|6459

Documents:
[Drawing \(PDF\)](#)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	2695
Application	Signal
Overview	kk
Product Name	KK®

Physical

Circuits (maximum)	20
Color - Resin	Natural (White)
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm (.100")
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	0°C to +75°C

Material Info

Old Part Number	2695-20RP
-----------------	-----------

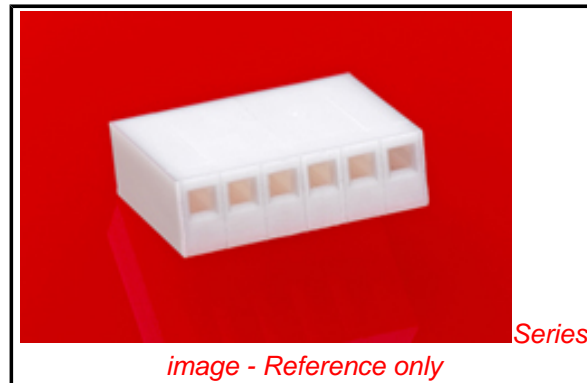


image - Reference only

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[2695Series](#)

Mates With

2.54mm (.100") Pitch KK® PCB Headers
[42375](#) , [42377](#) , [42376](#) , [4030](#) , [6373](#) , [6410](#)

Use With

KK® Crimp Terminal [2759](#) , [6459](#) , [41572](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION