

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0039010043](#)
Status: **Planned for Obsolescence**
Description: 2.50mm (.098") Pitch Wire-to-Board Receptacle Housing, Low Profile, 4 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-5480-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [5480](#)
 Application Signal
 Product Name N/A

Physical


Circuits (maximum) 4
 Color - Resin Natural
 Flammability 94V-0
 Gender Female
 Glow-Wire Compliant No
 Material - Resin Polyester
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.50mm (.098")
 Stackable No
 Temperature Range - Operating -40°C to +105°C

Material Info

Old Part Number 5480-04

Reference - Drawing Numbers

Product Specification PS-5480-001, RPS-5480-001, RPS-5480-002, RPS-5480-003, RPS-5483-001, RPS-5483-002
 Sales Drawing SD-5480-N

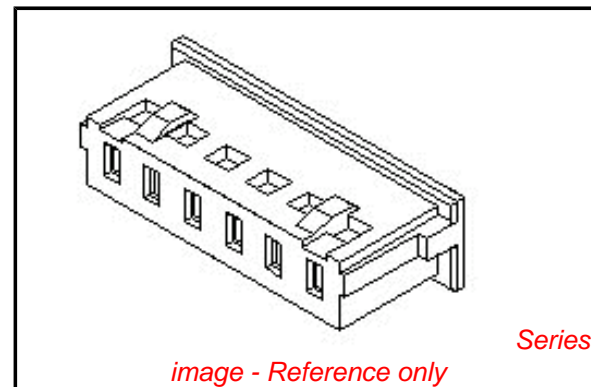

EU RoHS

ELV and RoHS Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

5480Series

Mates With

5483 , 5484

Use With

5479