

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0874380333](#)
Status: **Obsolete**
Description: 1.50mm (.059") Pitch Wire-to-Board Header, Surface Mount, Right Angle, Shrouded, 3 Circuits, Embossed Tape on Reel Packaging
Replacement Part Number: [874380343](#)

Documents:
[Drawing \(PDF\)](#)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	PCB Headers
Series	87438
Application	Signal, Wire-to-Board
Obsolete Date	2005/06/01
Product Name	Pico-SPOX™
Replacement Part Number	874380343

Physical

Breakaway	No
Circuits (Loaded)	3
Circuits (maximum)	3
Durability (mating cycles max)	10
Flammability	94V-0
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.50mm (.059")
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-55°C to +105°C


Electrical

Current - Maximum per Contact	3A
Voltage - Maximum	350V

Solder Process Data

Replacement RoHS Compliant Part Number	0874380343
--	------------

Material Info

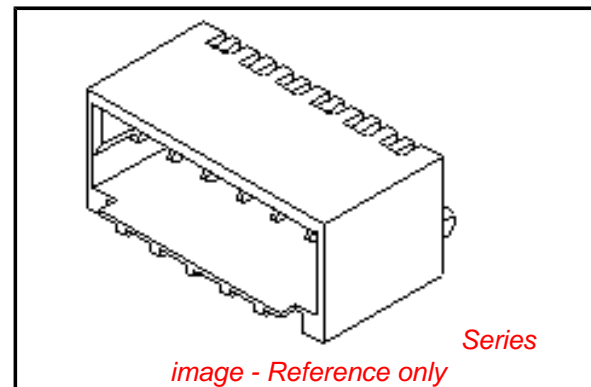

EU RoHS

Not RoHS Compliant
REACH SVHC
 Not Reviewed
Low-Halogen Status
 Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[87438Series](#)

Mates With

[87439](#)