



Extract from the online
catalog

DC-B 6-HB-M

Order No.: 1602038



<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1602038>

DUPLICON, aluminum panel mounting base with open bottom, type B6, IP67 protection, with gasket

Commercial data

EAN	4046356027731
Pack	10 pcs.
Customs tariff	85389099
Weight/Piece	0.11038 KG
Catalog page information	Page 406 (PC-2009)

Product notes

WEEE/RoHS-compliant since:
07/05/2004



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

General data

Design	DC-B6
Height	22 mm
Width	81 mm
Length	81 mm
Color	pearl gray

DC-B 6-HB-M Order No.: 1602038
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1602038>

Locking type	For double locking latch
Protective cover	No
Degree of protection	IP65/IP66/IP67
Ambient temperature (operation)	-40 °C ... 125 °C
Housing material	Aluminum, die-cast
Housing surface material	EMC-conductive
Seal material	NBR
Length of the assembly cutout	55 mm
Width of the assembly cutout	26 mm

Certificates / Approvals




Certification

VDE-PZI

Diagrams/Drawings

Dimensioned drawing

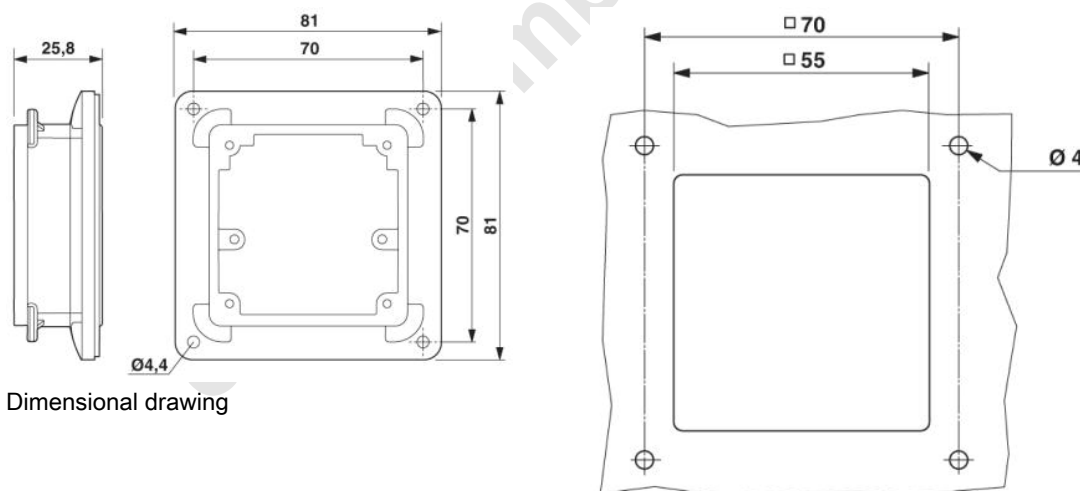

Dimensional drawing

Panel cutout: DC-B 6-HB-M

DC-B 6-HB-M Order No.: 1602038
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1602038>

Address

PHOENIX CONTACT Deutschland GmbH
Flachsmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 12000
Fax +49 5235 3 41200
<http://www.phoenixcontact.de>



© 2010 Phoenix Contact
Technical modifications reserved;

onlinecomponents.com