



Extract from the online catalog

# HC-B 24-AMQ-EMV

Order No.: 1642962



<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1642962>

HEAVYCON panel mounting base B24, with double locking latch, EMC version. Not suitable for D series terminal adapters

Commercial data	
EAN	4046356028608
Pack	10 pcs.
Customs tariff	85389099
Weight/Piece	0.1922 KG
Catalog page information	Page 519 (PC-2009)

### Product notes

WEEE/RoHS-compliant since:  
07/03/2006



<http://www.download.phoenixcontact.com>  
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

## Technical data


General data	
Note	For contact inserts HC-B24, BB46, D64, DD108, M
Design	B24
Height	30.5 mm
Width	48 mm

HC-B 24-AMQ-EMV Order No.: 1642962  
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1642962>


Length	140 mm
Housing type	EMC housings
Locking type	With double locking latch
Degree of protection	IP65
Ambient temperature (operation)	-40 °C ... 100 °C
Housing material	Aluminum, die-cast
Housing surface material	EMC coating, silver
Seal material	NBR, conductive
Locking latch material	Steel, galvanized
Length of the assembly cutout	108 mm
Width of the assembly cutout	35 mm

## Drawings

### Diagram

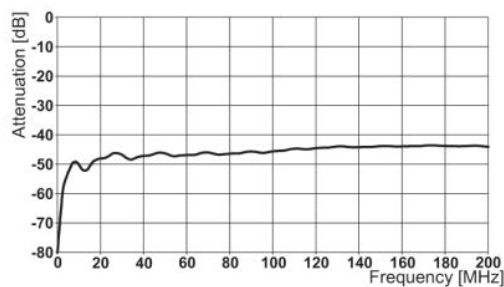

### Dimensioned drawing

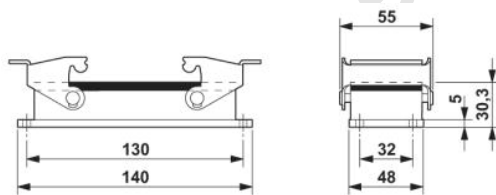

HC-B 24-AMQ-EMV Order No.: 1642962  
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1642962>

---

**Address**

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg, Germany  
Phone +49 5235 3 00  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.de>



© 2009 Phoenix Contact  
Technical modifications reserved;

onlinecomponents.com