


SWITCHES STANDARD TOGGLE

HEAVY DUTY UTILITY BAT HANDLE TOGGLE SWITCH (Two Circuit)

SPECIFICATIONS:

Current Rating:	20A @125V AC, 10A @ 250V AC 1-1/2 HP @ 125-250V AC
Initial Contact Resistance:	50 Meg ohm (Max.)
Insulation Resistance:	100 Meg ohm (Min.) @ 500V DC
Dielectric Strength:	1000V AC 50/60 Hz for 1 minute
Contact Material:	Brass - Nickel Plate
Terminal Material:	Brass
Terminal Type:	Screw


Part No.	Type	Action			Actuator
30-135	SP3T	ON	ON	ON	Metal

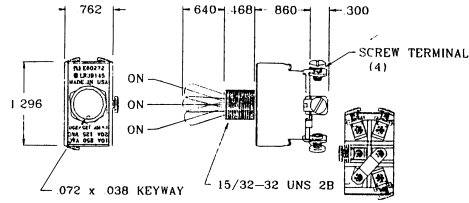

Mounting Hole: 0.500"

ON (2+6)
ON (2+4)
ON (1+4)

 Mounting Hole: 0.500"




SPECIFICATIONS:

Current Rating:	20A @125V AC, 10A @ 277V AC 3/4 HP @ 125-250V AC
Initial Contact Resistance:	50 Meg ohm (Max.)
Insulation Resistance:	100 Meg ohm (Min.) @ 500V DC
Dielectric Strength:	1000V AC 50/60 Hz for 1 minute
Contact Material:	Brass - Bright Nickel Plate
Terminal Material:	Brass
Terminal Type:	.250" Quick Connect

Part No.	Type	Action			Actuator
30-300	SPST	(ON)	-	OFF	Metal
30-305	SPST	ON	-	OFF	Metal
30-310	SPDT	ON	-	ON	Metal
30-315	SPDT	ON	OFF	ON	Metal
30-335	SPDT	(ON)	OFF	(ON)	Metal

NOTE: () = Momentary

HEAVY DUTY BAT HANDLE TOGGLE SWITCHES - SPST & SPDT

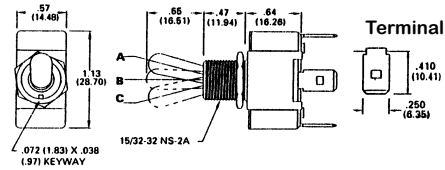

Mounting Hole: 0.500"




SPECIFICATIONS:

Current Rating:	20A @125V AC, 10A @ 277V AC 3/4 HP @ 125/250V AC
Initial Contact Resistance:	50 Meg ohm (Max.)
Insulation Resistance:	100 Meg ohm (Min.) @ 500V DC
Dielectric Strength:	1000V AC 50/60 Hz for 1 minute
Contact Material:	Brass - Bright Nickel Plate
Terminal Material:	Brass
Terminal Type:	Screw

Part No.	Type	Action			Actuator
30-080	SPST	ON	-	OFF	Metal
30-355	SPST	(ON)	-	OFF	Metal
30-013	SPDT	ON	-	ON	Metal
30-116	SPDT	ON	-	(ON)	Metal
30-010	SPDT	ON	OFF	ON	Metal
30-053	SPDT	ON	OFF	(ON)	Metal
30-055	SPDT	(ON)	OFF	(ON)	Metal

NOTE: () = Momentary

HEAVY DUTY BAT HANDLE TOGGLE SWITCHES - SPST & SPDT

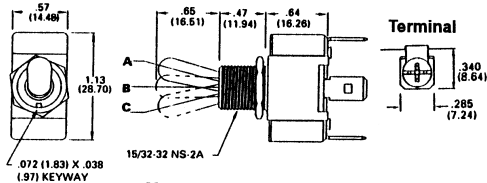

Mounting Hole: 0.500"




SPECIFICATIONS:

Current Rating:	20A @ 125V AC, 10A @ 277V AC 3/4 HP @ 125-250V AC
Initial Contact Resistance:	50 Meg ohm (Max.)
Insulation Resistance:	100 Meg ohm (Min.) @ 500V DC
Dielectric Strength:	1000V AC 50/60 Hz for 1 minute
Contact Material:	Brass - Bright Nickel Plate
Terminal Material:	Brass - Tin Dipped
Terminal Type:	Solder

Part No.	Type	Action			Actuator
30-078	SPST	ON	-	OFF	Metal
30-076	SPST	(ON)	-	OFF	Metal
30-014	SPDT	ON	-	ON	Metal
30-016	SPDT	ON	-	(ON)	Metal
30-086	SPDT	ON	OFF	(ON)	Metal

NOTE: () = Momentary

HEAVY DUTY BAT HANDLE TOGGLE SWITCHES - SPST & SPDT

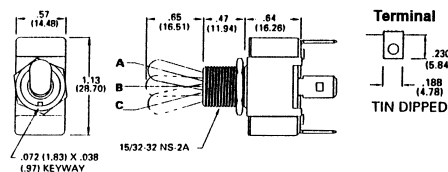

Mounting Hole: 0.500"

