

Search Results

Home > Products Overview > Search Results >


- Evaluate
- FAQ's
- How to Buy
- Bill of Material
 - Favorite Products List
 - Locate Distributor

Current refinements (click  to remove) Search Tips  Within Results


 Text Search: 'GEE71NC'

Your search criteria matched only one product, shown below

GEE71NC

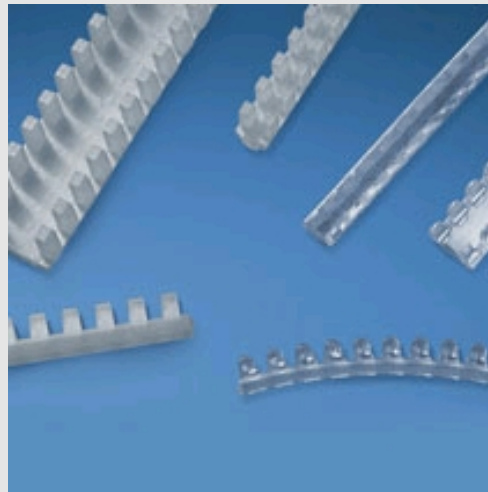

- Protects and insulates wires and cables from chafing against sharp edges
- Highly flexible self extinguishing Nylon material for indoor use up to 149°F (65°C)
 - Use in round panel holes

Part Number	GEE71NC
RoHS Compliancy Status	Compliant
Part Description	Slotted Wall Nylon Grommet Edging for use in cut outs up to 149°F (65°C)
Material	Nylon 6.6
Color	Natural
Height (In.)	.14
Height (mm)	3.5
Length (ft.)	100
Length (m)	30.5
Width (In.)	.15
Width (mm)	3.8
Flammability Rating	UL94 V-2
Outside Depth (In.)	.140
Outside Depth (mm)	3.5
Outside Width (In.)	.150
Outside Width (mm)	3.8
Panel Thickness Range (In.)	.063 – .079
Panel Thickness Range (mm)	1.6 – 2.0
Pricing Description	Grommet Edging, Slot 100', Nylon, Natural
Temperature Range	-40°F to 149°F (40°C to 65°C)
Min. Order UOM	RL
Min. Order Qty.	1
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.